


両舌付き座金



W2000820 鉄	W2010820 黄銅	W2020820 ステンレス	W2110820 SUS 316
---------------	----------------	-------------------	---------------------

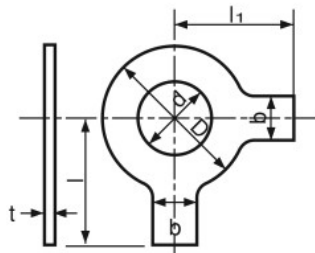

ねじの呼び	内径 (d)	外径 (D)	厚み (t)	穴芯長 (l)	穴芯長 (l1)	爪幅 (b)
W1/2	13.5	24	0.8	27	19	10
M3	3.2	7	0.29	13	5	4
M4	4.3	9	0.29	14	7	5
M5	5.3	10	0.5	15	8	6
M6	6.5	13	0.5	15	9	6
M8	8.5	16	0.5	20	13	7
M10	10.5	20	0.8	22	14	9
M12	12.5	24	0.8	27	19	10
M14	15	26	0.8	30	21	10
M16	17	30	1.2	32	24	12
M18	19	34	1.2	34	26	14
M20	21	38	1.2	36	28	15
M22	23	40	1.2	40	32	16
M24	25	44	1.2	44	35	17
M27	28	48	1.6	48	38	20
M30	31	52	1.6	52	42	21
M33	34	58	1.6	55	46	23
M36	37	62	1.6	60	50	25
M39	40	68	1.8	65	55	26
M42	44	72	1.8	70	62	28
M45	47	78	1.8	75	65	30
M48	50	82	1.8	80	70	32
M52	54	88	1.8	85	75	34

呼び	入り数	鉄		黄銅		ステンレス		SUS 316	
		生地	コテロ	クロメート					
1/2	500×6	●	●	●	●	●	●	●	●
M3	6000×6	●	●	●	●	●	●	●	●
M4	4000×6	●	●	●	●	●	●	●	●
M5	3000×6	●	●	●	●	●	●	●	●
M6	3000×6	●	●	●	●	●	●	●	●
M8	2000×6	●	●	●	●	●	●	●	●
M10	1000×6	●	●	●	●	●	●	●	●
M10	500×10				●				
M12	500×6	●	●	●	●	●	●	●	●
M14	500×6	●	●	●	●	●	●	●	●
M16	200×10				●				
M16	300×6	●	●	●	●	●	●	●	●
M18	200×6	●	●	●	●	●	●	●	●
M20	200×10				●				
M20	200×6	●	●	●	●	●	●	●	●
M22	200×10				●				
M22	200×6	●	●	●	●	●	●	●	●
M24	200×6	●	●	●	●	●	●	●	●
M27	100×6	●	●	●	●	●	●	●	●
M30	50×6	●	●	●	●	●	●	●	●
M33	50×6	●	●	●	●	●	●	●	●
M36	50×6	●	●	●	●	●	●	●	●
M39	40×6	●	●	●	●	●	●	●	●
M42	30×6	●	●	●	●	●	●	●	●
M45	30×6				●	●			
M45	50×6	●	●	●	●	●	●	●	●
M48	30×6	●	●	●	●	●	●	●	●
M52	30×6	●	●	●	●	●	●	●	●
M56	20×6	●	●	●	●	●	●	●	●

小ねじ
マクロねじ
組込みねじ
タップねじ
タップタイト
ハイテックねじ
いたすら防止ねじ
建材用スクリーン
ボルト
キャップホーロー
ドリルねじ
座金
つまみねじ
ナット
樹脂製品
アンカーボルト