


# ショルダーボルト

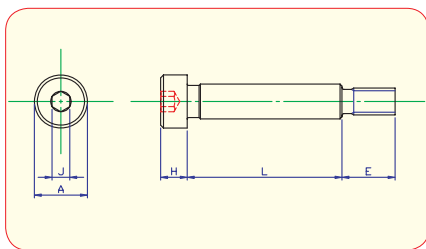

- 材質 ステンレス A2
- 表面処理 パシペート
- 規格 ASME B18.3



RoHS指令適合商品

単位: インチ

| 呼び        | 1/8    | 3/16   | 1/4    | 5/16   | 3/8    | 1/2    |
|-----------|--------|--------|--------|--------|--------|--------|
| ショルダー外径   | 0.1244 | 0.1863 | 0.2480 | 0.3105 | 0.3730 | 0.4980 |
| A 頭部外径    | 0.250  | 0.311  | 0.375  | 0.438  | 0.562  | 0.750  |
| H 頭部高さ    | 0.125  | 0.157  | 0.188  | 0.219  | 0.250  | 0.312  |
| J ソケットサイズ | 5/64   | 3/32   | 1/8    | 5/32   | 3/16   | 1/4    |
| E ねじ部長さ   | 0.157  | 0.189  | 0.375  | 0.438  | 0.500  | 0.625  |

| ねじの呼び       | サイズ   |                | 製品コード | 標準<br>梱包 |
|-------------|-------|----------------|-------|----------|
|             | L     |                |       |          |
| 1/8-(4-40)  | 1/8   | IN51.00440.010 | 25    |          |
|             | 3/16  | IN51.00440.015 | 25    |          |
|             | 1/4   | IN51.00440.020 | 25    |          |
|             | 5/16  | IN51.00440.025 | 25    |          |
|             | 3/8   | IN51.00440.030 | 25    |          |
|             | 1/2   | IN51.00440.040 | 25    |          |
|             | 5/8   | IN51.00440.050 | 25    |          |
|             | 3/4   | IN51.00440.060 | 25    |          |
|             | 1     | IN51.00440.100 | 25    |          |
|             | 1-1/4 | IN51.00440.120 | 25    |          |
| 3/16-(8-32) | 1/8   | IN51.00832.010 | 25    |          |
|             | 3/16  | IN51.00832.015 | 25    |          |
|             | 1/4   | IN51.00832.020 | 25    |          |
|             | 5/16  | IN51.00832.025 | 25    |          |
|             | 3/8   | IN51.00832.030 | 25    |          |
|             | 1/2   | IN51.00832.040 | 25    |          |
|             | 5/8   | IN51.00832.050 | 25    |          |
|             | 3/4   | IN51.00832.060 | 25    |          |
|             | 7/8   | IN51.00832.070 | 25    |          |
|             | 1     | IN51.00832.100 | 25    |          |
| 1/4-(10-24) | 3/8   | IN51.01024.030 | 25    |          |
|             | 1/2   | IN51.01024.040 | 25    |          |
|             | 5/8   | IN51.01024.050 | 25    |          |
|             | 3/4   | IN51.01024.060 | 25    |          |
|             | 1     | IN51.01024.100 | 25    |          |
|             | 1-1/4 | IN51.01024.120 | 25    |          |
| 1/4-(10-32) | 1/4   | IN51.01032.020 | 25    |          |
|             | 5/16  | IN51.01032.025 | 25    |          |
|             | 3/8   | IN51.01032.030 | 25    |          |
|             | 1/2   | IN51.01032.040 | 25    |          |
|             | 5/8   | IN51.01032.050 | 25    |          |
|             | 3/4   | IN51.01032.060 | 25    |          |
|             | 1     | IN51.01032.100 | 25    |          |
|             | 1-1/4 | IN51.01032.120 | 25    |          |

| ねじの呼び         | サイズ   |                | 製品コード | 標準<br>梱包 |
|---------------|-------|----------------|-------|----------|
|               | L     |                |       |          |
| 5/16-(1/4-20) | 3/8   | IN51.02020.030 | 25    |          |
|               | 1/2   | IN51.02020.040 | 25    |          |
|               | 5/8   | IN51.02020.050 | 25    |          |
|               | 3/4   | IN51.02020.060 | 25    |          |
|               | 7/8   | IN51.02020.070 | 25    |          |
|               | 1     | IN51.02020.100 | 25    |          |
|               | 1-1/4 | IN51.02020.120 | 25    |          |
|               | 1-1/2 | IN51.02020.140 | 25    |          |
|               | 1-3/4 | IN51.02020.160 | 25    |          |
|               | 2     | IN51.02020.200 | 25    |          |
| 3/8-(5/16-18) | 3/8   | IN51.02518.030 | 25    |          |
|               | 1/2   | IN51.02518.040 | 25    |          |
|               | 5/8   | IN51.02518.050 | 25    |          |
|               | 3/4   | IN51.02518.060 | 25    |          |
|               | 1     | IN51.02518.100 | 25    |          |
|               | 1-1/4 | IN51.02518.120 | 25    |          |
|               | 1-1/2 | IN51.02518.140 | 25    |          |
|               | 1-3/4 | IN51.02518.160 | 25    |          |
| 1/2-(3/8-16)  | 1/2   | IN51.03016.040 | 25    |          |
|               | 5/8   | IN51.03016.050 | 25    |          |
|               | 3/4   | IN51.03016.060 | 25    |          |
|               | 1     | IN51.03016.100 | 25    |          |
|               | 1-1/4 | IN51.03016.120 | 25    |          |
|               | 1-1/2 | IN51.03016.140 | 25    |          |
|               | 1-3/4 | IN51.03016.160 | 25    |          |
|               | 2     | IN51.03016.200 | 25    |          |

1本から販売致します。