




# PIN-FLAT HEAD HEX SOCKET SCREWS



● **Material**  
Stainless Steel A2

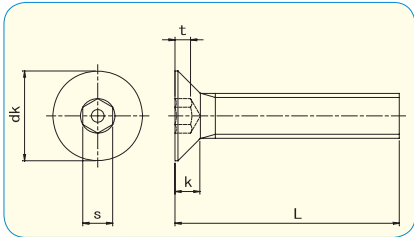

	M3	M4	M5	M6	M8
dk	5.5	8.4	9.3	11.3	15.8
k	1.65	2.7	2.7	3.3	4.65
s	2	2.5	3	4	5
Drive Size	2	2.5	3	4	5



SIZE	PART #		Box q'ty
	d	L	
M3	6	HE020306	100
	8	HE020308	100
	10	HE020310	100
	12	HE020312	100
	16	HE020316	100
	20	HE020320	100
M4	25	HE020325	100
	8	HE020408	100
	10	HE020410	100
	12	HE020412	100
	16	HE020416	100
	20	HE020420	100
M5	25	HE020425	100
	30	HE020430	100
	10	HE020510	100
	12	HE020512	100
	16	HE020516	100
	20	HE020520	100
	25	HE020525	100
	30	HE020530	100
	40	HE020540	100

SIZE	PART #		Box q'ty
	d	L	
M6	10	HE020610	100
	12	HE020612	100
	16	HE020616	100
	20	HE020620	100
	25	HE020625	100
	30	HE020630	100
	40	HE020640	100
M8	50	HE020650	100
	10	HE020810	100
	12	HE020812	100
	16	HE020816	100
	20	HE020820	100
	25	HE020825	100
	30	HE020830	100
	40	HE020840	100
	50	HE020850	100

Please see page 40-41 for tools.

- HE
- SP
- OW
- TX
- TW
- SF
- SS
- PH
- TC
- TOOLS
- Order Made