
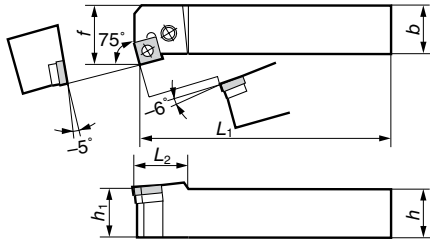
 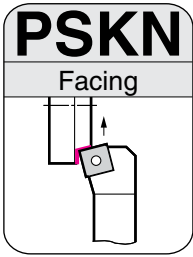


PSKN / ESBN Type




SEC- 70 Type Tool Holders

General Turning and Copying

Lever Lock

■ Spare Parts


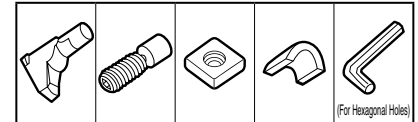


■ Holders

Above figures show right hand tools.

Cat. No.	Conventional Cat. No.	Stock		Dimensions (mm)						Applicable Inserts		Lever Pin	Bolt	Shim	Shim Pin	Spanner
		R	L	h	b	L ₁	f	h ₁	L ₂	Cat. No.	Ref. Page					
PSKN R/L1616H09	PSKN R/L1616-32	●	●	16	16	100	20	16	20	SN□□0903	B40	LCL3	LCS3	LSS32	LSP3	LH025
PSKN R/L2020K12	PSKN R/L2020-43	●	●	20	20	125	25	20	26	SN□□1204	From B41	LCL4	LCS4	LSS42	LSP4	LH030
PSKN R/L2520M12	PSKN R/L2520-43			25	20	150	25	25	26							
PSKN R/L2525M12	PSKN R/L2525-43	●	●	25	25	150	32	25	26							
PSKN R/L3225P12	PSKN R/L3225-43			32	25	170	32	32	26							
PSKN R/L3232P12	PSKN R/L3232-43			32	32	170	32	32	26	SN□□1506	From B44	LCL5	LCS5	LSS53	LSP5	LH030
PSKN R/L3225P15	PSKN R/L3225-54			32	25	170	32	32	32							
PSKN R/L3232P15	PSKN R/L3232-54			32	32	170	32	32	32	SN□□1906	From B45	LCL6	LCS6	LSS63	LSP6	LH040
PSKN R/L3232P19	PSKN R/L3232-64	●	●	32	32	170	40	32	36							
PSKN R/L4040R19	PSKN R/L4040-64			40	40	200	50	40	36	SN□□2507	B47	LCL8	LCS8	LSS84	LSP8	LH050
PSKN R/L5050S25	PSKN R/L5050-85			50	50	250	60	50	44							

Note: When using right/left handed type inserts for facing, holder and insert are opposite handed.

 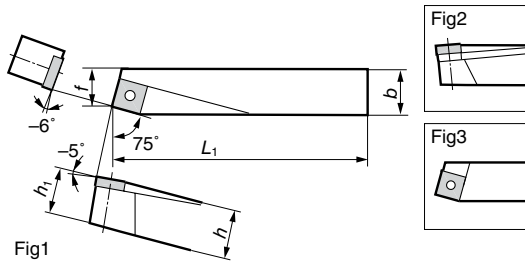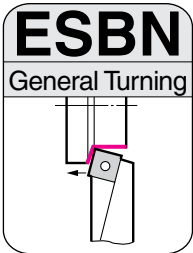


SEC- 30 Type Tool Holders

General Turning and Copying

Pin Lock

■ Spare Parts



■ Holders

Above figures show right hand tools.

Cat. No.	Conventional Cat. No.	Stock		Dimensions (mm)						Fig	Applicable Inserts		Pin	Shim	Spanner
		R	L	h	b	L ₁	f	h ₁	Cat. No.		Ref. Page				
ESBN R/L1212F09	ESBN R/L1212	●	●	12	12	80	9.5	11.5		1	SN□□0903	B40	P321US	-	KY40
ESBN R/L1616H09	ESBN R/L1616H32			16	16	100	13.0	15.5		1					
ESBN R/L1616H12	ESBN R/L1616H43			16	16	100	13.0	15.5		3	SN□□1204	From B41	P432U	-	
ESBN R/L2020K12	ESBN R/L2020			20	20	125	17.0	19.5		1					
ESBN R/L2020K12W	ESBN R/L2020W	●	●	20	20	125	17.0	19.5		2					
ESBN R/L2520M12	ESBN R/L2520			25	20	150	17.0	24.5		3					
ESBN R/L2520M12W	ESBN R/L2520W			25	20	150	17.0	24.5		2					
ESBN R/L2525M12	ESBN R/L2525			25	25	150	22.0	24.5		1					
ESBN R/L2525M12W	ESBN R/L2525W	●		25	25	150	22.0	24.5		2					
															P434U
													P434W	ESS42	
													P434U	-	
													P434W	ESS42	