
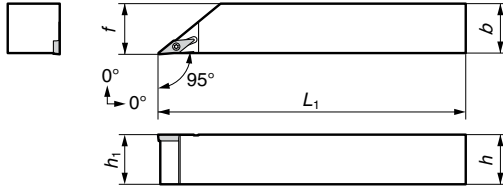
 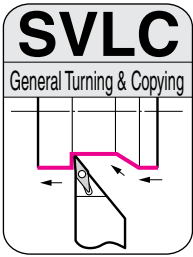


# SVLC / SVVC / SVPC Type



## SEC- SV Type MINI Tool Holders

General Turning and Copying

Screw-on

### Spare Parts



Screw	Spanner (For Torx Holes)
VC□□1103	From B119
BFTX2508NV	1.5
	TRX08

### ■ Holders

Above figures show right hand tools.

Cat. No.	Stock		Dimensions (mm)					Applicable Inserts	
	R	L	h	b	L <sub>1</sub>	f	h <sub>1</sub>	Cat. No.	Ref. Page
SVLC R/L1010-H11	●	●	10	10	100	10.5	10	VC□□1103	From B119
SVLC R/L1212-H11	●	●	12	12	100	12.5	12		
SVLC R/L1616-H11	●	●	16	16	100	16.5	16		
SVLC R/L2020-K11*	●	●	20	20	125	20.5	20		
SVLC R/L2525-M11	●	●	25	25	150	25.5	25		

\* Previous Cat. No. SVLC R/L 2020-H11

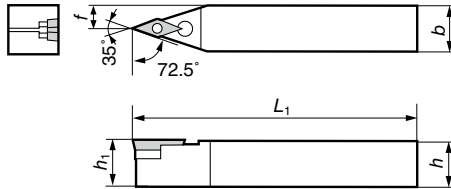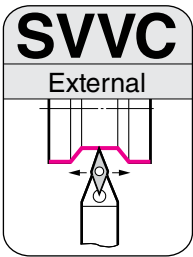

## SEC- SV Type Copying Tool Holders

Necking



Screw-on

### ■ Spare Parts

Pin	Nut	Shim	Screw	Spanner (For Torx Holes)	Nut Spanner (For Hexagonal Holes)
VP20	CPV33N	SVP32	BFTX03508	2.0	TRX10
VP25					
VP32					

### ■ Holders

Cat. No.	Conventional Cat. No.	Stock	Dimensions (mm)					Applicable Inserts	
			h	b	L <sub>1</sub>	f	h <sub>1</sub>	Cat. No.	Ref. Page
SVVC N2020K16	SVVC N2020-33	●	20	20	125	10.0	20	VC□□1604	From B120
SVVC N2525M16	SVVC N2525-33	●	25	25	150	12.5	25		
SVVC N3225P16	SVVC N3225-33	●	32	25	170	12.5	32		

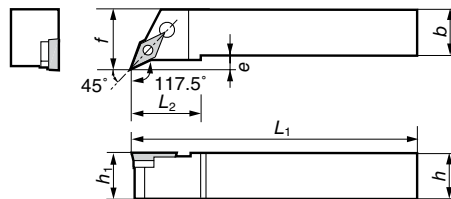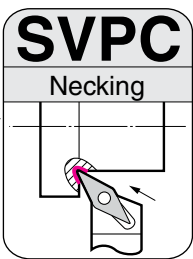

## SEC- SV Type Copying Tool Holders

Necking

Screw-on

### ■ Spare Parts

Pin	Nut	Shim	Screw	Spanner (For Torx Holes)	Nut Spanner (For Hexagonal Holes)
—	—	—	BFTX2508NV	1.5	TRX08
VP20	CPV33N	SVP32	BFTX03508	2.0	TRX10
VP25					
VP32					

### ■ Holders

Above figures show right hand tools.

Cat. No.	Conventional Cat. No.	Stock		Dimensions (mm)							Applicable Inserts	
		R	L	h	b	L <sub>1</sub>	f	h <sub>1</sub>	L <sub>2</sub>	e	Cat. No.	Ref. Page
SVPC R/L1010-H11	—	●	●	10	10	100	14.5	10	—	4.5	VC□□1103	From B119
SVPC R/L1212-H11	—	●	●	12	12	100	16.5	12	—	4.5		
SVPC R/L1616-H11	—	●	●	16	16	100	20.5	16	—	4.5		
SVPC R/L2020K16	SVPC R/L2020-33	●	●	20	20	125	25	20	35	5.0	VC□□1604	From B120
SVPC R/L2525M16	SVPC R/L2525-33	●	●	25	25	150	32	25	35	7.0		
SVPC R/L3225P16	SVPC R/L3225-33	●	●	32	25	170	32	32	35	7.0		

External Holders

Positive Inserts

C

D

R

S

T

V

W