 

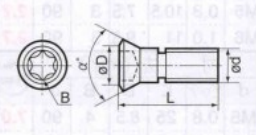


ねじ/偏芯軸

■ ねじ

皿ねじ (トルクス穴つき)	型番	在庫	寸法 (mm)						(N·m)
			d	ピッチ	L	D	B	α°	
	BFN0204T	●	M2	0.4	4.3	3.3	T8	90	—
	BFN0206T	●	M2	0.4	5.5	3.3	T8	90	1.1
	BFN0306T	●	M3	0.5	6	4.2	T10	90	—
	BFN0307T	●	M3	0.5	7	4.2	T10	90	2.0
	BFN0410T	●	M4	0.7	9.5	5.6	T10	90	2.0
	BFN0511T	●	M5	0.8	10.5	7.3	T20	90	—
	BFN0611T	●	M6	1.0	11	9.3	T25	90	—
	BFS0205T	●	M2	0.4	5.5	3	T8	60	1.1
	BFTX016033	●	M1.6	0.35	3.3	2.6	T6	60	0.2
	BFTX02507	●	M2.5	0.45	6.5	3.45	T8	60	—
	BFTX02508	●	M2.5	0.45	7.5	3.45	T8	60	—
	BFTX03508	●	M3.5	0.6	8	5.1	T10	52	2.0
	BFTX03584	●	M3.5	0.6	7.4	5.2	T15	60	3.0
	BFTX03588	●	M3.5	0.6	8.8	5.2	T15	60	3.4
	BFTX0408	●	M4	0.7	8	5.5	T15	60	—
	BFTX0414	●	M4	0.7	14.5	5.5	T15	60	3.0
	BFTX01604N	●	M1.6	0.35	4.2	2.4	T6	60	0.2
	BFTX0203N	●	M2	0.4	3	2.7	T6	60	0.5
	BFTX0204N	●	M2	0.4	4.3	2.7	T6	60	0.5
	BFTX02205N	●	M2.2	0.45	4.5	3	T6	60	0.5
	BFTX02505N	●	M2.5	0.45	4.5	3.45	T8	60	1.1
	BFTX02506N	●	M2.5	0.45	5.5	3.45	T8	60	1.5
	BFTX0305N	●	M3	0.5	5.3	4.2	T10	60	2.0
	BFTX0306N	●	M3	0.5	5.8	4.2	T10	60	2.0
	BFTX0307N	●	M3	0.5	6.5	4.2	T10	60	2.0
	BFTX03085N	●	M3	0.5	8.5	5.4	T10	60	—
	BFTX0309N	●	M3	0.5	9	4.2	T10	60	—
	BFTX0312N	●	M3	0.5	12	5.4	T10	60	—
	BFTX03509N	●	M3.5	0.6	8.5	4.9	T10	60	—
	BFTX0406N	●	M4	0.7	6	5.6	T15	60	—
	BFTX0407N	●	M4	0.7	7	5.6	T15	60	3.0
	BFTX0409N	●	M4	0.7	9	5.6	T15	60	3.4
	BFTX0412N	●	M4	0.7	12	5.5	T15	60	3.0
	BFTX0509N	●	M5	0.8	9	7	T20	60	5.0
	BFTX0511N	●	M5	0.8	11.5	7	T20	60	5.0
	BFTX0513N	●	M5	0.8	13	7	T20	60	5.0
	BFTX0515N	●	M5	0.8	15	7	T20	60	—
	BFTX0615N	●	M6	1.0	15	9	T25	60	5.0
	BFTX0619N	●	M6	1.0	19	9.3	T25	60	5.0
	BFTX0203A	●	M2	0.4	3	2.7	T6	90	0.5
	BFTX0204A	●	M2	0.4	4.3	2.7	T6	90	0.5
	BFTX0305A	●	M3	0.5	5.3	4.3	T10	90	—
	BFTX0306A	●	M3	0.5	5.8	4.3	T10	90	2.0
	BFTX0307A	●	M3	0.5	6.8	4.3	T10	90	2.0
	BFTX0407A	●	M4	0.7	7.3	5.6	T15	90	3.4
	BFTX0410A	●	M4	0.7	10.3	5.6	T15	90	3.4
	BFTX0509A	●	M5	0.8	9.3	6.9	T20	90	5.0
	BFTX0204NS	●	M2	0.4	4.4	3.2	T1.8	82	0.7
	BFTX0205NS	●	M2	0.4	5.5	3.2	T1.8	90	0.7
	BFTX02506NS	●	M2.5	0.45	6.8	3.6	T2.2	90	1.4
	BFTX0307NS	●	M3	0.5	7.8	4.2	T2.9	90	3
	BFTX02206NT	●	M2.2	0.45	6	3.2	T1.8	60	0.7
	BFTX02507NT	●	M2.5	0.45	7	3.6	T2.2	60	1.4
	BFTX0408NT	●	M4	0.7	8	5.8	T3.6	60	5
	BFTX0410NT	●	M4	0.7	10	5.8	T3.6	60	5
	BFTX02508NV	●	M2.5	0.45	7.5	3.45	T8	60	1.5

特キャップスクリュー BXD型	型番	在庫	寸法 (mm)						(N·m)
			d	ピッチ	L	D	B		
	BFF2506T08	●	M2.5	0.8	7.5	6	3.45	T8	—
	BFF3505T10	●	M3.5	0.6	6.6	5	5	T10	—
	BFF4510T15	●	M4.5	0.75	12.1	10.5	5.9	T15	—

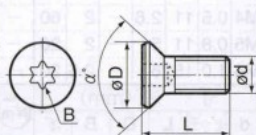

■ ねじ

皿ねじ (両面トルクス穴つき)	型番	在庫	寸法 (mm)						(N·m)
			d	ピッチ	L	D	B	α°	
	BFTX0410T8R	●	M4	0.7	9.6	5.6	T8	60	1.1
	BFTX0410T8L	●	M4	0.7	9.6	5.6	T8	60	1.1

※: 左ねじを示す
末尾 R: 右ねじ L: 左ねじ

高精度スクリュー (トルクス穴つき) (SEC 仕上ボールエンドミル用)	型番	在庫	寸法 (mm)						(N·m)
			d	ピッチ	L	D	B	α°	
	BFTG0408F	●	M4	0.5	7.5	5.7	T15	61	3.4
	BFTG0409F	●	M4	0.5	8.4	6.15	T15	61	3.4
	BFTG0513F	●	M5	0.5	13	6.8	T20	61	5.0
	BFTG0617F	●	M6	0.75	16.5	8	T25	61	7.5
	BFTG0621F	●	M6	0.75	21	9.5	T25	61	7.5
	BFTG0825F	●	M8	0.75	24.5	12	T25	61	7.5


皿ねじ (トルクスプラス穴つき)	型番	在庫	寸法 (mm)						(N·m)
			d	ピッチ	L	D	B	α°	
	BFTX018041P	●	M1.8	0.35	3.7	2.45	6IP	60	—
	BFTX025051P	●	M2.5	0.45	4.5	3.45	8IP	60	—
	BFTX025061P	●	M2.5	0.45	5.5	3.45	8IP	60	—
	BFTX03051P	●	M3	0.5	5.3	3.8	8IP	60	2.0
	BFTX03061P	●	M3	0.5	6	3.8	8IP	60	2.0
	BFTX03071P	●	M3	0.5	7	4.3	10IP	55	2.0
	BFTX03081P	●	M3	0.5	8	3.8	8IP	60	—
	BFTX03510P08	●	M3.5	0.6	10	5.3	8IP	60	—
	BFTX03510P15	●	M3.5	0.6	10	5.3	15IP	60	—
	BFTX035121P	●	M3.5	0.6	11.5	5.3	15IP	60	3.0
	BFTX035841P	●	M3.5	0.6	7.4	5.2	15IP	60	—
	BFTX04071P	●	M4	0.7	8	5.6	15IP	60	3.0
	BFTX04091P	●	M4	0.7	9	5.6	15IP	60	3.0
	BFTX04121P	●	M4	0.7	12	5.5	15IP	60	3.0
	BFTX04181P	●	M4	0.7	18	5.5	15IP	60	—
	BFTX04513P20	●	M4.5	0.75	13.1	6.8	20IP	60	—
	BFTX05111P	●	M5	0.8	11.5	7	20IP	60	—
	BFTX05131P	●	M5	0.8	13	7	20IP	60	—
	BFTX06151P	●	M6	1.0	15	9	25IP	60	—

皿ねじ (両面トルクスプラス穴つき)	型番	在庫	寸法 (mm)						(N·m)
			d	ピッチ	L	D	B	α°	
	BFTX0410NSW	●	M4	0.7	10	5.8	2.2	90	1.4
	BFTX0410NTW	●	M4	0.7	10	5.85	2.2	60	1.4
	BFTX0412NTW	●	M4	0.7	12	5.85	2.2	60	1.4

キャップスクリュー (トルクスプラス穴つき)	型番	在庫	寸法 (mm)						(N·m)
			d	ピッチ	L	ℓ	D	B	
	BXD022081P	●	M2.2	0.45	7.5	5.7	3.5	8IP	—
	BXD025091P	●	M2.5	0.45	9	—	4.1	10IP	—
	BXD030111P	●	M3	0.5	10.5	8	4.9	15IP	—
	BXD035121P	●	M3.5	0.6	11.5	8.8	5.5	15IP	—
	BXD040141P	●	M4	0.7	12.5	9.5	6	20IP	—
	BXD045151P	●	M4.5	0.75	14.3	10.8	6.8	25IP	—

■ 偏芯軸

SEC- ボーリングバイト用	型番	在庫	寸法 (mm)						(N·m)
			d	D ₁	D ₂	L	ℓ	B	
	CPB43	●	4.5	5.5	7	19	5	3	—
	CPB44T	●	4.5	5.5	7	22	5	3	—
	CPB45T	●	4.5	5.5	7	27	5	3	—
	CPB43S	●	4.5	5.5	7	16	5	3	—
	CPB32C	●	3.3	4.1	5.5	14	3.4	2.5	—
	CPB32	●	3.4	4.1	5.5	14	3.4	2.5	—
	CPB33	●	3.4	4.1	5.5	17	3.4	2.5	—
	CPB34	●	3.4	4.1	5.5	14	5	2.5	—
	CPB35	●	3.4	4.1	5.5	17	5	2.5	—
	CPB42	●	4.5	5.5	7	14	5	3	—
	CPB45	●	4.5	5.5	7	23	5	3	—
	CPB64	●	6.8	8.2	10.5	24	6.6	4	—

 

部品他

N

部品

資料
テニカマガジン