



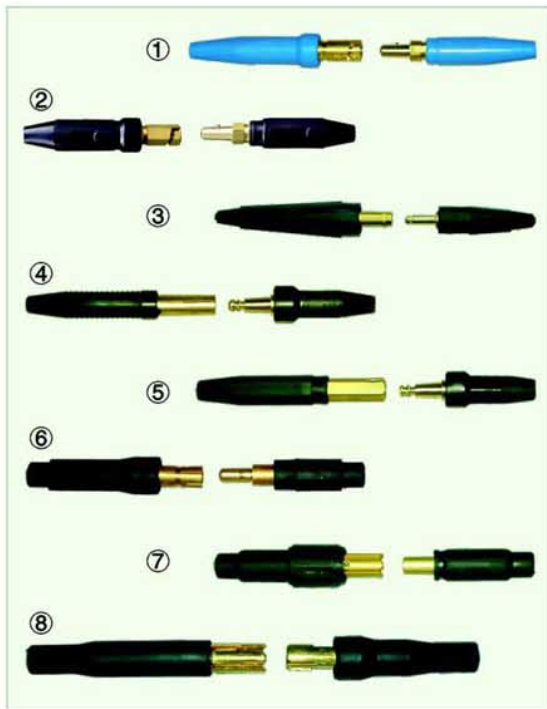


ケーブルジョイント



⑨ ウエルダー

 ⑩ パネル式

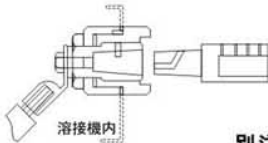

型 式	使用電線 (mm ²)	ネジ止	半田付	圧着式	金具形状	全 長 (mm)	重 量 (g)
① ST-38	22~38	○	別注○		φ20 3溝	220	280
ST-60	38~60	○	○		φ23 3溝	295	500
ST-80	60~80		別注○		φ29 3溝	280	800
ST-100	80~100		別注○		φ29 3溝	330	760
② T-38	22~38	○			六角 18	200	290
T-60	38~60	○		別注○	六角 22	325	630
T-100	80~100			別注○	六角 26	270	910
③ K-14	8~14	○			φ13	190	130
④ K-19	38~60	○	○		φ19	210	290
K-22	60	○	○		φ22	230	420
K-24	80	○	○		φ24	240	440
⑤ SK-19	38~60	○			六角 19	210	290
SK-22	60	○			六角 21	230	440
S-22	8~22	○			φ15	185	190
⑥ S-38	22~38	○	○		φ20	200	400
S-60	38~60	○	○		φ20	200	400
⑦ フリー300	22~60	○			φ22	260	390
⑧ N-60	50~60						650
N-80	60~80	ナット式			φ27	290	630
N-100	80~100						610
⑨ ウエルダー (T-38用・K-19用・K-22用・ST-38用・ST-60用)							
⑩ パネル式 小 (黒・赤)	8~22	ネジ止			オス φ15	140	180
	22~38				φ20 3溝	160	260

 
① ST-38



② T-38



T-100



③ K-14



④ K-19



⑤ SK-19



 
⑧ N-60



⑥ S-38



⑦ フリー300



⑨ ウエルダー K-19



ウエルダー T-38



⑩ パネル式 小 (黒)



パネル式 大 (赤)

