


寸法表 Lタイプ

V-L

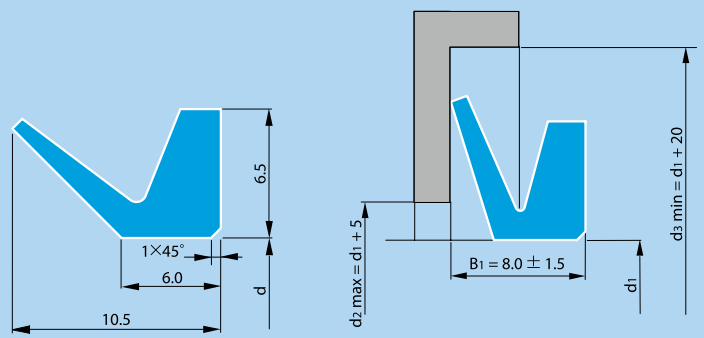

単位:mm

単位:mm

呼び番号	軸径 d1	内径 d
V-110L	105~115	99
V-120L	115~125	108
V-130L	125~135	117
V-140L	135~145	126
V-150L	145~155	135
V-160L	155~165	144
V-170L	165~175	153
V-180L	175~185	162
V-190L	185~195	171
V-200L	195~210	182
V-220L	210~233	198
V-250L	233~260	225
V-275L	260~285	247
V-300L	285~310	270
V-325L	310~335	292
V-350L	335~365	315
V-375L	365~385	337
V-400L	385~410	360
V-425L	410~440	382
V-450L	440~475	405
V-500L	475~510	450
V-525L	510~540	472
V-550L	540~575	495
V-600L	575~625	540
V-650L	625~675	600
V-700L	675~710	630
V-725L	710~740	670

呼び番号	軸径 d1	内径 d
V-750L	740~775	705
V-800L	775~825	745
V-850L	825~875	785
V-900L	875~925	825
V-950L	925~975	865
V-1000L	975~1025	910
V-1050L	1025~1075	955
V-1100L	1075~1125	1000
V-1150L	1125~1175	1045
V-1200L	1175~1225	1090
V-1250L	1225~1275	1135
V-1300L	1275~1325	1180
V-1350L	1325~1375	1225
V-1400L	1375~1425	1270
V-1450L	1425~1475	1315
V-1500L	1475~1525	1360
V-1550L	1525~1575	1405
V-1600L	1575~1625	1450
V-1650L	1625~1675	1495
V-1700L	1675~1725	1540
V-1750L	1725~1775	1585
V-1800L	1775~1825	1630
V-1850L	1825~1875	1675
V-1900L	1875~1925	1720
V-1950L	1925~1975	1765
V-2000L	1975~2025	1810