

SI-2740


10mm Belt Sander

- 10mm sanding belt sander
- Super light & ergonomic design
- Rubber grip giving comfortable operation and reducing vibration

OPTION	
509-45Z/40	10mm Sanding belt #40
509-45Z/80	10mm Sanding belt #80
509-45Z/100	10mm Sanding belt #100
509-45Z/120	10mm Sanding belt #120

Adjustable 160° Sanding arm

Quick change belt replacement lever

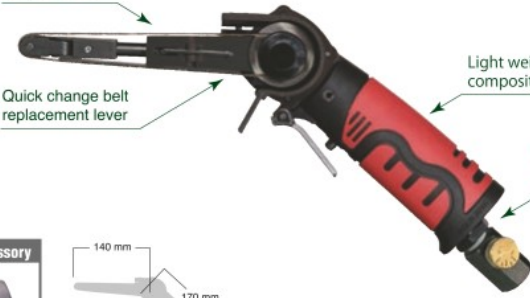

Light weight composite construction

Includes air regulator for quick speed adjustment


	SI-2740	SI-2741
Belt Size mm	10 x 330	12 x 330
Free Speed r.p.m.	15,000	15,000
Out Put Watt	317	317
Weight kg/(lb)	0.73/(1.61)	0.73/(1.61)
Noise Level dBA/(power)	85/(96)	85/(96)
Vibration a/k m/s ²	1.0/0.6	1.0/0.6
Max Air Consumption CFM/(L/S)	19.8/(9.3)	19.8/(9.3)
Avg. Air Consumption CFM/(L/S)	3.3/(1.6)	3.3/(1.6)

SI-2740

Standard Accessory



 Standard Accessory



SI-2741

Standard Accessory



SI-2700


10mm Belt Sander

- 10mm sanding belt sander
- Quick and easy belt change
- Adjustable arm angle


OPTION	
509-45Z/40	10mm Sanding belt #40
509-45Z/80	10mm Sanding belt #80
509-45Z/100	10mm Sanding belt #100
509-45Z/120	10mm Sanding belt #120

Adjustable 160° Sanding arm

Quick change belt replacement lever

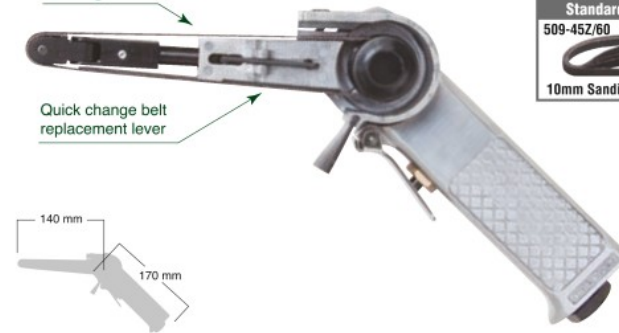

Standard Accessory

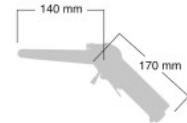

Belt Size mm	10x330
Free Speed r.p.m.	15,000
Out Put Watt	317
Weight kg/(lb)	0.82/(1.82)
Noise Level dBA/(power)	86/(99)
Vibration a/k m/s ²	2.2/0.7
Max Air Consumption CFM/(L/S)	19.8/(9.3)
Avg. Air Consumption CFM/(L/S)	3.3/(1.6)

SI-2700L

10mm Belt Sander


SI-2700LS

13mm Belt Sander

- Head rotates 120 degrees for operating convenience. Variable speed throttle for positive control.
- Best for the light grinding, sanding and deburring. (SI-2700L)
 - For nugget grinding of spot welding (SI-2700LS)


SI-2700L

Standard Accessory

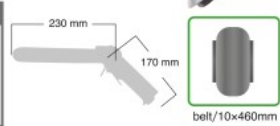

2700LS

Standard Accessory

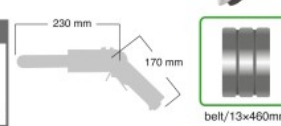


	SI-2700L	SI-2700LS
Belt Size mm	10x460	13x460
Free Speed r.p.m.	15,000	15,000
Out Put Watt	317	317
Weight kg/(lb)	0.85/(1.87)	0.9/(1.98)
Noise Level dBA/(power)	83/(94)	84/(95)
Vibration a/k m/s ²	2.5/0.7	1.6/0.6
Max Air Consumption CFM/(L/S)	19.8/(9.3)	19.8/(9.3)
Avg. Air Consumption CFM/(L/S)	3.3/(1.6)	3.3/(1.6)

SI-2800

20mm Belt Sander

- 20mm sanding belt sander
- Safety cover over belt wheel

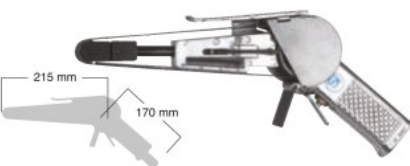

Belt Size mm	20x520
Free Speed r.p.m.	15,000
Out Put Watt	429
Weight kg/(lb)	1.43/(3.14)
Noise Level dBA/(power)	84/(95)
Vibration a/k m/s ²	3.0/0.8
Max Air Consumption CFM/(L/S)	22.8/(10.8)
Avg. Air Consumption CFM/(L/S)	3.8/(1.8)

OPTION	
507-58Z/40	20mm Sanding belt #40
507-58Z/80	20mm Sanding belt #80
507-58Z/100	20mm Sanding belt #100
507-58Z/120	20mm Sanding belt #120

Standard Accessory



SI-2830

30mm Belt Sander

- 30mm sanding belt sander
- Safety cover over belt wheel
- Side handle for firm tool control



Belt Size mm	30x540
Free Speed r.p.m.	10,000
Out Put Watt	582
Weight kg/(lb)	2.02/(4.45)
Noise Level dBA/(power)	86/(97)
Vibration a/k m/s ²	1.6/0.6
Max Air Consumption CFM/(L/S)	31.8/(15.0)
Avg. Air Consumption CFM/(L/S)	5.3/(2.5)

OPTION	
505-56Z/40	30mm Sanding belt #40
505-56Z/80	30mm Sanding belt #80
505-56Z/100	30mm Sanding belt #100
505-56Z/120	30mm Sanding belt #120

Standard Accessory

