


RGYパッキン

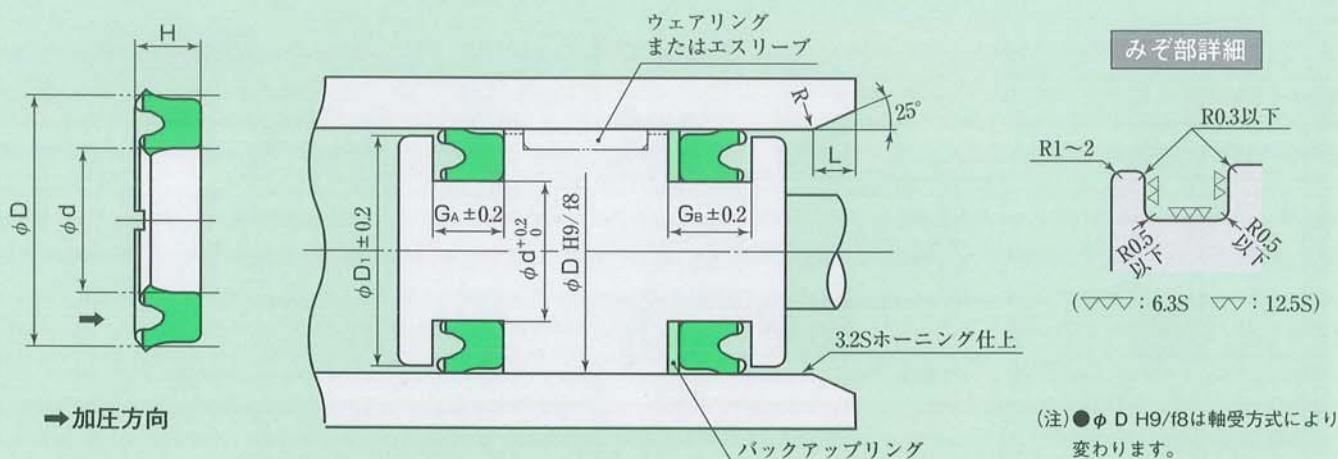

RGYパッキン寸法表

単位: mm

呼び番号 標準(RN 923)	パッキンおよびみぞ寸法							併用バック アップリング	互換SKY パッキン
	D	d	H	GA	GB	D1	L		
RGY- 40	40	30	6.2	7	8.5	39	3.5	TCS- 40× 30	SKY- 30
RGY- 45	45	35	6.2	7	8.5	44	3.5	TCS- 45× 35	SKY- 35
RGY- 50	50	40	6.2	7	8.5	49	3.5	TCS- 50× 40	SKY- 40
RGY- 55	55	45	6.2	7	8.5	54	3.5	TCS- 55× 45	SKY- 45
RGY- 60	60	50	6.2	7	8.5	59	3.5	TCS- 60× 50	SKY- 50
RGY- 63	63	53	6.2	7	8.5	62	3.5	TCS- 63× 53	SKY- 53
RGY- 65	65	55	6.2	7	8.5	64	3.5	TCS- 65× 55	SKY- 55
RGY- 70	70	60	6.2	7	8.5	69	3.5	TCS- 70× 60	SKY- 60
RGY- 70B	70	57	8.2	9	11	69	4	TCS- 70× 57	—
RGY- 75	75	65	6.2	7	8.5	74	4	TCS- 75× 65	SKY- 65
RGY- 75B	75	62	8.2	9	11	74	4	TCS- 75× 62	—
RGY- 80	80	70	6.2	7	8.5	79	4	TCS- 80× 70	SKY- 70
RGY- 80A	80	71	6.2	7	8.5	79	4	TCS- 80× 71	SKY- 71
RGY- 80B	80	65	9.2	10	12	79	4	TCS- 80× 65	—
RGY- 90	90	80	6.2	7	8.5	89	4	TCS- 90× 80	SKY- 80
RGY- 90B	90	75	9.2	10	12	88	4	TCS- 90× 75	—
RGY- 100	100	85	9.2	10	12	98	4	TCS-100× 85	SKY- 85
RGY- 110	110	95	9.2	10	12	108	4	TCS-110× 95	SKY- 95
RGY- 120	120	106	8.7	9.5	11.5	118	4	TCS-120×106	SKY-106
RGY- 125	125	112	8.7	9.5	11.5	123	4	TCS-125×112	SKY-112, 112A
RGY- 140	140	125	9.2	10	12	138	4	TCS-140×125	SKY-125
RGY- 150	150	136	8.7	9.5	11.5	148	4	TCS-150×136	SKY-136
RGY- 160	160	145	9.2	10	12	158	4	TCS-160×145	SKY-145
RGY- 180	180	165	9.2	10	12	178	4	TCS-180×165	SKY-165
RGY- 200	200	180	12.2	13	15.5	198	5.5	TCS-200×180	SKY-180
RGY- 224	224	204	12.2	13	15.5	222	5.5	TCS-224×204	SKY-204
RGY- 250	250	230	12.2	13	15.5	248	5.5	TCS-250×230	SKY-230

★ご注文・お問い合わせは、呼び番号にてご指示下さい。

★表中・呼び番号が色地のものは、在庫しております。