


KYパッキン

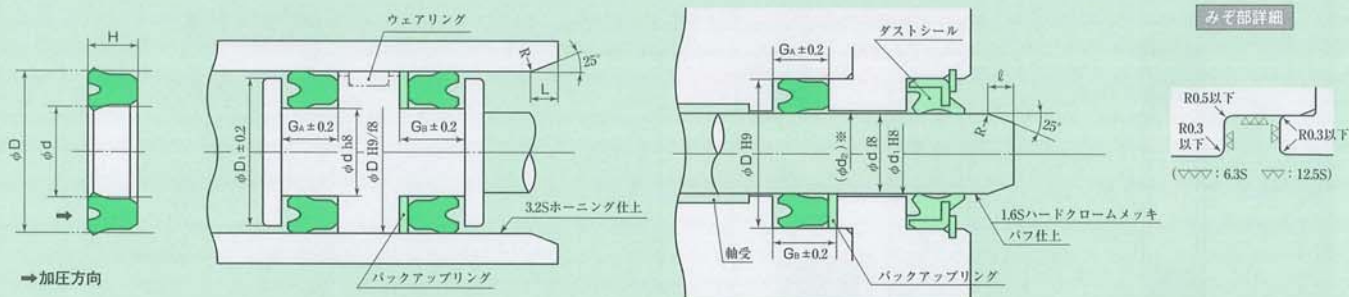

(注)ピストン用D=140以上ロッド用d=80以上は一体みぞに装着できます。この場合バックアップリングはバイアスカット (TC-KY-00) をご指定下さい。

KYパッキン寸法表

単位: mm

呼び番号	パッキンおよびみぞ寸法							呼び番号	パッキンおよびみぞ寸法						
標準(RN 906)	d	D	H	GA	GB	D1	d1(参考)	標準(RN 906)	d	D	H	GA	GB	D1	d1(参考)
KY- 6.3	6.3	16.3	7.5	8.5	10.5	15.3	6.7		40	55	10	11	14	53	40.5
KY- 7.1	7.1	17.1	7.5	8.5	10.5	16.1	7.5	KY- 40	40	56	12	13	16	54	40.5
KY- 8	8	18	7.5	8.5	10.5	17	8.4		40	60	12	13	16	58	40.5
KY- 9	9	19	7.5	8.5	10.5	18	9.4		44	60	12	13	16	58	44.5
KY- 10	10	20	7.5	8.5	10.5	19	10.4		45	60	10	11	14	58	45.5
KY- 11.2	11.2	21.2	7.5	8.5	10.5	20.2	11.6		45	60	12	13	16	58	45.5
KY- 12.5	12.5	22.5	7.5	8.5	10.5	21.5	12.9	KY- 45	45	61	12	13	16	59	45.5
KY- 14	14	24	7.5	8.5	10.5	23	14.4	KY- 47	47	63	12	13	16	61	47.5
	15	25	6.5	7.5	9.5	24	15.4		50	65	10	11	14	63	50.5
KY- 15	15	28	10	11	13.5	27	15.4	KY- 50	50	66	12	13	16	64	50.5
KY- 16	16	26	7.5	8.5	10.5	25	16.4		50	70	12	13	16	68	50.5
	18	28	8	9	11	27	18.4	KY- 53	53	69	12	13	16	67	53.6
KY- 18	18	31	10	11	13.5	30	18.4		54	70	12	13	16	68	54.6
KY- 18.5	18.5	31.5	10	11	13.5	30.5	18.9	KY- 55	55	71	12	13	16	69	55.6
	20	30	8	9	11	29	20.4		55	72	12	13	16	70	55.6
KY- 20	20	33	10	11	13.5	32	20.4		55	75	12	13	16	73	55.6
	20	35	9.5	10.5	13	34	20.4		55	80	15	16	19	78	55.6
	22	35	8	9	11.5	34	22.4	KY- 56	56	72	12	13	16	70	56.6
KY- 22	22	35	10	11	13.5	34	22.4	KY- 60	60	76	12	13	16	74	60.6
KY- 22.4	22.4	35.4	10	11	13.5	34.4	22.8	KY- 60 80 12	60	80	12	13	16	78	60.6
	25	35	8	9	11	34	25.4	KY- 63	63	79	12	13	16	77	63.6
KY- 25	25	38	10	11	13.5	37	25.4	KY- 64	64	80	12	13	16	78	64.6
KY- 27	27	40	10	11	13.5	39	27.4	KY- 65	65	81	12	13	16	79	65.6
	28	40	10	11	13.5	39	28.4	KY- 67	67	87	15	16	19	85	67.6
KY- 28	28	41	10	11	13.5	40	28.4		70	90	12	13	16	88	70.6
KY- 30	30	43	10	11	13.5	42	30.5	KY- 70	70	90	15	16	19	88	70.6
	30	45	10	11	14	44	30.5	KY- 71	71	91	15	16	19	89	71.6
KY- 31.5	31.5	44.5	10	11	13.5	43.5	32.0		75	95	12	13	16	93	75.6
KY- 32	32	45	10	11	13.5	44	32.5	KY- 75	75	95	15	16	19	93	75.6
KY- 34	34	50	12	13	16	48	34.5		80	100	12	13	16	98	80.6
	35	50	10	11	14	48	35.5	KY- 80	80	100	15	16	19	98	80.6
KY- 35	35	50	12	13	16	48	35.5		85	105	12	13	16	103	85.6
KY- 35A	35	51	12	13	16	49	35.5	KY- 85	85	105	15	16	19	103	85.6
KY- 35.5	35.5	51.5	12	13	16	49.5	36.0		90	110	12	13	16	108	90.6
	36	52	12	13	16	50	36.5	KY- 90	90	110	15	16	19	108	90.6