


GLYパッキン

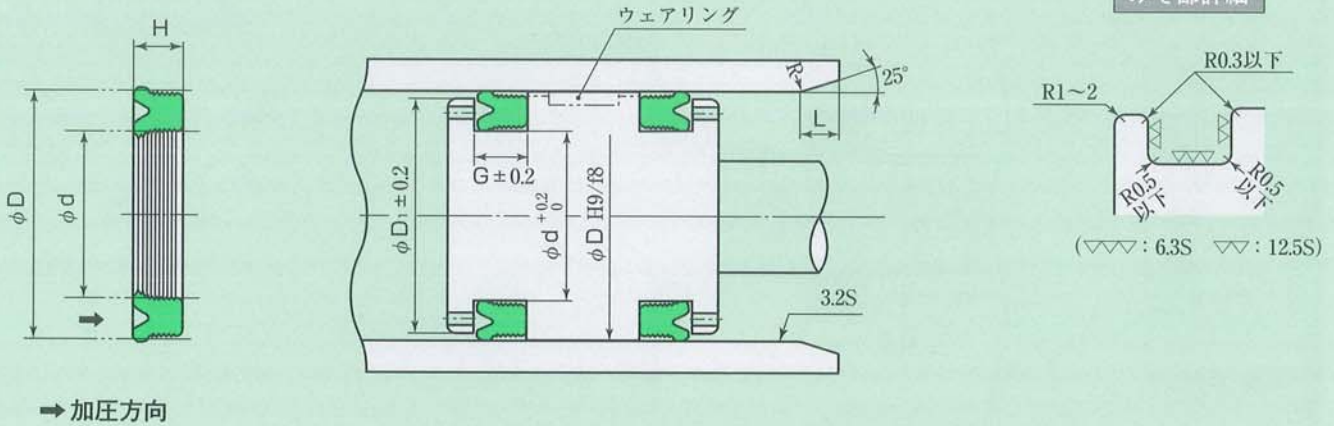

GLYパッキン寸法表

単位：mm

呼び番号		パッキンおよびみぞ寸法						
標準(RK 701)	耐熱用(RF 905)	d	D	H	G	D ₁	L	ℓ
GLY- 10 18 5		10	18	5	5.7	17.1	3	1.5
GLY- 12		12	20	5	5.7	19.1	3	1.5
GLY- 14		14	22	5	5.7	21.1	3	1.5
GLY- 16		16	24	5	5.7	23.1	3	1.5
GLY- 18		18	26	5	5.7	25.1	3	1.5
GLY- 20	GLY- 20F	20	28	5	5.7	27.1	3	1.5
GLY- 22.4	GLY- 22.4F	22.4	30	5	5.7	29.1	3	1.5
GLY- 25	GLY- 25F	25	33	5	5.7	32.1	3	1.5
GLY- 28		28	36	5	5.7	35.1	3	1.5
GLY- 30	GLY- 30F	30	40	6	7	39	3	3
GLY- 31.5		31.5	41.5	6	7	40.5	3	3
GLY- 32		32	42	6	7	41	3	3
GLY- 35	GLY- 35F	35	45	6	7	44	3	3
GLY- 35.5		35.5	45.5	6	7	44.5	3	3
GLY- 36	GLY- 36F	36	46	6	7	45	3	3
GLY- 40	GLY- 40F	40	50	6	7	49	3	3
GLY- 45	GLY- 45F	45	55	6	7	54	3	3
GLY- 50	GLY- 50F	50	60	6	7	59	3	3
GLY- 53	GLY- 53F	53	63	6	7	62	3	3
GLY- 55		55	65	6	7	64	3	3
GLY- 60	GLY- 60F	60	70	6	7	69	3	3
GLY- 63		63	73	6	7	72	3	3
GLY- 65		65	75	6	7	74	3	3
GLY- 70	GLY- 70F	70	80	6	7	79	3	3
GLY- 75		75	85	6	7	84	3	3
GLY- 80		80	90	6	7	89	3	3
GLY- 85		85	100	9	10	98.5	4	4
GLY- 95 110 9		95	110	9	10	108.5	4	4
GLY- 100	GLY- 100F	100	115	9	10	113.5	4	4
GLY- 105		105	120	9	10	118.5	4	4
GLY- 110	GLY- 110F	110	125	9	10	123.5	4	4
GLY- 125		125	140	9	10	138.5	4	4
GLY- 135		135	150	9	10	148.5	4	4
GLY- 145	GLY- 145F	145	160	9	10	158.5	4	4
GLY- 160 175 9		160	175	9	10	173.5	4	4
GLY- 165		165	180	9	10	178.5	4	4
GLY- 180	GLY- 180F	180	200	12	13	198	5	5
GLY- 200 220 12		200	220	12	13	218	5	5
GLY- 215		215	235	12	13	233	5	5
GLY- 230	GLY- 230F	230	250	12	13	248	5	5

★ご注文・お問合せは、呼び番号にてご指示下さい。
★表中 呼び番号が色地のものは、在庫しております。