




SFRスクレーパ

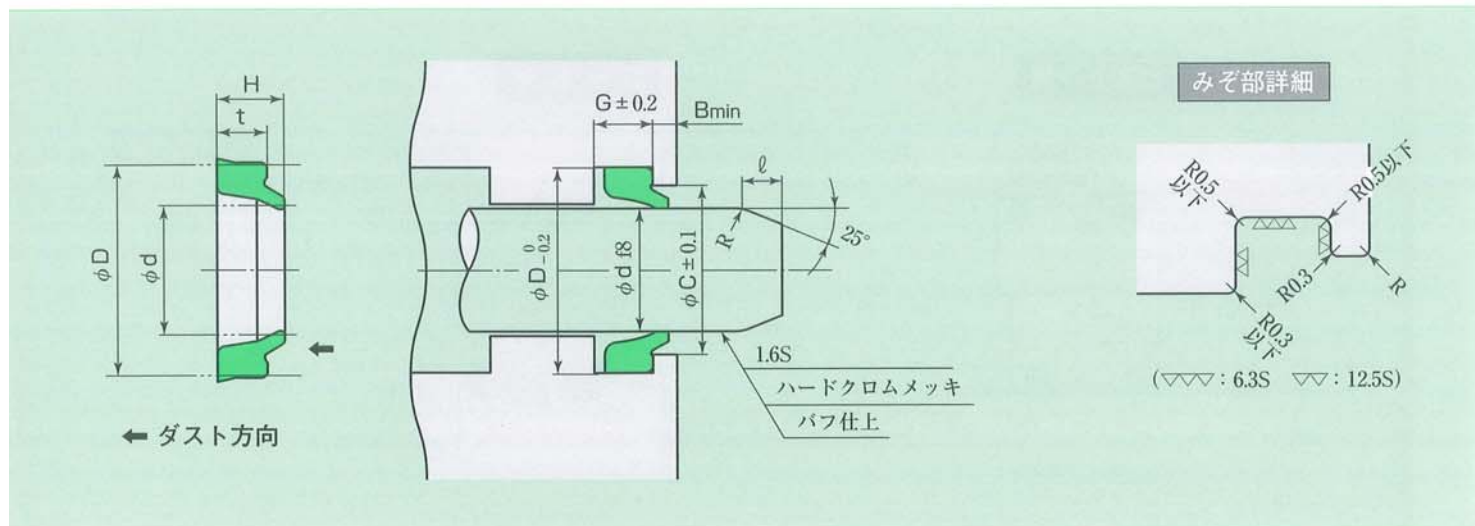

SFRスクレーパ寸法表

単位：mm

| 呼び番号 標準 (RN 912) | スクレーパおよびみぞ寸法 | | | | | | |
|---------------------|--------------|------|-----|-----|---|------|---|
| | d | D | H | t | G | C | B |
| SFR- 16K | 16 | 24 | 6 | 4.5 | 5 | 20.3 | 2 |
| SFR- 18K | 18 | 26 | 6 | 4.5 | 5 | 22.3 | 2 |
| SFR- 20K | 20 | 28 | 6 | 4.5 | 5 | 24.3 | 2 |
| SFR- 22K | 22 | 30 | 6 | 4.5 | 5 | 26.3 | 2 |
| SFR- 22.4K | 22.4 | 30.4 | 6 | 4.5 | 5 | 26.7 | 2 |
| SFR- 25K | 25 | 33 | 6 | 4.5 | 5 | 29.3 | 2 |
| SFR- 28K | 28 | 36 | 6 | 4.5 | 5 | 32.3 | 2 |
| SFR- 30K | 30 | 38 | 6.5 | 5 | 6 | 34 | 2 |
| SFR- 31.5K | 31.5 | 39.5 | 6.5 | 5 | 6 | 35.5 | 2 |
| SFR- 32K | 32 | 40 | 6.5 | 5 | 6 | 36 | 2 |
| SFR- 35K | 35 | 43 | 6.5 | 5 | 6 | 39 | 2 |
| SFR- 35.5K | 35.5 | 43.5 | 6.5 | 5 | 6 | 39.5 | 2 |
| SFR- 36K | 36 | 44 | 6.5 | 5 | 6 | 40 | 2 |
| SFR- 40K | 40 | 48 | 6.5 | 5 | 6 | 44 | 2 |
| SFR- 45K | 45 | 53 | 6.5 | 5 | 6 | 49 | 2 |
| SFR- 50K | 50 | 58 | 6.5 | 5 | 6 | 54 | 2 |
| SFR- 55K | 55 | 63 | 6.5 | 5 | 6 | 59 | 2 |
| SFR- 60K | 60 | 68 | 6.5 | 5 | 6 | 64 | 2 |
| SFR- 63K | 63 | 71 | 6.5 | 5 | 6 | 67 | 2 |
| SFR- 70K | 70 | 80 | 8 | 6 | 7 | 75 | 3 |
| SFR- 75K | 75 | 85 | 8 | 6 | 7 | 80 | 3 |
| SFR- 80K | 80 | 90 | 8 | 6 | 7 | 85 | 3 |

★ご注文・お問合せは、呼び番号にてご指示下さい。
 ★表中 呼び番号が色地のものは、在庫しております。