


# PWLベアリング

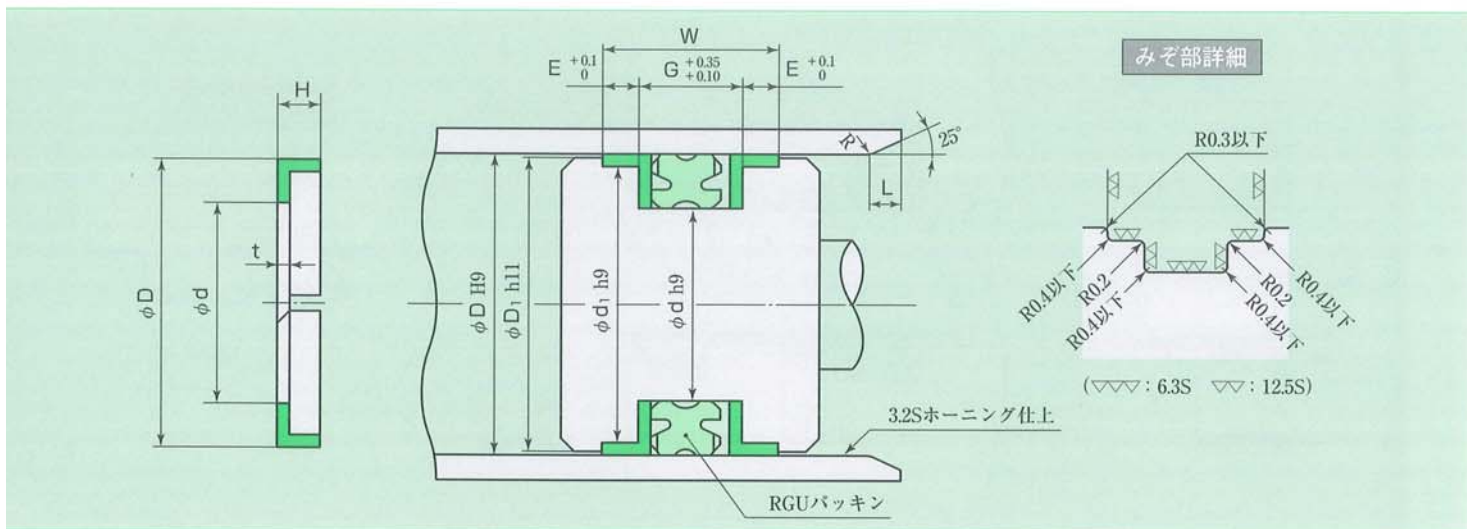

PWLベアリング寸法表

単位: mm

呼び寸法 標準(PN 104)	PWL ベアリング および みぞ寸法									
	D	d	H	t	D <sub>1</sub>	d <sub>1</sub>	G	E	W	L
PWL- 40	40	30	5.5	1.5	39.0	37	10.0	4.0	18.0	2.5
PWL- 45	45	35	5.5	1.5	44.0	42	10.0	4.0	18.0	2.5
PWL- 50	50	40	5.5	1.5	49.0	47	10.0	4.0	18.0	2.5
PWL- 55	55	45	5.5	1.5	54.0	52	10.0	4.0	18.0	2.5
PWL- 60	60	50	5.5	1.5	59.0	57	10.0	4.0	18.0	2.5
PWL- 63	63	53	5.5	1.5	62.0	60	10.0	4.0	18.0	2.5
PWL- 65	65	55	7.0	2.0	63.5	61	11.0	5.0	21.0	2.5
PWL- 70	70	60	7.0	2.0	68.5	66	11.0	5.0	21.0	2.5
PWL- 75	75	65	7.0	2.0	73.5	71	11.0	5.0	21.0	2.5
PWL- 80	80	67	7.0	2.0	78.5	76	12.5	5.0	22.5	3.0
PWL- 85	85	72	7.0	2.0	83.5	81	12.5	5.0	22.5	3.0
PWL- 90	90	77	7.0	2.0	88.5	86	12.5	5.0	22.5	3.0
PWL- 100	100	85	7.0	2.0	98.5	96	14.0	5.0	24.0	4.0

★ご注文・お問合せは、呼び番号にてご指示下さい。

★表中・呼び番号が色地のものは在庫しております。