

# KFG2 Series


Applicable Tubing: Metric Size, Connection Thread: R, Rc

## Dimensions

### Female Connector: KFG2F



Applicable tubing size (mm)		Connection thread Rc	Model	Width across flat		L1	L2	M	ød	Effective area (mm <sup>2</sup> )		Weight (g)
O.D.	I.D.			H1	H2							
ø4	ø2.5	1/4	KFG2F0425-02	17	8	25.9	16.4	5	1.8	1.6	24	
ø4	ø3	1/4	KFG2F0403-02						2.3	2.6		
ø6	ø4	1/4	KFG2F0604-02	17	10	26.8	15.8	5.8	3.3	6	25	
ø8	ø6	3/8	KFG2F0806-03	19	14	28.8	16.4	6.6	5.3	17	31	
ø10	ø7.5	3/8	KFG2F1075-03	19	17	30	15.6	7.6	6.8	30	36	
ø10	ø8	3/8	KFG2F1008-03						7.3	35		
ø12	ø9	3/8	KFG2F1209-03	19	17	31.2	15.2	8.5	8	45	36	
ø12	ø10	3/8	KFG2F1210-03						9	57		
ø16	ø13	1/2	KFG2F1613-04	24	22	37.7	20.5	9.3	12	101	71	

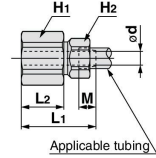

### Union Nut: KFG2N



Applicable tubing O.D. (mm)	Model	H (Width across flat)	L	Weight (g)
ø4	KFG2N-04	8	7.7	1.9
ø6	KFG2N-06	10	8.8	3
ø8	KFG2N-08	14	10.1	6.7
ø10	KFG2N-10	17	11.7	10.5
ø12	KFG2N-12	17	12.8	9.6
ø16	KFG2N-16	22	14	15.3

