

 
 
 
 
LQ1 Series

How to Order Space Saving Type Fittings

This product, for use with products with one nut attached (insert bushing) has one nut removed.

LQ1 E 21 - SN -

Fitting type

E	T
Union Elbow 	Union Tee 
P	U
Panel Mount Union 	Union 

Packaging

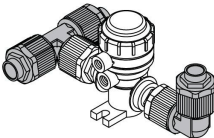
Symbol	Packaging
Nil	Clean packaging equivalent to Class M3.5
1	Standard packaging equivalent to Class M5.5

• Without a nut (including insert bushing) in one part

• Combination of different diameter (on B side)

Symbol	Applicable tubing size (mm)	Symbol	Applicable tubing size (inch)
1 1	4 x 3	1 A	1/8" x 0.086"
1 2	3 x 2	—	—
2 1	6 x 4	2 A	1/4" x 5/32"
2 2	4 x 3	2 B	3/16" x 1/8"
3 1	10 x 8	2 C	1/8" x 0.086"
3 2	8 x 6	3 A	3/8" x 1/4"
3 3	6 x 4	3 B	1/4" x 5/32"
4 1	12 x 10	4 A	1/2" x 3/8"
4 2	10 x 8	4 B	3/8" x 1/4"
5 1	19 x 16	5 A	3/4" x 5/8"
5 2	12 x 10	5 B	1/2" x 3/8"
6 1	25 x 22	6 A	1" x 7/8"
6 2	19 x 16	6 B	3/4" x 5/8"

Connection example



Note 1) For each body class, the second and later numbers or symbols indicate reducing. However, use of different diameters is not available with size 1.

Note 2) Please choose the same size fitting as the fitting of the connecting product.

Note 3) For details of applicable tubing sizes, refer to page 945.

Options

Panel mounting nut

LQN P 11 -

Applicable fitting

Symbol	Size
11	1
12	2
13	3
14	4
15	5
16	6

Packaging

Symbol	Packaging
Nil	Clean packaging equivalent to Class M3.5
1	Standard packaging equivalent to Class M5.5



It is used to mount panels with a panel mount union.