

## RATCHET WRENCH

**Bolt Capacity 10mm** [FLAT HEAD]

- 1/4" Bit. ● Low profile flat head. ● No deforming, no splashing of oil. ● Switchable rotations at hand, even in small spaces. ● Urethane covered cushion grip. ● 360 degree rotating rear exhaust.

### SP-7250H

1/4" Bit chuck retainer



**Bolt Capacity 10mm** [FLAT HEAD]

- Low profile flat head. ● No deforming, no splashing of oil. ● Switchable rotations at hand, even in small spaces. ● Ball locking. ● Urethane covered cushion grip. ● Built-in power regulator. ● 360 degree rotating rear exhaust.

### SP-7265

3/8" Ball-Lock




**Bolt Capacity 10mm** [ROTATIONAL HEAD]

- Rotating head (fixed at 90 degree each) . ● For working in tight spaces. ● Super compact size to fit in your hand.

### SP-1772

3/8" Ball-Lock

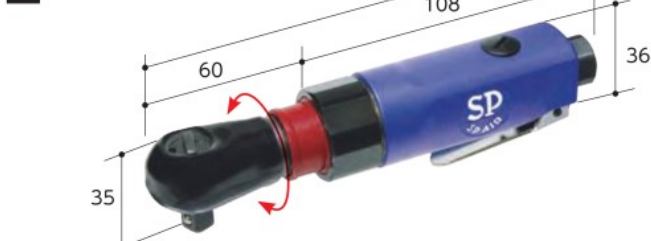

**Bolt Capacity 10mm** [ROTATIONAL HEAD]

- Rotating head (fixed at 90 degree each) . ● For working in tight spaces.

### SP-1133RH

3/8" Ball-Lock



**Bolt Capacity 10mm** [SEALED HEAD]

- Improved durability of ratchet head ● Switchable rotations at hand, even in small spaces. ● Ball locking. ● Urethane covered cushion grip. ● Built-in power regulator. ● 360 degree rotating rear exhaust.

### SP-7765

3/8" Ball-Lock



**Bolt Capacity 12mm** [FLAT HEAD]

- High power. ● Low profile flat head. ● No deforming, no splashing of oil. ● Switchable rotations at hand, even in small spaces. ● Ball locking. ● Urethane covered cushion grip. ● 360 degree rotating side exhaust.

### SP-7787

1/2" Ball-Lock




**Bolt Capacity 10mm** [W/ SILENCER] [ROTATIONAL HEAD]

- Swivel silencer. ● 360 degree rotating exhaust. ● Rotating head (fixed at 90 degree each) . ● For working in tight spaces.

### SP-1772N

3/8" Ball-Lock

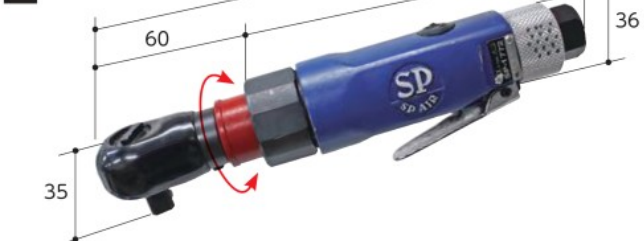


**Bolt Capacity 10mm** [ROTATIONAL HEAD]

- Rotating head (fixed at 90 degree each) . ● For working in tight spaces.

### SP-1133RH-2

1/2" Ball-Lock

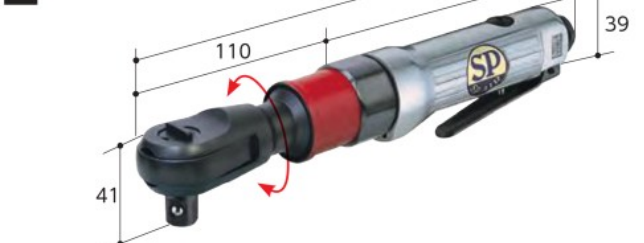

EDP	Model No.	Sq. Drive (inch)	Torque Range (N·m)	Free Speed (min <sup>-1</sup> )	Overall Length (mm)	Air Consumption (ml/min)	Hose Coupling	Net Weight (kg)	JAN (4545695)
370063	SP-7250H	1/4" HEX	20	290	203	0.2	1/4" NPT	0.7	003685
370059	SP-7765	3/8"	20	250	205	0.2	1/4" NPT	0.64	000035
370061	SP-7265	3/8"	20	400	203	0.4	1/4" NPT	0.7	003487
370062	SP-7787	1/2"	30	200	315	0.7	1/4" NPT	1.5	003494
370047	SP-1772	3/8"	20	220	168	0.2	1/4" NPT	0.5	001438
370054	SP-1772N	3/8"	20	200	188	0.2	1/4" NPT	0.54	002565
370056	SP-1133RH	3/8"	30	160	254	0.2	1/4" NPT	1.2	001452
370050	SP-1133RH-2	1/2"	30	160	254	0.2	1/4" NPT	1.2	001469

Air pressure: 0.62 MPa Air hose inner dia.: 9.5 mm Rear exhaust Side exhaust (SP-7787) Air connector included