


# メールコネクター (テーパーネジタイプ)

MALE CONNECTOR (SHD Type)

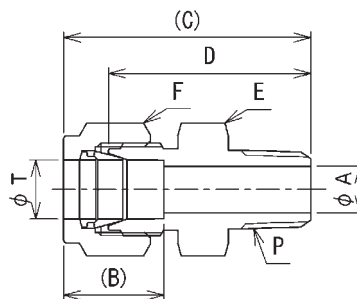

UNIT : mm

型番	チューブ外径	管用テーパ おねじ	最小穴径	差込深さ	組込長さ	本体長さ	六角対辺	
TYPE NO.	TUBE O.D.	PIPE THREAD	MIN. BORE	DEPTH	APPROX	BODY	WIDTH ACROSS HEX	
	T	P	A	B	C	D	E	F

[ミリサイズチューブ用]

SHD- 6M- 2R	6	R1/8	4.5	15.5	36.6	29	14	14
SHD- 6M- 4R	6	R1/4	4.5	15.5	39.1	31.5	14	14
SHD- 6M- 6R	6	R3/8	4.5	15.5	40.1	32.5	19	14
SHD- 6M- 8R	6	R1/2	4.5	15.5	44.6	37	22	14
SHD- 8M- 2R	8	R1/8	4.5	16.5	37.7	30	16	16
SHD- 8M- 4R	8	R1/4	6	16.5	40.2	32.5	16	16
SHD- 8M- 6R	8	R3/8	6	16.5	41.2	33.5	19	16
SHD- 8M- 8R	8	R1/2	6	16.5	45.7	38	22	16
SHD-10M- 2R	10	R1/8	5	17.2	39.2	31.5	17	19
SHD-10M- 4R	10	R1/4	7.5	17.2	41.7	34	17	19
SHD-10M- 6R	10	R3/8	8	17.2	42.2	34.5	19	19
SHD-10M- 8R	10	R1/2	8	17.2	46.7	39	22	19
SHD-12M- 4R	12	R1/4	7.5	23	44.4	34	22	22
SHD-12M- 6R	12	R3/8	10	23	44.9	34.5	22	22
SHD-12M- 8R	12	R1/2	10	23	49.4	39	22	22

[インチサイズチューブ用] チューブ外径の ( ) 内はインチ表示

SHD- 4C- 2R	6.35(1/4")	R1/8	4.8	15.5	36.6	29	14	14
SHD- 4C- 4R	6.35(1/4")	R1/4	4.8	15.5	39.1	31.5	14	14
SHD- 4C- 6R	6.35(1/4")	R3/8	4.8	15.5	40.1	32.5	19	14
SHD- 4C- 8R	6.35(1/4")	R1/2	4.8	15.5	44.6	37	22	14
SHD- 6C- 2R	9.52(3/8")	R1/8	5	17.2	39.2	31.5	17	17
SHD- 6C- 4R	9.52(3/8")	R1/4	7.5	17.2	41.7	34	17	17
SHD- 6C- 6R	9.52(3/8")	R3/8	7.5	17.2	42.2	34.5	19	17
SHD- 6C- 8R	9.52(3/8")	R1/2	7.5	17.2	46.7	39	22	17
SHD- 8C- 4R	12.7(1/2")	R1/4	7.5	23	44.4	34	22	22
SHD- 8C- 6R	12.7(1/2")	R3/8	10	23	44.9	34.5	22	22
SHD- 8C- 8R	12.7(1/2")	R1/2	10.4	23	49.4	39	22	22

◎製品改良のため、形状及び(法は、予告無く変更することがありますので、あらかじめご了承下さい。

◎NPT (アメリカ管用テーパおねじ)をご注文の場合は、型番末尾の"R"を"N"に変えてご用命下さい。

例：SHD-6M-4R ⇒ SHD-6M-4N