


# メールエルボコネクター (テーパネジタイプ)

## MALE ELBOW CONNECTOR (SLD Type)

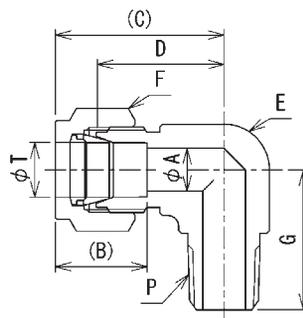

UNIT : mm

型番	チューブ外径	管用テーパ おねじ	最小穴径	差込深さ	組込長さ	本体長さ	二面幅	六角対辺	
TYPE NO.	TUBE O.D.	PIPE THREAD	MIN. BORE	DEPTH	APPROX	BODY	ACROSS FLATS	ACROSS HEX	
	T	P	A	B	C	D	E	F	G

[ミリサイズチューブ用]

SLD- 6M- 2R	6	R1/8	4.5	15.5	28.1	20.5	14	14	21.5
SLD- 6M- 4R	6	R1/4	4.5	15.5	28.1	20.5	14	14	24
SLD- 6M- 6R	6	R3/8	4.5	15.5	30.1	22.5	17	14	28
SLD- 6M- 8R	6	R1/2	4.5	15.5	32.1	24.5	21	14	33
SLD- 8M- 2R	8	R1/8	6	16.5	29.2	21.5	14	16	21.5
SLD- 8M- 4R	8	R1/4	6	16.5	29.2	21.5	14	16	24
SLD- 8M- 6R	8	R3/8	6	16.5	30.7	23	17	16	28
SLD- 8M- 8R	8	R1/2	6	16.5	32.7	25	21	16	33
SLD-10M- 2R	10	R1/8	5	17.2	31.7	24	17	19	24.5
SLD-10M- 4R	10	R1/4	7	17.2	31.7	24	17	19	27.5
SLD-10M- 6R	10	R3/8	8	17.2	31.7	24	17	19	28
SLD-10M- 8R	10	R1/2	8	17.2	33.7	26	21	19	33
SLD-12M- 4R	12	R1/4	7	23	36.4	26	21	22	28.5
SLD-12M- 6R	12	R3/8	9.5	23	36.4	26	21	22	29
SLD-12M- 8R	12	R1/2	10	23	36.4	26	21	22	33

[インチサイズチューブ用] チューブ外径の ( ) 内はインチ表示

SLD- 4C- 2R	6.35(1/4")	R1/8	4.8	15.5	28.1	20.5	14	14	21.5
SLD- 4C- 4R	6.35(1/4")	R1/4	4.8	15.5	28.1	20.5	14	14	24
SLD- 4C- 6R	6.35(1/4")	R3/8	4.8	15.5	30.1	22.5	17	14	28
SLD- 4C- 8R	6.35(1/4")	R1/2	4.8	15.5	32.1	24.5	21	14	33
SLD- 6C- 2R	9.52(3/8")	R1/8	5	17.2	31.7	24	17	17	24.5
SLD- 6C- 4R	9.52(3/8")	R1/4	7	17.2	31.7	24	17	17	27.5
SLD- 6C- 6R	9.52(3/8")	R3/8	7.5	17.2	31.7	24	17	17	28
SLD- 6C- 8R	9.52(3/8")	R1/2	7.5	17.2	33.7	26	21	17	33
SLD- 8C- 4R	12.7(1/2")	R1/4	7	23	36.4	26	21	22	28.5
SLD- 8C- 6R	12.7(1/2")	R3/8	10	23	36.4	26	21	22	29
SLD- 8C- 8R	12.7(1/2")	R1/2	10	23	36.4	26	21	22	33

◎A寸法はチューブ側とねじ側 (P側) で異なる場合があります。A寸法は最小穴寸法を表しています。  
 ◎製品改良のため、形状及び寸法は、予告無く変更することがありますので、あらかじめご了承下さい。  
 ◎NPT (アメリカ管用テーパおねじ) をご注文の場合は、型番の "R" を "N" に変えてご用命下さい。  
 例: SLD-6M-4R ⇒ SLD-6M-4N