


Pneumatic Wheel/Airless (Flat-free) Wheel Castors

RoHS compliant products.

POINT


- Pneumatic tire absorbs shock on uneven floor by cushion of compressed air.
- Airless tire; comprised of **two different types of rubber fillings**, resulting in reducing impact and absorbing vibration from the floor.
- Semi-pneumatic tire; a type of **tubeless** and puncture-proof tire.

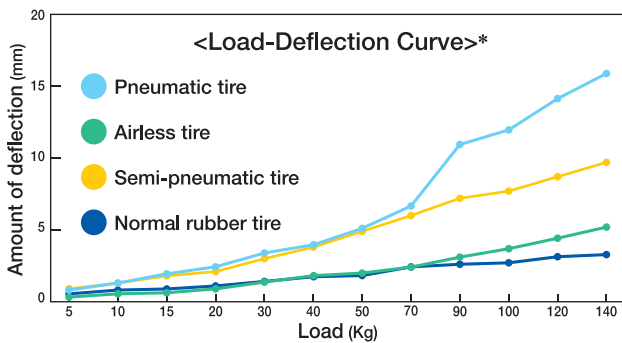

*Deflection is one of the features of rubber tires, which helps to absorb impact forces from the floor.

USE EXAMPLE

- For carriers used on uneven floor and outdoor.
- ©We'll accept your custom-order. Please feel free to contact us.
(Use "Specification Form for Custom-designed castor" at the end of this catalog.)
- ©Please feel free to ask about the product weight for each item.

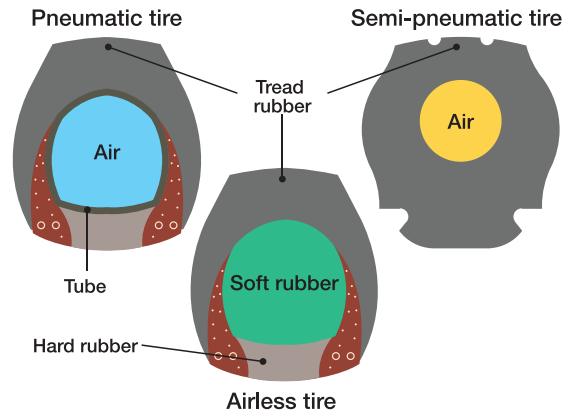

AIJ Swivel castors



| |
|----------------------------------------|
| AIJ-6-2G |
| AIJ-6 ¹ / ₂ ×2-4 |
| AIJ-2.00-4 |
| AIJ-2.50-4 |
| AIJ-3.00-4 |
| AIJ-3.50-5 |

• Color/Finish; Zinc plated

AILJ Swivel with airless tire



| |
|-------------|
| AILJ-2.50-4 |
| AILJ-3.00-4 |
| AILJ-3.50-5 |

AIJB Swivel with stopper



| |
|--------------------------------------------------------|
| AIJB-6-2G |
| AIJB-3.00-4 (with airless tire type is also available) |

SPMJ Swivel with semi-pneumatic tire



| |
|----------|
| SPMJ-150 |
| SPMJ-200 |

• Color/Finish; Zinc plated

SPMJB Swivel with semi-pneumatic tire and stopper



| |
|-----------|
| SPMJB-150 |
| SPMJB-200 |

• Color/Finish; Zinc plated

AIK Fixed castors



| |
|----------------------------------------|
| AIK-6-2G |
| AIK-6 ¹ / ₂ ×2-4 |
| AIK-2.00-4 |
| AIK-2.50-4 |
| AIK-3.00-4 |
| AIK-3.50-5 |

• Color/Finish; Zinc plated

AILK Fixed with airless tire



| |
|-------------|
| AILK-2.50-4 |
| AILK-3.00-4 |
| AILK-3.50-5 |

AIKB Fixed with stopper



| |
|-----------|
| AIKB-6-2G |
|-----------|

SPMK Fixed with semi-pneumatic tire



| |
|----------|
| SPMK-150 |
| SPMK-200 |

• Color/Finish; Zinc plated

SPMKB Fixed with semi-pneumatic tire and stopper



| |
|-----------|
| SPMKB-150 |
| SPMKB-200 |

• Color/Finish; Zinc plated

WHEELS

CB ...Pressed bearing JBB ...Radial ball bearing

See P.62 to P.71 for detailed description.



AI (SBR/Gray) 6-2G <Made in China>

JBB AI (SBR) 6¹/₂×2-4 NB With ribbed pattern (straight line)

CB AI (SBR) 2.00-4/2.50-4/3.00-4/3.50-5 <Made in China> 2.50-4 and 3.00-4 only

CB AIL (SBR/Airless) 2.50-4/3.00-4/3.50-5/4.00-8 (wheel only)

JBB SPM (NR/Semi-pneumatic)