


SK式回転アダプター


●材質：SS(三価クロメートメッキ)

SK-10

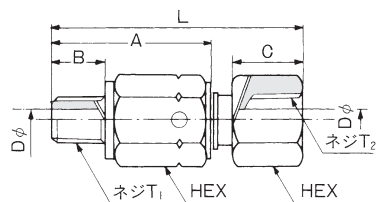

呼び径	ネジT ₁	ネジT ₂	Lmm	Amm	Bmm	Cmm	Dφmm	HEXmm
6	R $\frac{1}{4}$	Rc $\frac{1}{4}$	61	39	13	17	5	19
9	R $\frac{3}{8}$	Rc $\frac{3}{8}$	66	41	15	19	7	22
12	R $\frac{1}{2}$	Rc $\frac{1}{2}$	76	48	18	22	10	27
19	R $\frac{3}{4}$	Rc $\frac{3}{4}$	84	52	20	25	16	36
25	R 1	Rc 1	90	56	22	27	21	41


SK-11

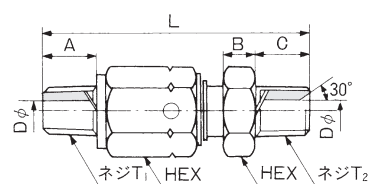RR
RG
GG

呼び径	ネジT ₁	ネジT ₂	Lmm	Amm	Bmm	Cmm	Dφmm	HEXmm
6	G \cdot R $\frac{1}{4}$	G \cdot R $\frac{1}{4}$	65	13	8	13	5	19
9	G \cdot R $\frac{3}{8}$	G \cdot R $\frac{3}{8}$	70	15	8	15	7	22
12	G \cdot R $\frac{1}{2}$	G \cdot R $\frac{1}{2}$	82	18	10	18	10	27
19	G \cdot R $\frac{3}{4}$	G \cdot R $\frac{3}{4}$	91	20	12	20	16	36
25	G \cdot R 1	G \cdot R 1	97	22	12	22	21	41


Rは30° シートなし

SK-12

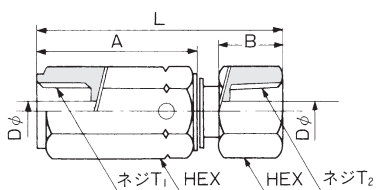


呼び径	ネジT ₁	ネジT ₂	Lmm	Amm	Bmm	Dφmm	HEXmm
6	Rc $\frac{1}{4}$	Rc $\frac{1}{4}$	55	33	17	5	19
9	Rc $\frac{3}{8}$	Rc $\frac{3}{8}$	61	38	19	7	22
12	Rc $\frac{1}{2}$	Rc $\frac{1}{2}$	70	42	22	10	27
19	Rc $\frac{3}{4}$	Rc $\frac{3}{4}$	78	46	25	16	36
25	Rc 1	Rc 1	82	48	27	21	41

SK-13

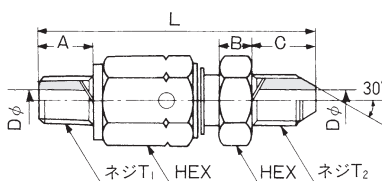


呼び径	ネジT ₁	ネジT ₂	Lmm	Amm	Bmm	Cmm	Dφmm	HEXmm
6	R $\frac{1}{4}$	G $\frac{1}{4}$	68	13	8	16	5	19
9	R $\frac{3}{8}$	G $\frac{3}{8}$	72	15	8	18	7	22
12	R $\frac{1}{2}$	G $\frac{1}{2}$	84	18	10	20	10	27
19	R $\frac{3}{4}$	G $\frac{3}{4}$	92	20	12	22	16	36
25	R 1	G 1	98	22	12	23	21	41

SK-14

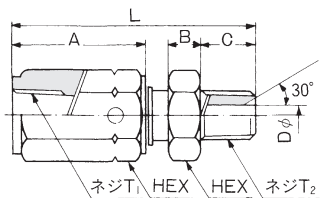

呼び径	ネジT ₁	ネジT ₂	Lmm	Amm	Bmm	Cmm	Dφmm	HEXmm
6	Rc $\frac{1}{4}$	G $\frac{1}{4}$	59	33	8	13	5	19
9	Rc $\frac{3}{8}$	G $\frac{3}{8}$	65	38	8	15	7	22
12	Rc $\frac{1}{2}$	G $\frac{1}{2}$	76	42	10	18	10	27
19	Rc $\frac{3}{4}$	G $\frac{3}{4}$	85	46	12	20	16	36
25	Rc 1	G 1	89	48	12	22	21	41

SK-15

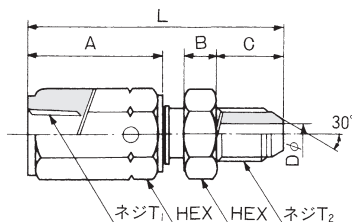

呼び径	ネジT ₁	ネジT ₂	Lmm	Amm	Bmm	Cmm	Dφmm	HEXmm
6	Rc $\frac{1}{4}$	G $\frac{1}{4}$	62	33	8	16	5	19
9	Rc $\frac{3}{8}$	G $\frac{3}{8}$	68	38	8	18	7	22
12	Rc $\frac{1}{2}$	G $\frac{1}{2}$	78	42	10	20	10	27
19	Rc $\frac{3}{4}$	G $\frac{3}{4}$	87	46	12	22	16	36
25	Rc 1	G 1	90	48	12	23	21	41

(注意) 予告なしに、品質・性能・改善のため寸法を変更する事があります。