


SA series

単相 複巻

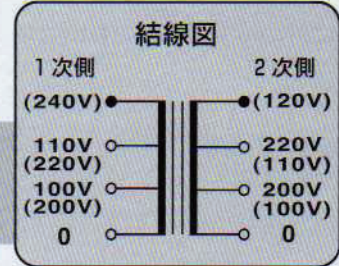

SA12 100・110V - 200・220V

() 内の電圧はSA21です

品番	仕様		端子形状	外形寸法 (mm)			取付寸法 (mm)			取付穴 (mm)		端子ネジ (mm)	絶縁種類	重量	本体価格	
	1次電圧	2次電圧		容量	W	D	H	A	B	C	E					F
○ SA12-30			30VA	UP	77	88	92	55	49	35	4.5×8	4	4	A	約1.3kg	4,700
○ SA12-50			50VA	UP	77	95	92	55	54	35	4.5×8	4	4	A	約1.6kg	5,100
○ SA12-100			100VA	UP	96	102	103	59	60	40	5.5×10	4	4	A	約2.7kg	6,100
○ SA12-200			200VA	UP	108	117	118	75	73	48	6×10	4	4	A	約4.4kg	8,700
○ SA12-300	110V	220V	300VA	UP	128	110	131	97	70	68	6.5×12	5	4	A	約5.3kg	10,700
○ SA12-500			500VA	UP	146	122	145	110	72	76	6.5×12	5	4	E	約7.0kg	14,500
○ SA12-750	100V	200V	750VA	UP	146	150	145	110	92	76	6.5×12	5	4	E	約9.2kg	20,700
○ SA12-1000			1KVA	UP	146	172	145	110	122	76	6.5×12	5	4	E	約12.2kg	22,600
○ SA12-1500	0	0	1.5KVA	UP	180	170	183	120	114		10×20		4	E	約19kg	33,600
○ SA12-2000			2KVA	UP	180	190	183	120	134		10×20		4	E	約22kg	38,500
○ SA12-3000			3KVA	UP	200	190	220	138	144		10×20		5	B	約30kg	51,900
○ SA12-4000			4KVA	UP	250	220	240	170	148		10×20		5	B	約43kg	72,600
○ SA12-5000			5KVA	UP	250	240	240	170	168		10×20		5	B	約50kg	84,700

※「SA12」は旧品番のSA1です。


SA21 200・220・240V - 100・110・120V

○ SA21-30			30VA	UP	76	88	92	55	49	35	4.5×8	4	4	A	約1.3kg	5,500
○ SA21-50			50VA	UP	77	95	92	55	54	35	4.5×8	4	4	A	約1.6kg	5,800
○ SA21-100			100VA	UP	96	102	103	59	60	40	5.5×10	4	4	A	約2.7kg	7,200
○ SA21-200			200VA	UP	108	117	118	75	73	48	6×10	4	4	A	約4.4kg	9,900
○ SA21-300			300VA	UP	128	110	131	97	70	68	6.5×12	5	4	A	約5.3kg	11,300
○ SA21-500	240V	120V	500VA	UP	146	122	145	110	72	76	6.5×12	5	4	E	約7.0kg	17,100
○ SA21-750			750VA	UP	146	160	145	110	102	76	6.5×12	5	4	E	約10kg	21,200
○ SA21-1000	220V	110V	1KVA	UP	146	180	145	110	122	76	6.5×12	5	4	E	約12.2kg	23,700
○ SA21-1500			1.5KVA	UP	180	170	183	120	114		10×20		4	E	約19kg	34,700
○ SA21-2000	200V	100V	2KVA	UP	180	190	183	120	134		10×20		4	E	約22kg	40,500
○ SA21-3000			3KVA	UP	200	190	220	138	144		10×20		5	B	約30kg	53,400
○ SA21-4000	0	0	4KVA	UP	250	220	240	170	148		10×20		5	B	約43kg	77,000
○ SA21-5000			5KVA	UP	250	240	240	170	168		10×20		5	B	約50kg	88,600
○ SA21-6000			6KVA	UP	250	260	270	170	168		10×20		5/8	B	約60kg	144,100
○ SA21-7500			7.5KVA	UP	260	260	370	150	180		11φ		8	B	約65kg	176,000
○ SA21-10K			10KVA	UP	290	280	430	150	190		13φ		8	B	約85kg	204,600

※「SA21」は旧品番のSA2です。

形状・寸法図

UP形 (ねじアップ式端子台)

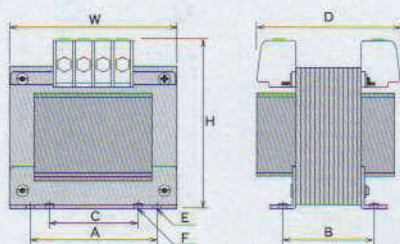

UP形 (ねじアップ式端子台)

