


SH-E series

単相 複巻

静電シールド付



結線図

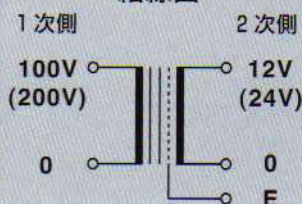

SH1-E 100V-12-24V-E

() 内の電圧はSH2-Eです

品番	仕様			端子形状	外形寸法 (mm)				取付寸法 (mm)			取付穴 (mm)		端子種類	絶縁種類	重量	本体価格
	1次電圧	2次電圧	容量		W	D	H	I	A	B	C	E	F				
○ SH1-1205E	100V 0	12V 0 E	0.5A	BL	51	40	41	70	60			4×6		ラグ	A	約260g	1,700
○ SH1-121E			1A	BL	60	45	51	81	71			4×6		ラグ	A	約440g	1,900
○ SH1-122E			2A	BL	69	55	59	91	80			4.5×6		ラグ	A	約770g	2,400
○ SH1-123E			3A	BL	69	65	59	91	80			4.5×6		ラグ	A	約1.0kg	2,900
○ SH1-125E			5A	UP	86	98	95		57	56	35	5.5×10	4	M4	A	約1.7kg	5,900
○ SH1-1210E			10A	UP	96	102	103		59	60	40	5.5×10	4	M4	A	約3.0kg	7,600
○ SH1-1215E			15A	UP	108	117	118		75	73	48	6×10	4	M4	A	約4.0kg	9,900
○ SH1-1220E			20A	UP	128	100	131		97	60	68	6.5×12	5	M4	A	約5.0kg	11,000
○ SH1-2405E			100V 0	24V 0 E	0.5A	BL	60	45	51	81	71			4×6		ラグ	A
○ SH1-241E	1A	BL			69	55	59	91	80			4.5×6		ラグ	A	約770g	2,400
○ SH1-242E	2A	BL			79	65	67	104	92			4.5×6		ラグ	A	約1.2kg	4,200
○ SH1-243E	3A	UP			86	103	95		57	62	35	5.5×10	4	M4	A	約2.1kg	6,600
○ SH1-245E	5A	UP			96	102	103		59	60	40	5.5×10	4	M4	A	約3.0kg	7,700
○ SH1-2410E	10A	UP			128	100	131		97	60	68	6.5×12	5	M4	A	約5.4kg	11,000
○ SH1-2415E	15A	UP			128	110	131		97	70	68	6.5×12	5	M4	A	約6.0kg	12,700
○ SH1-2420E	20A	UP			146	130	145		110	72	76	6.5×12	5	M4	E	約7.2kg	15,400

SH2-E 200V-12-24V-E

○ SH2-121E	200V 0	12V 0 E	1A	BL	60	45	51	81	71			4×6		ラグ	A	約240g	1,900
○ SH2-122E			2A	BL	69	55	59	91	80			4.5×6		ラグ	A	約770g	2,400
○ SH2-123E			3A	BL	69	65	59	91	80			4.5×6		ラグ	A	約1.0kg	2,900
○ SH2-125E			5A	UP	86	98	95		57	56	35	5.5×10	4	M4	A	約1.7kg	5,900
○ SH2-1210E			10A	UP	96	102	103		59	60	40	5.5×10	4	M4	A	約3.0kg	7,600
○ SH2-1215E			15A	UP	108	117	118		75	73	48	6×10	4	M4	A	約4.0kg	9,900
○ SH2-2405E	200V 0	24V 0 E	0.5A	BL	60	45	51	81	71			4×6		ラグ	A	約440g	1,900
○ SH2-241E			1A	BL	69	55	59	91	80			4.5×6		ラグ	A	約770g	2,400
○ SH2-242E			2A	BL	79	65	68	104	92			4.5×6		ラグ	A	約1.2kg	4,200
○ SH2-243E			3A	UP	86	103	95		57	62	35	5.5×10	4	M4	A	約2.1kg	6,600
○ SH2-245E			5A	UP	96	102	103		59	60	40	5.5×10	4	M4	A	約3.0kg	7,700
○ SH2-248E			8A	UP	108	113	118		75	72	48	6×10	4	M4	A	約4.1kg	9,900
○ SH2-2410E			10A	UP	128	100	131		97	60	68	6.5×12	5	M4	A	約4.4kg	11,000
○ SH2-2415E			15A	UP	128	115	131		97	70	68	6.5×12	5	M4	A	約5.5kg	12,700
○ SH2-2420E			20A	UP	146	127	145		110	72	76	6.5×12	5	M4	E	約7.2kg	15,400

形状・寸法図

BL形 (ラグ端子板)

UP形 (ねじアップ式端子台)

