
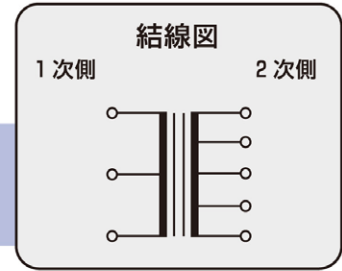


R series

単相 複巻
タップ付

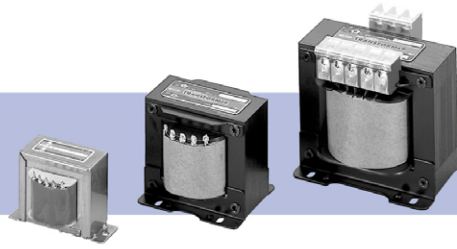

R1 100-110V-5~24V


品番	仕様			端子形状	外形寸法 (mm)				取付寸法 (mm)			取付穴 (mm)		端子	絶縁種類	重量	本体価格
	1次電圧	2次電圧	容量		W	D	H	I	A	B	C	E	F				
◎ R1-631	100V-0	6.3V	1A	BL	51	40	41	70	60				4×6	ラグ	A	約260g	1,500
◎ R1-632	110V 100V	5V	2A	BL	60	45	51	84	71				4×7	ラグ	A	約440g	2,000
◎ R1-633	100V 0	0	3A	BL	69	50	59	91	80				4.5×6	ラグ	A	約740g	2,800
◎ R1-1203	100V 0	12V-10V-0	0.3A	BL	43	36	36	60	51				3.8×4	ラグ	A	約150g	1,400
◎ R1-1205	110V 100V	12V	0.5A	BL	51	40	41	70	60				4×6	ラグ	A	約260g	1,800
◎ R1-121	110V 100V	10V	1A	BL	60	45	51	80	70				4×6	ラグ	A	約450g	2,000
◎ R1-122	100V 0	8V	2A	BL	69	55	59	91	80				4.5×6	ラグ	A	約770g	2,500
◎ R1-123	100V 0	6V	3A	BL	79	65	67	104	92				4.5×8	ラグ	A	約1.2kg	4,000
◎ R1-125	100V 0	0	5A	BL	79	75	67	104	92				4.5×7	ラグ	A	約1.6kg	5,200
◎ R1-2003	110V 100V	20V	0.3A	BL	51	40	41	70	60				4×6	ラグ	A	約260g	1,500
◎ R1-2005	110V 100V	18V	0.5A	BL	60	45	51	80	70				4×6	ラグ	A	約440g	1,900
◎ R1-201	100V 0	16V	1A	BL	69	55	59	91	80				4.5×6	ラグ	A	約770g	2,800
◎ R1-202	100V 0	14V	2A	BL	79	65	67	104	92				4.5×8	ラグ	A	約1.2kg	4,000
◎ R1-203	100V 0	0	3A	BL	79	80	67	104	92				4.5×7	ラグ	A	約1.6kg	4,800
◎ R1-205	110V 100V	0	5A	SS	96	85	82		59	60	40	5.5×10	4	ラグ	A	約2.5kg	7,900
◎ R1-2405	110V 100V	24V	0.5A	BL	60	53	51	84	70				4×6	ラグ	A	約500g	2,600
◎ R1-241	100V 0	20V	1A	BL	69	59	59	91	80				4.5×6	ラグ	A	約900g	2,900
◎ R1-242	100V 0	15V	2A	BL	79	70	67	104	92				4.5×6	ラグ	A	約1.4kg	4,400
◎ R1-243	100V 0	12V	3A	BL	89	77	76	115	102				4×8	ラグ	A	約2.0kg	5,500
◎ R1-245	100V 0	0	5A	SS	96	85	82		59	60	40	5.5×10	4	ラグ	A	約2.5kg	8,100

R1 100-110V-15~50V


◎ R1-3005	110V 100V	30V	0.5A	BL	60	53	51	84	72				4×7	ラグ	A	約500g	2,200
◎ R1-301	100V 0	25V	1A	BL	69	65	60	94	80				4.5×6	ラグ	A	約1.0kg	3,400
◎ R1-302	100V 0	20V	2A	BL	79	75	67	104	92				4.5×7	ラグ	A	約1.6kg	4,700
◎ R1-303	100V 0	15V	3A	SS	96	85	82		59	60	40	5.5×10	4	ラグ	A	約2.5kg	7,500
◎ R1-3805	110V 100V	38V	0.5A	BL	69	55	60	90	80				4.5×6	ラグ	A	約900g	2,900
◎ R1-381	100V 0	35V	1A	BL	79	65	67	104	92				4.5×8	ラグ	A	約1.2kg	4,000
◎ R1-382	100V 0	32V	2A	BL	89	77	76	115	102				4×8	ラグ	A	約2.0kg	5,800
◎ R1-383	100V 0	24V	3A	SS	96	85	82		59	60	40	5.5×10	4	ラグ	A	約2.5kg	8,300
◎ R1-501	110V 100V	50V	1A	BL	79	70	67	104	92				4.5×6	ラグ	A	約1.4kg	4,600
◎ R1-502	100V 0	45V	2A	SS	96	85	82		59	60	48	5.5×10	4	ラグ	A	約2.5kg	7,600
◎ R1-503	100V 0	40V	3A	SS	96	95	82		59	67	48	5.5×10	4	ラグ	A	約2.9kg	8,500

形状・寸法図

BL形 (ラグ端子板)

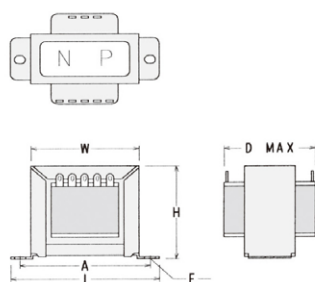

SS形 (ラグ端子板)

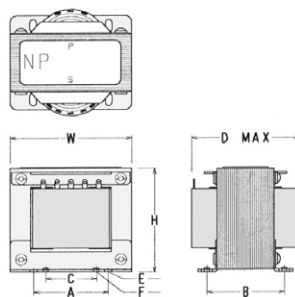

UP形 (ねじアップ式端子台)

