
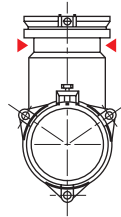


脚部継手

納まり図 ▶P.15
支持方法 ▶P.12,13

SEB エクセルベンド


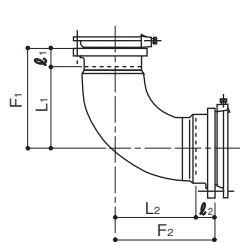


▶◀SEBセッター取付位置

単位：mm

呼び径	記号	F ₁	F ₂	L ₁	L ₂	l ₁	l ₂
100×75		210	193	175	155	35	38
125×100		223	225	185	180	38	45
125×75		205	210	170	165	35	45
150×100		226	234	188	186	38	48

 
SEB-C エクセルベンド掃除口付

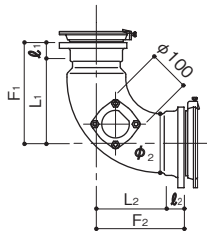

▶◀SEBセッター取付位置

単位：mm



呼び径	記号	F ₁	F ₂	L ₁	L ₂	l ₁	l ₂
100×75		210	193	175	155	35	38
125×75		205	210	170	165	35	45
125×100		223	225	185	180	38	45
150×100		226	234	188	184	38	50

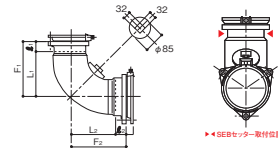

▶◀SEBセッター取付位置

※ 100×75、125×100は上記形状になります。

 SEB-L エクセルロングベンド


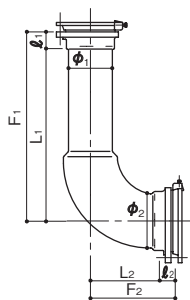


▶◀SEB-Lセッター取付位置

単位：mm

呼び径	記号	F ₁	F ₂	L ₁	L ₂	l ₁	l ₂	φ ₁	φ ₂
100×75		500	194	465	156	35	38	94	129
125×75		500	213	465	168	35	45	94	155
125×100		500	213	462	168	38	45	118	155
150×100		500	234	462	186	38	48	118	183

 SEB-LC エクセルロングベンド掃除口付

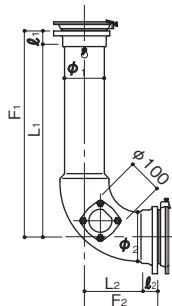

▶◀SEB-Lセッター取付位置

単位：mm

呼び径	記号	F ₁	F ₂	L ₁	L ₂	l ₁	l ₂	φ ₁	φ ₂
100×75		600	193	565	155	35	38	94	128
125×100		600	225	562	180	38	45	119	156
150×100		600	234	562	184	38	50	119	184