 



NOZZLE

200A Insulation Nozzle

038040 20MINI Nozzle 13mm
Bore: ϕ 13



 038041 20MINI Straight Nozzle
Bore: ϕ 16



038042 20MINI Long Nozzle
102 Bore: ϕ 10



 
※Use the nozzle in combination with a long tip

D 350A Nozzle

023012 D Nozzle No.8 12mm
Bore: ϕ 12



023013 D Nozzle No.10 16mm
Bore: ϕ 16



023501 DSRC Nozzle
Bore: ϕ 13



N 350A Nozzle


001002 N Nozzle 16mm
Bore: ϕ 16



001003 N Nozzle 12mm
Bore: ϕ 12



001008 N Nozzle 18mm
73 Bore: ϕ 18

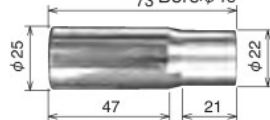

001014 Step Down Nozzle
73 Bore: ϕ 12

 


001004 Small-Diameter Long Nozzle
100 Bore: ϕ 10



※Use the nozzle in combination with a long tip


001007 N 350A Arc Spot Nozzle
Bore: ϕ 20




001009 N Thick Nozzle 16mm
Bore: ϕ 16



 001013 N Nozzle 16mm 63L 350A
Bore: ϕ 16



033203 HR-350Nozzle 16mm
Bore: ϕ 16

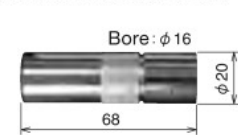

001016 N Small-Diameter Nozzle 73L
73 Bore: ϕ 10



※Use the nozzle in combination with a rocket tip

N 500A Nozzle

 
001001 N Nozzle 19mm 500A
Bore: ϕ 19




001010 N Nozzle 16mm 500A
Bore: ϕ 16




001005 N Nozzle 13mm 500A
Bore: ϕ 13



001012 N Nozzle 19mm 500A 84L
Bore: ϕ 19

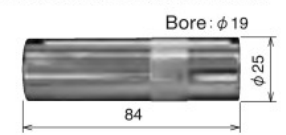

 001015 N Nozzle 16mm 500A 84L
Bore: ϕ 16



Nozzle		Size			Part No.		
Type	Description	ID	OD	Length	Tokin	P Part No.	D Part No.
180A 200A Insulated	CSL-18,20 Nozzle 13mm	13	17	75	038040	TGN01208	U4186L00 U5342N00
	CSL-18,20 Straight Nozzle	16	19	75	038041	TGN01506	U4186P00 U5342P00
	CSL-18, 20 Long Nozzle	10	13	102	038042	TGN01026	U4186R00
N 350A	N Nozzle 16mm	16	20	73	001002	TGN00043	U4167G01
	N Nozzle 12mm	12	16	73	001003	TGN00044	U4167H01
	N Nozzle 18mm	18	25	73	001008	TGN00111	U4167H02
	Step Down Nozzle	12	16	73	001014	TGN00105	-
	N Small-Diameter Long Nozzle	10	13	100	001004	TGN01001	U4167H04
	N 350A Arc Spot Nozzle	20	24	88	001007	TGN02001	U4167H03
	N Thick Nozzle	16	21	73	001009	TGN00038	U4167H16
	N Nozzle 16mm 63L 350A	16	21	63	001013	TGN01663	-
	HR-350Nozzle 16mm/ N Nozzle 16mm 68L	16	20	68	033203	-	-
	N Small-Diameter Nozzle 73L	10	13	73	001016	-	-
D 350A	D Nozzle No.8 12mm	12	16	70	023012	-	U608N01
	D Nozzle No.10 16mm	16	20	70	023013	-	U608N02 U2437J04
	DSRC Nozzle	13	16.8	64	023501	-	L6380F03
N 500A	N Nozzle 19mm 500A	19	25	88	001001	TGN00055	U4173G01
	N Nozzle 16mm 500A	16	22	88	001010	TGN00057	U4173H01
	N Nozzle 13mm 500A	13	19	88	001005	TGN00064	-
	N Nozzle 19mm 500A 84L	19	25	84	001012	TGN00050 TGN00056	-
	N Nozzle 16mm 500A 84L	16	22	84	001015	TGN00058 TGN00065	-