




## テーパシャンクドリル

Taper Shank Drills

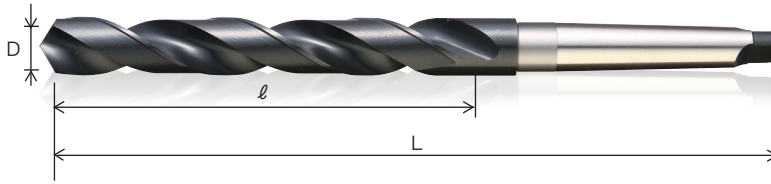

直径許容差:h8  
(JIS B4301参照)

### 特長 Feature

●高品質で低価格

●High quality and low price.

単位: mm

商品コード Item Code	D	ℓ	L	M.T.No.
TC-TD 7.5	7.5	78	158	1
TC-TD 8.0	8.0	82	162	1
TC-TD 8.5	8.5	85	168	1
TC-TD 9.0	9.0	88	172	1
TC-TD 9.5	9.5	92	175	1
TC-TD 10.0	10.0	95	178	1
TC-TD 10.5	10.5	98	182	1
TC-TD 11.0	11.0	102	185	1
TC-TD 11.5	11.5	105	188	1
TC-TD 12.0	12.0	108	192	1
TC-TD 12.5	12.5	112	195	1
TC-TD 13.0	13.0	115	198	1
TC-TD 13.5	13.5	118	202	1
TC-TD 14.0	14.0	122	205	1
TC-TD 14.5	14.5	122	222	2
TC-TD 15.0	15.0	125	225	2
TC-TD 15.5	15.5	128	228	2
TC-TD 16.0	16.0	130	230	2
TC-TD 16.5	16.5	132	232	2
TC-TD 17.0	17.0	135	235	2
TC-TD 17.5	17.5	140	240	2
TC-TD 18.0	18.0	140	240	2
TC-TD 18.5	18.5	145	245	2
TC-TD 19.0	19.0	145	245	2
TC-TD 19.5	19.5	150	250	2
TC-TD 20.0	20.0	150	250	2
TC-TD 20.5	20.5	155	255	2
TC-TD 21.0	21.0	155	255	2
TC-TD 21.5	21.5	160	260	2
TC-TD 22.0	22.0	160	260	2
TC-TD 22.5	22.5	165	265	2
TC-TD 23.0	23.0	165	265	2
TC-TD 23.5	23.5	165	285	3
TC-TD 24.0	24.0	165	285	3
TC-TD 24.5	24.5	165	285	3
TC-TD 25.0	25.0	165	285	3
TC-TD 25.5	25.5	165	285	3
TC-TD 26.0	26.0	165	285	3
TC-TD 26.5	26.5	170	290	3
TC-TD 27.0	27.0	170	290	3