


## Foam Sun Braid Hose

A hose for cooling water used for printing or molding machines. The foamed materials keep away waterdrops from the hose surface.

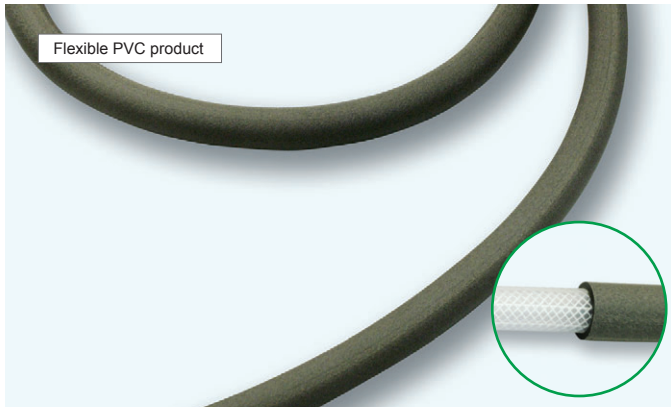


Flexible PVC product

Specifications: Working temperature limit: Between -5°C and + 60°C

Nominal designation	Inner diameter (mm)	Outer diameter (mm)	Regular size (m)	Maximum working pressure (MPa at 20°C)	Burst pressure (MPa at 20°C)	Minimum bending radius (mm)	Weight (kg/m)	Regular size weight (kg)
FB-12	12.0	24.0	50	1.0	5.0	48	0.433	21.7
FB-15	15.0	29.0	50	0.8	4.0	60	0.612	30.6
FB-19	19.0	32.0	50	0.7	3.8	76	0.671	33.6

[Structure]

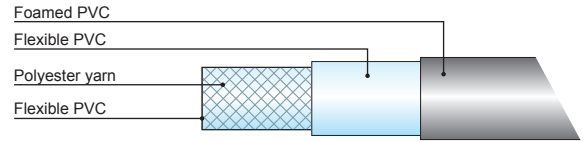


**Use** For the cooling water used for printing or molding machine (for condensation prevention).

**Features** The foamed materials keep away waterdrops from the hose surface.

**Fluids** Water

## Super Air Hose

Lighter than rubber hoses and superior in workability. Withstanding to direct sunlight and blocking cracks.

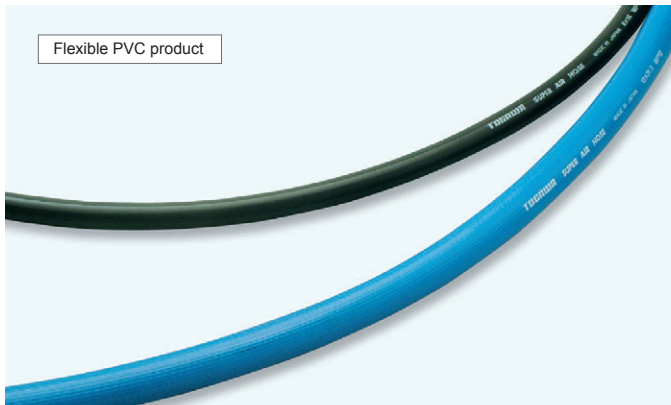


Flexible PVC product

Specifications: Working temperature limit: Between -5°C and + 60°C

Nominal designation	Inner diameter (mm)	Outer diameter (mm)	Regular size (m)	Maximum working pressure (MPa at 20°C)	Burst pressure (MPa at 20°C)	Minimum bending radius (mm)	Weight (kg/m)	Regular size weight (kg)	Lines
SA-6	6.5	13.0	100	1.0	9.0	32.5	0.120	12	●●
SA-7	7.0	13.5	100	1.0	8.5	35	0.125	12.5	●—
SA-8	8.0	15.0	100	1.0	8.5	40	0.150	15	●●
SA-9	9.5	16.5	100	1.0	8.0	47.5	0.170	17	●●
SA-12	13.0	21.5	100	1.0	7.5	65	0.280	28	●●
SA-19	19.0	27.5	100	1.0	5.0	95	0.390	39	—●
SA-25	25.0	34.5	100	1.0	4.7	125	0.550	55	—●

[Structure]

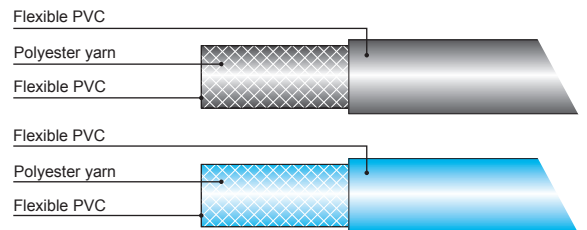


**Use** For compressors, car maintenance, sheet metal and paint works, quarrying etc.

**Features** Lighter than rubber hoses and superior in workability.

**Fluids** Air

## Super Water Hose

Appropriate for washing and sprinkling water on vessels, gas stations, factories, farmlands, golf courses etc.

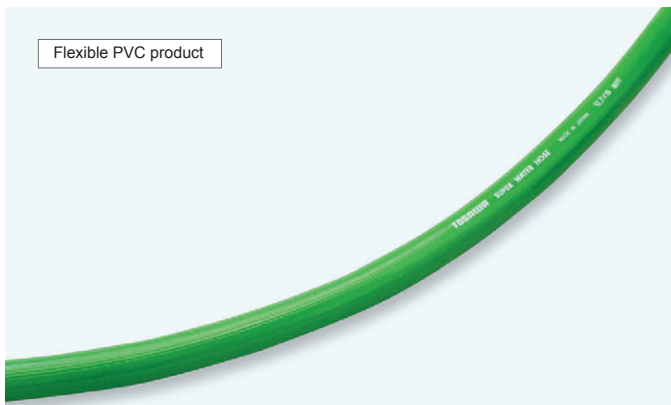

Flexible PVC product

Specifications: Working temperature limit: Between -5°C and + 60°C

Nominal designation	Inner diameter (mm)	Outer diameter (mm)	Regular size (m)	Maximum working pressure (MPa at 20°C)	Burst pressure (MPa at 20°C)	Minimum bending radius (mm)	Weight (kg/m)	Regular size weight (kg)	Lines
SW-12	12.7	19.0	100	0.7	4.0	63.5	0.195	19.5	●
SW-15	15.0	22.5	100	0.7	4.0	75	0.255	25.5	●
SW-19	19.0	27.0	100	0.7	3.0	95	0.380	38	●
SW-25	25.0	33.5	100	0.7	3.0	125	0.480	48	●
SW-32	32.0	43.0	60	0.5	2.0	160	0.800	48	●
SW-38	38.0	50.0	60	0.5	2.0	190	1.020	61.2	●

[Structure]



**Use** Washing and sprinkling water on vessels, factories, farmlands, golf courses, engineering sites, etc.

**Features** Lighter than rubber hoses and superior in workability.

**Fluids** Water