

Transparent Vinyl Tube

From small to large, variety of sizes are available to fit your usage.



Use For piping at factories, sprinkling water for farmlands and gardening.

Features From small to large, variety of sizes are available to fit your usage.

Fluids Air Water

Specifications:
Working temperature limit: Between -5°C and +60°C

Nominal designation	Inner diameter (mm)	Regular size (m)	Packages (number of pieces)
TV-3×5	3.0	200	Five drums/case
TV-4×6	4.0	200	◇
TV-5×7	5.0	200	◇
TV-5×8	5.0	200	◇
TV-6×8	6.0	200	◇
TV-6×9	6.0	200	Four drums/case
TV-6×10	6.0	100	Five drums/case
TV-7×9	7.0	200	Four drums/case
TV-7×10	7.0	100	Five drums/case
TV-7×11	7.0	100	◇
TV-8×10	8.0	100	◇
TV-8×11	8.0	100	◇
TV-8×12	8.0	100	Four drums/case
TV-9×11	9.0	100	Five drums/case
TV-9×12	9.0	100	Four drums/case
TV-9×13	9.0	100	◇
TV-10×12	10.0	100	◇
TV-10×13	10.0	100	◇
TV-10×14	10.0	50	Five drums/case
TV-12×14	12.0	50	◇

Specifications:
Working temperature limit: Between -5°C and +60°C

Nominal designation	Inner diameter (mm)	Regular size (m)	Packages (number of pieces)
TV-12×15	12.0	50	◇
TV-12×16	12.0	50	Four drums/case
TV-15×17	15.0	50	◇
TV-15×18	15.0	50	◇
TV-18×21	18.0	50	Three drums/case
TV-18×22	18.0	50	◇
TV-19×23	19.0	50	◇
TV-19×25	19.0	50	Rings
TV-22×26	22.0	50	◇
TV-25×29	25.0	50	◇
TV-25×30	25.0	50	◇
TV-25×31	25.0	50	◇
TV-32×37	32.0	50	◇
TV-32×38	32.0	50	◇
TV-38×44	38.0	50	◇
TV-45×51	45.0	30	◇
TV-50×58	50.0	30	◇
TV-63×73	63.0	30	◇
TV-75×86	75.0	30	◇
TV-90×104	90.0	20	◇

Super Tom Fusso Tube

The super soft fusso tube with the excellent non-adhesive, low leachability and chemical resistance.



 
Use For piping of paints, solvents, chemicals, drinking water and foods

Features Excellent solvent and chemical resistance and low leachability.

Fluids Paints Solvents Chemicals Various foods

Specifications: Working temperature limit: Between -40°C and +80°C

Nominal designation	Inner diameter (mm)	Outer diameter (mm)	Regular size (m)	Maximum working pressure (MPa at 20°C)	Minimum bending radius (mm)	Weight (kg/m)
FST-4	4.0	6.0	20-100	0.9	17	19
FST-6	6.0	9.0	20-100	0.7	26	41
FST-8	8.0	12.0	20-100	0.7	46	72




Features

- A multipurpose tube with excellent chemical resistance and low permeability against the organic solvent. Also has high transparency and flexibility.

Super Tom Fusso-easy Hose

The super soft fusso hose with a conductive resin line.

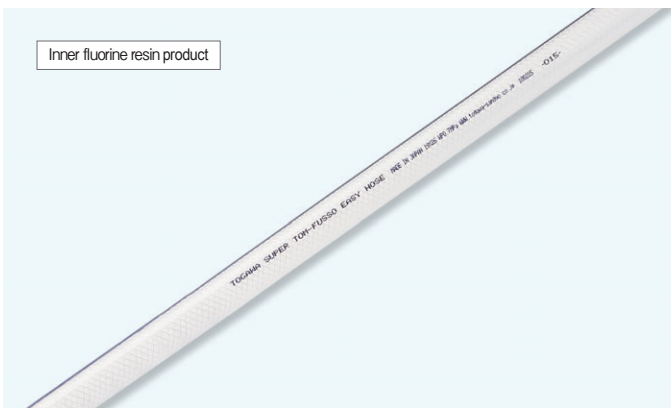


Use For piping of paints, solvents, chemicals, drinking water and foods.

Features Excellent solvent and chemical resistance and low leachability.

Fluids Paints Solvents Chemicals Various foods

Specifications: Working temperature limit: Between -20°C and +60°C

Nominal designation	Inner diameter (mm)	Outer diameter (mm)	Regular size (m)	Maximum working pressure (MPa at 20°C)	Minimum bending radius (mm)	Weight (kg/m)	Regular size weight (kg)
FE-9	9.0	15.0	20	1.1	45	0.141	2.8
FE-12	12.0	18.0	20	1.0	60	0.177	3.5
FE-15	15.0	22.0	20	0.8	75	0.253	5.1
FE-19	19.0	26.0	20	0.7	95	0.308	6.2
FE-25	25.0	33.0	20	0.6	125	0.451	9.0

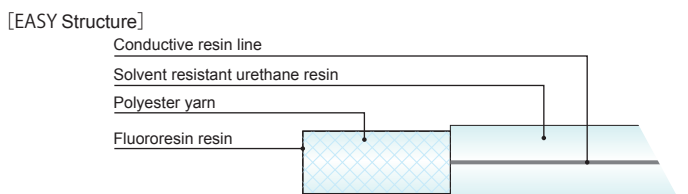

Features

A versatile chemical hose is now available!

- As a conductive sleeve is applied around the outer layer, the grounding can be completed just by tightening the metallic joint (when the resistance value is "9× 10⁶W" or less, and the whole length is 15m or less).