



For Air Tools Air tool Hose

A series of air hoses that support maximum working pressure of each application. The hoses can be used for various air tools, spray paint, and air piping at factories with a variety of different colors for color coding.

Polyurethane Hose (TPH)

Appropriate for air tools (air-tucker, pegger machine, and impact wrench), paint, spray, in-factory air tools.



Polyurethane product

Specifications: Working temperature limit: Between -40°C and +60°C

Nominal designation	Inner diameter (mm)	Outer diameter (mm)	Regular size (m)	Maximum working pressure MPa at 20°C	Burst pressure MPa at 20°C	Minimum bending radius (mm)	Weight (kg/m)	Regular size weight (kg)	Delivery unit	Color
TPH-6510	6.5	10.0	100	1.5	7.2	30	0.057	5.7	1	●●●
TPH-8512	8.5	12.5	100	1.5	7.6	40	0.083	8.3	1	●●●
TPH-1116	11.0	16.0	50	1.5	8.0	45	0.128	6.5	1	●

Performance evaluation

Descriptions	Evaluation	Descriptions	Evaluation
Lightness	★ ★ ★ ★ ★	Smoothness	★ ★ ★
Softness	★ ★ ★	Spattering resistance	★ ★

* All the evaluations were made in-house
* Use our specified brackets


Usege For air-paint, air-spray, and in-factory air tools

Features With flexibility and light weight, this hose is appropriate for construction sites.

Fluids  Air

Super Win Soft Hose II

With further softness and smoothness, this hose is free from winding or hopping.

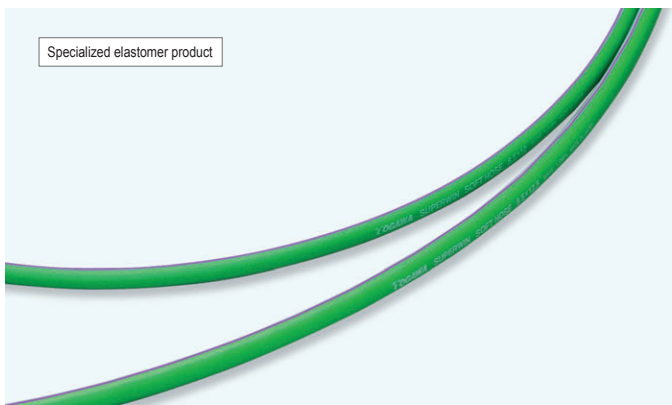

Specialized elastomer product

Specifications: Working temperature limit: Between -5°C and +60°C

Nominal designation	Inner diameter (mm)	Outer diameter (mm)	Regular size (m)	Maximum working pressure MPa at 20°C	Burst pressure MPa at 20°C	Minimum bending radius (mm)	Weight (kg/m)	Regular size weight (kg)
SWH-6510	6.5	10.0	100	1.5	6.0	20	0.058	5.8
SWH-8512	8.5	12.5	100	1.5	6.0	40	0.083	8.3

Performance evaluation

Descriptions	Evaluation	Descriptions	Evaluation
Lightness	★ ★ ★ ★ ★	Smoothness	★ ★ ★ ★ ★
Softness	★ ★ ★ ★ ★	Spattering resistance	★ ★ ★

* All the evaluations were made in-house
* Use our specified brackets

Without the winding or hopping, this hose is easy to carry and improves the workability.

