







## Sun Tech Air Hose


A convenient and affordable air hose combined with a pair of couplers. The hose is available in a variety of different colors.

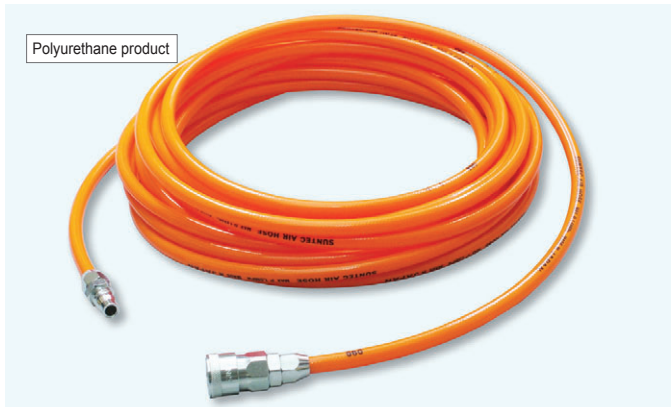

- Usege** For air-paint, air-spray, and in-factory air tools
- Features** A convenient and affordable air hose with a pair of couplers. Available in a variety of different colors as orange, green, and yellow.
- Fluids**  Air

Specifications: Working temperature limit: Between -40°C and + 60°C


Nominal designation	Inner diameter (mm)	Outer diameter (mm)	Regular size (m)	Maximum working pressure MPa at 20°C	Burst pressure MPa at 20°C	Minimum bending radius (mm)	Brackets used	Delivery unit	Color
STC-7010	7.0	10.0	10	1.5	6.0	40	Two-touch coupler	10	
STC-7020	7.0	10.0	20	1.5	6.0	40		10	
STC-7030	7.0	10.0	30	1.5	6.0	40		10	
STC-7100	7.0	10.0	100	1.5	6.0	40	—	—	

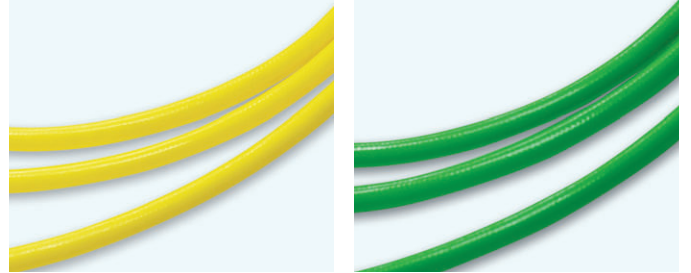

## Takumi Air Hose

Characterized by the extraordinary flexibility of the special resin. You may feel as if no hose is attached.



- Usege** For air-paint, air-spray, and in-factory air tools
- Features** Characterized by the extraordinary light weight with the aluminum couplers.
- Fluids**  Air

Specifications: Working temperature limit: Between -5°C and + 60°C

Nominal designation	Inner diameter (mm)	Outer diameter (mm)	Regular size (m)	Maximum working pressure MPa at 20°C	Burst pressure MPa at 20°C	Minimum bending radius (mm)	Brackets used	Delivery Unit
TAC-6510	6.5	10.0	10	1.5	4.0	20	One-touch aluminum coupler	10
TAC-6520	6.5	10.0	20	1.5	4.0	20		10
TAC-6530	6.5	10.0	30	1.5	4.0	20		10
TAC-6100	6.5	10.0	100	1.5	4.0	20	—	—





### Super flexible hose with light weight coupler!

This hose can be used in a wide variety of applications such as pegger machines, air-tuckers, and air-spray guns. This hose may be well praised even by professional skilled workers. The couplers, made of aluminum, are characterized by the light weight, resistance to damages, and increased removability and operability. In addition, the couplers are superior in versatility which can be used for a variety of applications ranging from in-factory air piping to hose connection with air tools.

## Quattro Hose

The high pressure hose of super flexibility and smoothness which can support up to 4MPa maximum operating pressure.

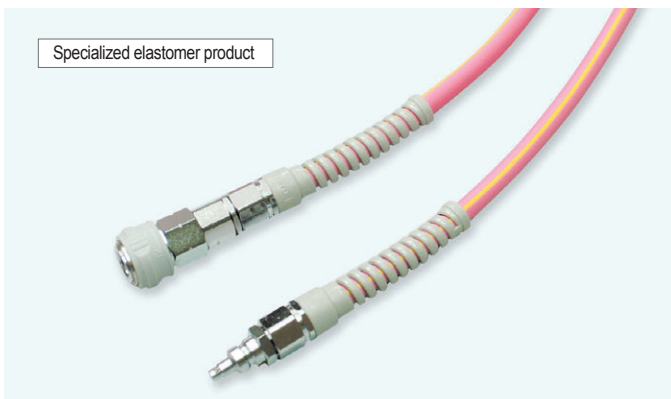

- Usege** For air tools (pegger machines and air-tuckers) and in-factory air tools.
- Features** A high pressure hose that supports up to 4MPa maximum operating pressure and significantly shorten the work hours. With the new proprietary special material, this hose cannot get stuck or kinked easily.
- Fluids**  Air

Specifications: Working temperature limit: Between -5°C and + 60°C

Nominal designation	Inner diameter (mm)	Outer diameter (mm)	Regular size (m)	Maximum working pressure MPa at 20°C	Burst pressure MPa at 20°C	Minimum bending radius (mm)	Brackets used	Delivery Unit
QHC-6010	6.0	10.0	10	4.0	16.0	18	One-touch aluminum coupler	10
QHC-6020	6.0	10.0	20	4.0	16.0	18		10
QHC-6030	6.0	10.0	30	4.0	16.0	18		10

### Performance evaluation

Descriptions	Evaluation	Descriptions	Evaluation
Lightness	☆☆☆☆☆	Smoothness	☆☆☆☆☆
Softness	☆☆☆☆	Spattering resistance	☆☆☆☆☆

\* All the evaluations were made in-house  
\* Use our specified brackets