



SILICONE BELT HEATER

シリコンベルトヒーター

It can accommodate complex shapes such as pipes, valves, and pumps.
It can be easily heated and kept warm.



Made in Japan


Heat Resistant
200°C/392°F

RoHS2
Compliance

Silicone-belt heater

Please feel free to ask us for prices and other specifications.

Regular Type

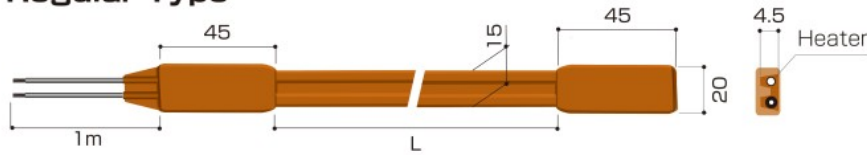

● Voltage / 100V


Selection Standard

Product code	Wattage	L(m)
SB100- 10-1000	10	1m
SB100- 20-1000	20	
SB100- 30-1000	30	

Product code	Wattage	L(m)
SB100- 40-1000	40	1m
SB100- 50-1000	50	
SB100- 90-3000	90	3m

Product code	Wattage	L(m)
SB100-150-3000	150	3m
SB100-150-5000	150	5m
SB100-250-5000	250	

Slim Type

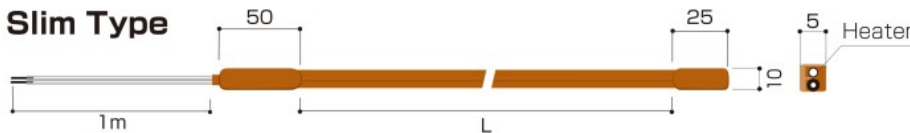

● Voltage / 100V


Selection Standard

Product code	Wattage	L(m)
SBS100- 10-1000	10	1m
SBS100- 20-1000	20	
SBS100- 30-1000	30	

Product code	Wattage	L(m)
SBS100- 40-1000	40	1m
SBS100- 50-1000	50	
SBS100- 90-3000	90	3m

Product code	Wattage	L(m)
SBS100-150-3000	150	3m
SBS100-150-5000	150	5m
SBS100-250-5000	250	

Wide Type

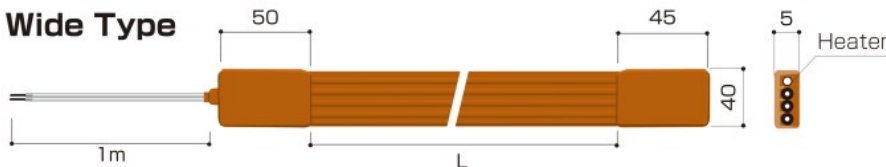

● Voltage / 100V

Selection Standard

Product code	Wattage	L(m)
SBW100- 20-1000	20	1m
SBW100- 40-1000	40	

Product code	Wattage	L(m)
SBW100- 60-1000	60	1m
SBW100- 80-1000	80	

Product code	Wattage	L(m)
SBW100-100-1000	100	1m



株式会社スリーハイ
THREE HIGH CO.,LTD.

Web: www.threehigh.com
Mail: info_overseas@threehigh.co.jp

Headquarters/Factory 4-42-16 Higashiyamata, Tsuzuki Ward, Yokohama City, Kanagawa 224-0023 JAPAN
TEL: +81-45-590-5561 FAX: +81-45-590-5571

