


接头型号 End Fitting List

TF-20000

型式略称 : NW
Code Address

法兰型 非焊接接合
Non Welded Flange Type

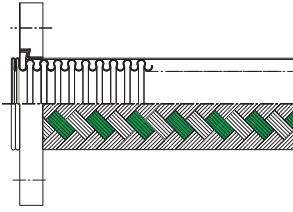

- 构造: 软管非焊接接合的法兰型
- 特长: 优秀的吸收振动能力
- 通径: 20A~300A
- 接头材质: 法兰 碳钢·不锈钢

Construction: Non welded flange type
Features: Excellent absorption of vibration
Nominal dia.: 20A~300A
Fitting materials: Flange Carbon Steel, Stainless steel

 
使用软管
Tubes

Ω型环形软管
Tuf Omega Tube

TF-1600

型式略称 : MT
Code Address

锥管螺纹型 非焊接型接合
Non Welded Screw Type



- 构造: 非焊接型软管接合
- 特长: 小型的锥管螺纹
- 通径: 8A~25A
- 接头材质: 法兰 碳钢·不锈钢

Construction: Flange nut is connected with tube without welding.

Features: Compact design, screw type
Nominal dia.: 8A~25A
Fitting materials: Flange Carbon Steel, Stainless steel

使用软管
Tubes


优秀螺旋软管
Excellent Tube

柔软螺旋软管
Soft Tube

TF-1800

型式略称 : Super UNW
Code Address

锥管螺纹型 非焊接型接合
Non Welded Screw Type

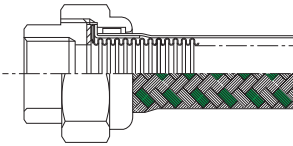

- 构造: 软管不焊接的由任型号
- 特长: 不焊接, 优秀的振动吸收能力
- 通径: 15A~50A
- 接头材质: FCMB (由任接头)

Construction: Non welded, union type.
Features: Non welded, excellent absorption of vibration
Nominal dia.: 15A~50A
Fitting materials: FCMB (Union)


使用软管
Tubes

超柔软环形管
Super Annular

TF-1100

型式略称 : SSE·SUSE·EF (R式)
Code Address

锥管螺纹型 焊接型接合
Screw Welded Type

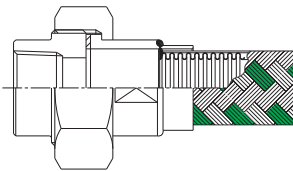

- 构造: 由任接头与管焊接。
- 特长: SUSE的接液部耐腐蚀性优越。
- 通径: 10A~50A
- 接头材质: SSE : 碳钢
SUSE : 不锈钢
EF (R式) : FCMB

※其他的由任接头也能焊接, 请联系。

Construction: Union fitting is welded to tube
Features: As wetted part is stainless steel, it is good corrosion resistance.

Nominal dia.: 10A~50A
Fitting materials: SSE Carbon steel
SUSE Stainless steel
EF (R-type) FCMB

* Other union welding type are available. Please contact us.

使用软管
Tubes

Ω型环形软管
Tuf Omega Tube

超柔软环形管
Super Annular

超薄柔软环形管
Super Bellow

优秀螺旋软管
Excellent Tube

柔软螺旋软管
Soft Tube

 
3层超耐压柔软螺旋管
UFO Flex BOA-DUO

2层超柔软螺旋管
Ultra Soft Flex

TF-7000

型式略称 : SSNM·SSNF·SUSSNM·SUSSNF
Code Address

锥管螺纹型 焊接型接合
Screw Welded Type



- 构造: 螺帽接头与软管焊接。
- 特长: 用扳手把螺母夹紧, 能够容易与配管安装和拆卸。
- 通径: 8A~50A
- 接头材质: SSNM·SSNF : 碳钢
SUSSNM·SUSSNF : 不锈钢
- 锥管螺纹: M : 螺纹管接头 R
F : 螺纹管插座 Rc

Construction: Female unit fitting tube is butt welded to tube.

Features: Female nut can be easily fastened with wrench.

Nominal dia.: 8A~50A
Fitting materials: SSNM·SSNF : Carbon steel
SUSSNM·SUSSNF : Stainless Steel

Fitting screw: M : Male Nipple R
F : Female Socket Rc

使用软管
Tubes

Ω型环形软管
Tuf Omega Tube

超柔软环形管
Super Annular

超薄柔软环形管
Super Bellow

优秀螺旋软管
Excellent Tube

柔软螺旋软管
Soft Tube

3层超耐压柔软螺旋管
UFO Flex BOA-DUO

2层超柔软螺旋管
Ultra Soft Flex