
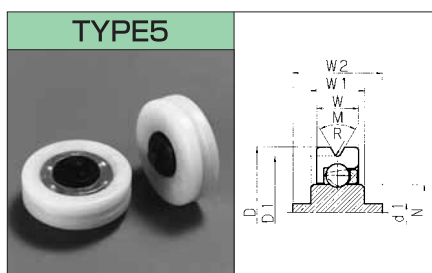
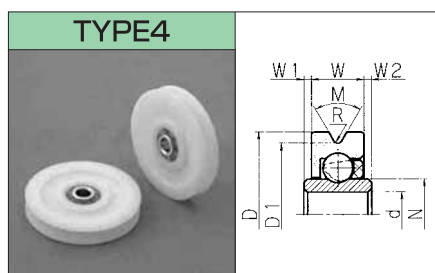
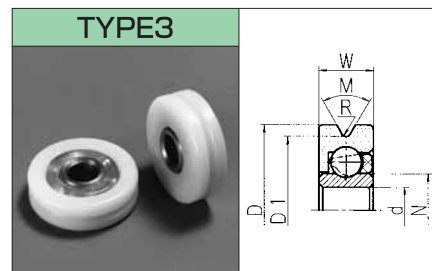
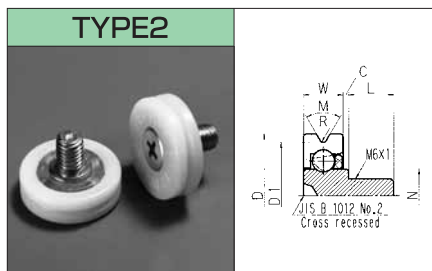


DV (外輪V溝タイプ) RoHS

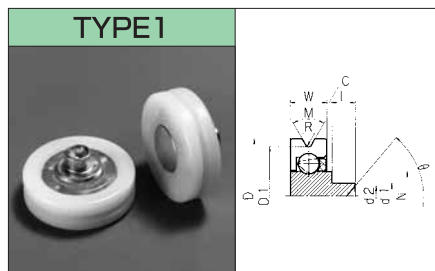

Code	Part No.	D ^{±0.2} [mm]	D1 ^{±0.2} [mm]	d ^{+0.1} [mm]	d1 ^{-0.1} [mm]	W ^{-0.2} [mm]	C ^{±0.4} [mm]	L ^{±0.2} [mm]	*1 (d2 × θ)	W1 ^{*1} [mm]	W2 ^{*1} [mm]	M°	R	N [mm]	Type	Q'ty [pcs/box]	Gross Weight [kg/box]
090000	DV-19-A0.5	19	17	—	5	6	0.5	3.5	φ4 × 120°	—	—	60	0.6	(8.2)	1	2,000	11.0
090100	DV-22-A1	22	19	—	5	7	1	3.5	φ4.4 × 90°	—	—	60	0.6	(9.5)	1	1,000	9.2
090200	DV-24-A1	24	21	—	5	7	1	3.5	φ4.4 × 90°	—	—	60	0.6	(9.5)	1	1,000	9.8
090300	DV-26-A1	26	23	—	5	7	1	3.5	φ4.4 × 90°	—	—	60	0.6	(9.5)	1	1,000	10.6
090400	DV-28-A1	28	24	—	5	7	1	3.5	φ4.4 × 90°	—	—	60	0.6	(9.5)	1	500	5.3
090500	DV-30-A1	30	27	—	5	7	1	3.5	φ4.4 × 90°	—	—	60	0.6	(9.5)	1	500	6.5
090600	DV-38-A0.5	38	35	—	5	8 ^{±0.2}	0.5	3.5	φ4.4 × 90°	—	—	60	0.6	(9.5)	1	500	7.5
091000	DV-19-B0.5	19	17	—	—	6	0.5	8 ^{±0.5}	—	—	—	60	0.6	(8.2)	2	2,000	12.6
091100	DV-22-B0.5	22	19	—	—	7	0.5	8 ^{±0.5}	—	—	—	60	0.6	(9.5)	2	1,000	10.0
091200	DV-24-B0.5	24	21	—	—	7	0.5	8 ^{±0.5}	—	—	—	60	0.6	(9.5)	2	1,000	10.6
091201	DV-24-B3	24	21	—	—	7	3	8 ^{±0.5}	—	—	—	60	0.6	(9.5)	2	1,000	10.7
091300	DV-26-B0.5	26	23	—	—	7	0.5	8 ^{±0.5}	—	—	—	60	0.6	(9.5)	2	1,000	11.2
091500	DV-30-B0.5-0.5R	30	28	—	—	7	0.5	8 ^{±0.5}	—	—	—	90	0.5	(9.5)	2	500	8.0
091501	DV-32.5-B1.5-2R	32.5	20.5	—	—	9.5 ^{±0.2}	1.5	8 ^{±0.5}	—	—	—	15	2	(9.5)	2	400	6.6
091600	DV-38-B0.5	38	35	—	—	8 ^{±0.2}	0.5	8 ^{±0.5}	—	—	—	60	0.6	(9.5)	2	250	5.8
092001	DV-19-H5	19	17	5	—	6	—	—	—	—	—	60	0.6	(8.2)	3	2,500	10.0
092100	DV-22-H6-M	22	19	6	—	7	—	—	—	—	—	60	0.6	(9.5)	3	1,500	9.7
092200	DV-24-H6	24	21	6	—	7	—	—	—	—	—	60	0.6	(9.5)	3	1,000	7.4
092201	DV-24-H8	24	20 ^{±1}	8	—	7	—	—	—	—	—	30	0.6	(11.0)	3	1,000	5.6
092300	DV-26-H6	26	23	6	—	7	—	—	—	—	—	60	0.6	(9.5)	3	1,000	8.0
092500	DV-30-H6	30	27	6	—	7	—	—	—	—	—	60	0.6	(9.5)	3	500	6.8
092700	DV-48-H6W0.4-1.6R	48.3	35	6	—	8.2 ^{±0.2}	—	—	—	0.4	0.4	30	1.6	(9.5)	4	250	4.1
090102	DV-22-AW0.5-B	22 ^{-0.1}	19 ^{±0.1}	—	3	7	—	—	—	8	12	60	0.65	(9.5)	5	1,000	8.9

*1 参考値 Reference Dimension

*2 上記以外のサイズ・形状につきましては、弊社までご相談ください。Each limiting size can be changed for practical application. Please ask our engineer for further information.

※上記は受注生産品です。 These products manufactured to order.