


Prices displayed include 8% tax.

TRUSCO Stock 38,650 Items


L Type Clamp



- Features
- Most suitable for sheet metal processing.
 - Tightening is smooth by employing steel T handle.
- Materials
- Medium Carbon Steel (S45C)
- Origin
- Taiwan

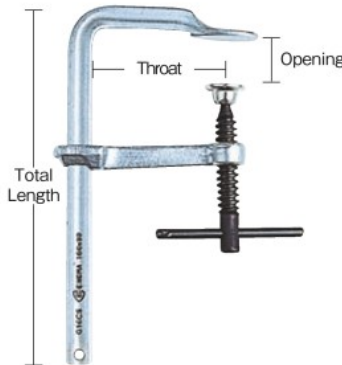

G-16CS

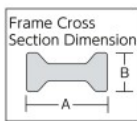

Throat 50mm

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Max Opening (mm)	Throat (mm)	Frame Dimension (mm)		SPQ (piece)	Weight (kg)
							A	B		
445-4499	G-10CS	¥1,545	¥1,670	151	100	50	11.5	5.7	10	0.19
856-6688	G-20CS5	¥1,954	¥2,110	251	200	50	11.5	5.7	10	0.23
856-6692	G-25CS5	¥2,074	¥2,240	301	250	50	11.5	5.7	10	0.26
856-6701	G-30CS5	¥2,203	¥2,380	351	300	50	11.5	5.7	10	0.28

Throat 60mm

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Max Opening (mm)	Throat (mm)	Frame Dimension (mm)		SPQ (piece)	Weight (kg)
							A	B		
445-4511	G-12CS	¥1,926	¥2,080	181	120	60	13.5	6.5	10	0.28
856-6689	G-20CS6	¥2,286	¥2,470	261	200	60	13.5	6.5	10	0.33
856-6693	G-25CS6	¥2,398	¥2,590	311	250	60	13.5	6.5	10	0.37
856-6702	G-30CS6	¥2,564	¥2,770	361	300	60	13.5	6.5	10	0.40

Throat 80mm

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Max Opening (mm)	Throat (mm)	Frame Dimension (mm)		SPQ (piece)	Weight (kg)
							A	B		
162-1017	G-16CS	¥2,407	¥2,600	225	160	80	16.0	7.5	10	0.50
856-6690	G-20CS8	¥2,667	¥2,880	265	200	80	16.0	7.5	10	0.53
856-6694	G-25CS8	¥2,796	¥3,020	315	250	80	16.0	7.5	10	0.57
856-6703	G-30CS8	¥2,971	¥3,210	365	300	80	16.0	7.5	10	0.62
856-6707	G-40CS8	¥3,258	¥3,520	465	400	80	16.0	7.5	10	0.70

Throat 100mm

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Max Opening (mm)	Throat (mm)	Frame Dimension (mm)		SPQ (piece)	Weight (kg)
							A	B		
162-1025	G-20CS	¥3,036	¥3,280	278	200	100	19.5	9.5	10	0.88
856-6691	G-25CS10	¥3,619	¥3,910	330	250	100	19.5	9.5	10	0.94
856-6699	G-30CS10	¥3,870	¥4,180	380	300	100	19.5	9.5	10	1.00
856-6705	G-40CS10	¥4,258	¥4,600	480	400	100	19.5	9.5	10	1.13
856-6708	G-50CS10	¥4,638	¥5,010	580	500	100	19.5	9.5	10	1.26

Throat 120mm, 140mm

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Max Opening (mm)	Throat (mm)	Frame Dimension (mm)		SPQ (piece)	Weight (kg)
							A	B		
162-1033	G-25CS	¥3,795	¥4,100	337	250	120	22.0	10.5	10	1.23
856-6700	G-30CS12	¥4,267	¥4,610	387	300	120	22.0	10.5	10	1.32
856-6706	G-40CS12	¥4,730	¥5,110	487	400	120	22.0	10.5	10	1.48
856-6709	G-50CS12	¥5,156	¥5,570	587	500	120	22.0	10.5	10	1.65
856-6711	G-60CS12	¥5,573	¥6,020	687	600	120	22.0	10.5	10	1.80
856-6712	G-80CS12	¥6,332	¥6,840	887	800	120	22.0	10.5	6	2.13
856-6687	G-100CS12	¥7,091	¥7,660	1087	1000	120	22.0	10.5	6	2.45
856-6735	SG-30CS	¥5,008	¥5,410	396	300	120	25.0	12.0	10	1.76
856-6737	SG-40CS	¥5,573	¥6,020	496	400	120	25.0	12.0	10	1.97
856-6738	SG-50CS	¥6,045	¥6,530	596	500	120	25.0	12.0	10	2.18
856-6740	SG-60CS	¥6,545	¥7,070	696	600	120	25.0	12.0	10	2.39
856-6741	SG-80CS	¥8,239	¥8,900	900	800	120	27.0	13.0	6	3.27
856-6731	SG-100CS	¥9,276	¥10,020	1100	1000	120	27.0	13.0	6	3.75
856-6732	SG-125CS	¥11,589	¥12,520	1350	1250	120	27.0	13.0	4	4.38
856-6734	SG-150CS	¥12,997	¥14,040	1600	1500	120	27.0	13.0	4	4.90
162-1041	G-30CS	¥4,767	¥5,150	396	300	140	25.0	12.0	10	1.85

Throat 175mm

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Max Opening (mm)	Throat (mm)	Frame Dimension (mm)		SPQ (piece)	Weight (kg)
							A	B		
445-4596	G-40CS	¥5,962	¥6,440	505	400	175	27.0	13.0	10	2.57
445-4626	G-60CS	¥7,462	¥8,060	705	600	175	27.0	13.0	6	3.06
445-4642	G-80CS	¥9,331	¥10,080	905	800	175	27.0	13.0	6	3.55
445-4464	G-100CS	¥11,664	¥12,600	1105	1000	175	27.0	13.0	6	4.03

Contact us: 0120-509-849 <http://www.orange-book.com/>

Toggle Clamps

Hand Vices

Grip Pliers

C-Clamps

L Type Clamp

Clamps for Temporary Structures

Welding Clamps

Hand Clamps

Bar Clamps

Special Clamps

Vices

Parts for Vices