

L Type Clamps

The number next to the logo mark indicates items in stock for each brand.

Toggle Clamps

Hand Vices

Grip Pliers

C-Clamps

L Type Clamp

Clamps for Temporary Structures

Welding Clamps

Hand Clamps

Bar Clamps

Special Clamps


Vices

Parts for Vices



Stock 38,650 Items

L-Type Clamp (standard type)

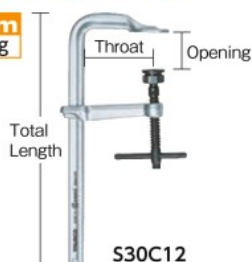

- Features**
- Because the shaft head is a hexagon that can be tightened with a wrench, it can be tightened more reliably.
 - **Maximum tightening pressure at 150mm clamping is 11.5kN.**
 - The tightening angle up to approximately 35° can be possible with the powerful type adapter.
- Specs**
- Standard Mounting Pad: SC-FP
- Materials**
- Special Steel
- Origin**
- Taiwan

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

| Order Code | Item No. | Price (per piece) | MSRP (per piece) | Total Length (mm) | Max Opening (mm) | Throat (mm) | Frame Dimension (mm) | | SPQ (piece) | Weight (kg) |
|------------|----------|-------------------|------------------|-------------------|------------------|-------------|----------------------|------|-------------|-------------|
| | | | | | | | A | B | | |
| 445-4871 | S20C12 | ¥5,822 | ¥6,290 | 320 | 200 | 120 | 27.0 | 13.0 | 10 | 1.97 |
| 445-4880 | S25C12 | ¥6,128 | ¥6,620 | 370 | 250 | 120 | 27.0 | 13.0 | 10 | 2.09 |
| 445-4898 | S30C12 | ¥6,434 | ¥6,950 | 420 | 300 | 120 | 27.0 | 13.0 | 10 | 2.21 |
| 445-4901 | S40C12 | ¥7,045 | ¥7,610 | 520 | 400 | 120 | 27.0 | 13.0 | 10 | 2.46 |
| 445-4910 | S50C12 | ¥7,656 | ¥8,270 | 620 | 500 | 120 | 27.0 | 13.0 | 10 | 2.71 |
| 445-4928 | S60C12 | ¥8,276 | ¥8,940 | 720 | 600 | 120 | 27.0 | 13.0 | 10 | 2.96 |

Parts Materials •Medium Carbon Steel (S45C)

Order Unit: 1 Piece

(Price revision date: Jan, 2017)

| Order Code | Item No. | Price (per piece) | MSRP (per piece) | Item Name | Applicable frame dimension A (mm) | SPQ (piece) | Weight (g) |
|------------|----------|-------------------|------------------|-----------------|-----------------------------------|-------------|------------|
| 445-4936 | SC-FP | ¥463 | ¥500 | Flat Pad | 25, 27 | 10 | 70 |
| 445-4952 | SC-MP | ¥509 | ¥550 | Pad with Groove | 25, 27 | 10 | 70 |
| 445-4979 | SC-VP | ¥814 | ¥880 | V Pad | 25, 27 | 10 | 103 |
| 445-4961 | SC-N | ¥463 | ¥500 | Nut | 25, 27 | 10 | 35 |
| 445-4944 | SC-J | ¥509 | ¥550 | Joint | 25, 27 | 10 | 65 |

Contact us:0120-509-849 <http://www.orange-book.com/>



Stock 38,650 Items

L Type Clamp (strong type)



- Features**
- Because the shaft head is a hexagon that can be tightened with a wrench, it can be tightened more reliably.
 - The tightening angle up to approximately 35° can be possible with the powerful type adapter.
- Specs**
- Standard Mounting Pad: GSSS-FP
- Materials**
- Special Steel
- Origin**
- Taiwan

Heavy Type Features •Maximum tightening pressure at 150mm clamping is 13.5kN.

Order Unit: 1 Piece

(Price revision date: Jan, 2017) TRUSCO NAKAYAMA CORPORATION

| Order Code | Item No. | Price (per piece) | MSRP (per piece) | Total Length (mm) | Max Opening (mm) | Throat (mm) | Frame Dimension (mm) | | SPQ (piece) | Weight (kg) |
|------------|----------|-------------------|------------------|-------------------|------------------|-------------|----------------------|------|-------------|-------------|
| | | | | | | | A | B | | |
| 445-4693 | GS25C | ¥7,689 | ¥8,305 | 388 | 250 | 120 | 30.0 | 15.0 | 10 | 2.76 |
| 445-4707 | GS30C | ¥8,737 | ¥9,438 | 438 | 300 | 140 | 30.0 | 15.0 | 10 | 2.96 |
| 445-4715 | GS40C | ¥9,408 | ¥10,163 | 538 | 400 | 120 | 30.0 | 15.0 | 6 | 3.20 |
| 445-4723 | GS50C | ¥10,356 | ¥11,187 | 638 | 500 | 140 | 30.0 | 15.0 | 6 | 3.66 |
| 445-4731 | GS60C | ¥10,916 | ¥11,792 | 738 | 600 | 120 | 30.0 | 15.0 | 6 | 3.87 |
| 445-4740 | GS80C | ¥12,474 | ¥13,475 | 938 | 800 | 140 | 30.0 | 15.0 | 6 | 4.62 |
| 445-4669 | GS100C | ¥13,594 | ¥14,685 | 1138 | 1000 | 120 | 30.0 | 15.0 | 1 | 5.15 |
| 445-4677 | GS125C | ¥15,580 | ¥16,830 | 1388 | 1250 | 120 | 30.0 | 15.0 | 1 | 5.94 |
| 445-4685 | GS150C | ¥17,514 | ¥18,920 | 1638 | 1500 | 120 | 30.0 | 15.0 | 1 | 6.65 |

Super Heavy Type Features •Maximum tightening pressure at 150mm clamping is 25.0kN.

Order Unit: 1 Piece

(Price revision date: Jan, 2017)

| Order Code | Item No. | Price (per piece) | MSRP (per piece) | Total Length (mm) | Max Opening (mm) | Throat (mm) | Frame Dimension (mm) | | SPQ (piece) | Weight (kg) |
|------------|----------|-------------------|------------------|-------------------|------------------|-------------|----------------------|------|-------------|-------------|
| | | | | | | | A | B | | |
| 445-5011 | SS30C | ¥11,710 | ¥12,650 | 460 | 300 | 175 | 40.0 | 20.0 | 4 | 5.50 |
| 445-5029 | SS40C | ¥14,480 | ¥15,642 | 560 | 400 | 175 | 40.0 | 20.0 | 4 | 6.06 |
| 445-5037 | SS50C | ¥15,234 | ¥16,457 | 660 | 500 | 175 | 40.0 | 20.0 | 4 | 6.62 |
| 445-5045 | SS60C | ¥16,017 | ¥17,303 | 760 | 600 | 175 | 40.0 | 20.0 | 2 | 7.18 |
| 445-5053 | SS80C | ¥19,002 | ¥20,527 | 960 | 800 | 175 | 40.0 | 20.0 | 2 | 8.30 |
| 445-4987 | SS100C | ¥20,875 | ¥22,550 | 1160 | 1000 | 175 | 40.0 | 20.0 | 1 | 9.43 |
| 445-4995 | SS125C | ¥23,930 | ¥25,850 | 1410 | 1250 | 175 | 40.0 | 20.0 | 1 | 10.83 |
| 445-5002 | SS150C | ¥26,985 | ¥29,150 | 1660 | 1500 | 175 | 40.0 | 20.0 | 1 | 12.05 |

Parts Materials •Medium Carbon Steel (S45C)

Order Unit: 1 Piece

| Order Code | Item No. | Price (per piece) | MSRP (per piece) | Item Name | Applicable frame dimension A (mm) | SPQ (piece) | Weight (g) |
|------------|----------|-------------------|------------------|-----------------|-----------------------------------|-------------|------------|
| 445-4758 | GSSS-FP | ¥509 | ¥550 | Flat Pad | 30, 36, 40 | 10 | 74 |
| 445-4774 | GSSS-MP | ¥555 | ¥600 | Pad with Groove | 30, 36, 40 | 10 | 74 |
| 445-4791 | GSSS-VP | ¥833 | ¥900 | V Pad | 30, 36, 40 | 10 | 118 |
| 445-4782 | GSSS-N | ¥509 | ¥550 | Nut | 30, 36, 40 | 10 | 44 |
| 445-4766 | GSSS-J | ¥555 | ¥600 | Joint | 30, 36, 40 | 10 | 96 |

Shaft

Order Unit: 1 Piece

| Order Code | Item No. | Price (per piece) | MSRP (per piece) | Item Name | SPQ (piece) | Weight (g) |
|------------|----------|-------------------|------------------|----------------------------|-------------|------------|
| 490-1355 | TCSF-27 | ¥741 | ¥800 | Shaft | 10 | 200 |
| 490-1363 | TCSF-30 | ¥944 | ¥1,020 | Shaft for Heavy Type | 10 | 500 |
| 490-1371 | TCSF-40 | ¥1,342 | ¥1,450 | Shaft for Super Heavy Type | 10 | 800 |

Contact us:0120-509-849 <http://www.orange-book.com/>