

# L Type Clamps (for woodworking)

The number next to the logo mark indicates items in stock for each brand.

TRUSCO

 



Stock 38,650 Items

## UNI Clamp



Com Drawing

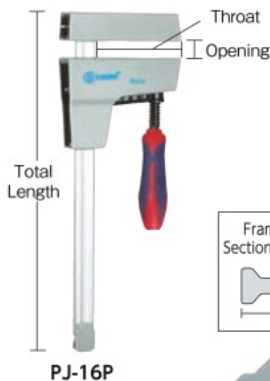

- Features**
- Suitable for precise surfaces, angled materials and sharp tip materials because of the large and flat clamp surface.
  - As the casing part is made of glass fiber strong polyamide, it is difficult to break and adhesive is difficult to stick.
- Materials**
- Cold rolled steel material
  - Resin
- Origin**
- Taiwan

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Max. Opening (mm)	Throat (mm)	Frame Dimension (mm)		SPQ (piece)	Weight (kg)
							A	B		
490-0898	PJ-16P	¥2,805	¥3,030	297	160	80	20	5	10	0.6
490-0901	PJ-30P	¥2,898	¥3,130	437	300	80	20	5	10	0.7
490-0910	PJ-60P	¥3,027	¥3,270	737	600	80	20	5	10	0.9

Stopper

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Compatible Model	SPQ (piece)	Weight (g)
490-0928	PJSP	¥278	¥300	PJ-16P, PJ-30P, PJ-60P	10	20


Contact us:0120-509-849 <http://www.orange-book.com/>

BESSEY



Stock 100 Items

## UNI Clamp

 

- Features**
- Suitable for precise surfaces, angled materials and sharp tip materials because of the large and flat clamp surface.
  - As the casing part is made of glass fiber strong polyamide, it is difficult to break and adhesive is difficult to stick.
- Materials**
- Cold Rolled Steel Material
- Origin**
- Germany

Order Unit: 1 Piece

BESSEY

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Max. Opening (mm)	Expansion width (mm)	Throat (mm)	Frame Dimension (mm)		SPQ (piece)	Weight (g)
								A	B		
222-0792	UK-16	¥3,857	¥4,390	290	160	172 to 270	80	20	5	6	600
222-0806	UK-30	¥3,996	¥4,540	430	300	172 to 415	80	20	5	6	700
222-0814	UK-60	¥4,166	¥4,740	740	600	172 to 720	80	20	5	6	930



Contact us:06-6531-0085 <http://www.daidokogyo-kk.co.jp/>

BESSEY



Stock 100 Items

## Clamp for Woodworking

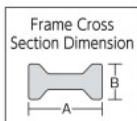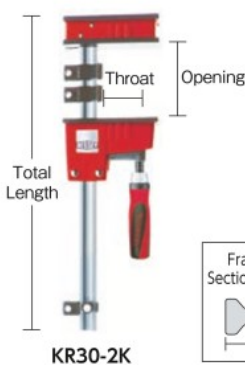

- Features**
- The tightening part is covered with plastic to prevent damages.
  - It is made so that it becomes always parallel to the clamp surface.
- Materials**
- Iron
  - Resin
- Origin**
- Germany



Order Unit: 1 Piece Blue Factory direct | Freight: ¥1,000 | Excluding remote islands |

BESSEY

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Max. Opening (mm)	Throat (mm)	Frame Dimension (mm)		SPQ (piece)	Weight (kg)
							A	B		
397-4502	KR30-2K	¥7,992	¥9,080	505	390	95	29	9	4	1.83
397-4511	KR60-2K	¥9,458	¥10,740	805	730	95	29	9	4	2.40
397-4481	KR100-2K	¥11,787	¥13,370	1205	1130	96	29	9	4	3.28
397-4499	KR125-2K	¥12,729	¥14,450	1455	1355	95	29	9	4	3.65
★461-5298	KR150-2K	¥14,117	¥16,020	1705	1610	95	29	9	2	4.13
★461-5301	KR200-2K	¥17,033	¥19,320	2205	2080	95	29	9	2	5.09
★461-5310	KR250-2K	¥20,705	¥23,500	2705	2580	95	29	9	2	6.05

Pad Materials •Resin Origin •China

Order Unit: 1 Set

Order Code	Item No.	Price (per set)	MSRP (per set)	Size of contact surface (mm)	Q'ty Per Set (piece)	SPQ (set)	Weight (kg/set)
397-4529	KRAS	¥2,052	¥2,340	170 x 25	2	1	0.15

Contact us:06-6531-0085 <http://www.daidokogyo-kk.co.jp/>