







## Type Index Classification Index


## Classification of Measuring Tape

 <b>General Purpose Free Type</b> p. 1-1954 to 1958	 <b>Lock Type</b> p. 1-1959 to 1969	 <b>Rubber Cover Type</b> p. 1-1959 to 1977
 <b>With belt holder type</b> p. 1-1977 to 1987	 <b>Special Type</b> p. 1-1987 to 1989	 <b>Measuring Tape Related Items</b> p. 1-1989

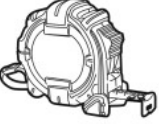
### Function Pict List

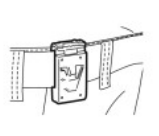Adjustable Hook, Fixing Hook, Lock, Free, JIS 1Rank, 455 mmPitch


[455mm Pitch Display]  
Marker used in a two-by-four construction style, panel construction style, prefabricated construction style.



[Deceleration Button]  
Reduce the speed of tape retraction.

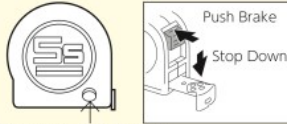

[Shock Absorber]  
Mitigate impact during retracting.

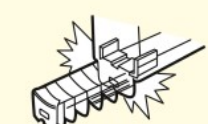

 <p><b>"Measuring Tape with Memo Plate"</b> Calibration OK Approx. 2 Weeks</p>	<p>Stock 38,650 Items</p>	<p><b>"Double Sided Braking"</b> Calibration OK Approx. 2 Weeks RoHS</p>
---	---------------------------	--

<p><b>Com Drawing</b> Features: •With a memo plate to jot down. Materials: •Tape: Steel Origin: •China</p> <p>Adjustable Hook, Free, JIS 1Rank, 455 mmPitch Tape Width 16mm</p>  <p>TT13-20</p> <p>Example: Please use a pencil.</p> <p>Double-sided</p> 	<p><b>Com Eco Drawing</b> Features: •With its double-sided scale convenient to measure three-dimensional places such as walls and ceilings. Materials: •Tape: Steel Origin: •Malaysia</p> <p>Adjustable Hook, Free, JIS 1Rank, 455 mmPitch</p>  <p>TRC-1635F</p> <p>Double-sided</p> 
---	--

Contact us:0120-509-849 <http://www.orange-book.com/>

 <p>Stock 280 Items</p> <p><b>"Free Measuring Tape"</b> Calibration OK Approx. 2 Weeks RoHS</p>	<p>Stock 280 Items</p>	<p><b>"Free Measuring Tape"</b> Calibration OK Approx. 2 Weeks RoHS</p>
--	------------------------	---

<p>Adjustable Hook, Free, JIS 1Rank, 455 mmPitch</p> <p>Features: •Movable hook for both hook measurement and push measurement. •Basic model free round type measuring tape, compact type. Materials: •Tape: Steel Origin: •Malaysia</p>  <p>KF13-20</p> <p>Single-sided</p> 	<p>Fixing Hook, Free, JIS 1Rank, 455 mmPitch</p> <p>Features: •Fixed hook dedicated to hooking measurement. •Basic model free round type measuring tape, compact type. Materials: •Tape: Steel Origin: •Malaysia</p>  <p>KF13-20K</p> <p>Single-sided</p> 
---	---

Order Unit: 1 Piece (Price revision date: Jan, 2016) MURATEC-KDS CORP.									Order Unit: 1 Piece (Price revision date: Jan, 2016) MURATEC-KDS CORP.								
Order Code	Item No.	Price (per piece)	MSRP (per piece)	Tape Length (m)	Tape Width (mm)	Horizontal Retention (m)	SPQ (piece)	Weight (g)	Order Code	Item No.	Price (per piece)	MSRP (per piece)	Tape Length (m)	Tape Width (mm)	Horizontal Retention (m)	SPQ (piece)	Weight (g)
000-1678	KF13-20	¥ 446	¥ 660	2.0	13	1.2	12	60	109-6915	KF13-20K	¥ 446	¥ 660	2.0	13	1.2	12	60
000-1686	KF16-35	¥ 1,128	¥ 1,670	3.5	16	1.3	12	114	109-6923	KF16-35K	¥ 1,128	¥ 1,670	3.5	16	1.3	12	114
000-1694	KF16-55	¥ 1,236	¥ 1,830	5.5	16	1.3	12	180	109-6931	KF16-55K	¥ 1,236	¥ 1,830	5.5	16	1.3	12	180

Contact us:0120-25-5548 <http://www.muratec-kds.jp/>