

# Measuring Tapes (rubber cover type/belt holder type)

Stock 422 Items

1-1977

Prices displayed include 8% tax.

**PROMART** Stock 68 Items **"GOKUSYOH GOM"** RoHS

**Adjustable Hook** **Lock** **JIS 1Rank** **455 mmPitch**

**Features**

- Compact body with rubber.
- Rustless stainless steel spring.
- With shock absorber so that the case and the claws are not easily broken.

**Materials**

- Tape: Steel

**Origin**

- China



**GDK2555**

Single-sided



**PROMART** Stock 68 Items **"GOKUSYOH GOM"** RoHS

**Adjustable Hook** **Lock** **455 mmPitch**

**Features**

- **With scale equivalent scale gradations.**
- Compact body with rubber.
- Rustless stainless steel spring.
- With shock absorber so that the case and the claws are not easily broken.

**Materials**

- Tape: Steel

**Origin**

- China



**GDK2555S**

Single-sided



Order Unit: 1 Piece (Price revision date: Apr, 2017) HARA RULE MFG.Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Tape Length (m)	Tape Width (mm)	Horizontal Retention (m)	SPQ (piece)	Weight (g)
484-1506	GDK1955	¥1,934	—	5.5	19	1.8	4	244
484-1531	GDK2555	¥2,321	—	5.5	25	2.3	4	290
484-1573	GDK2575	¥3,016	—	7.5	25	2.2	4	382
484-1522	GDK25100	¥3,349	—	10.0	25	2.2	4	508

Contact us: 0465-48-8211 <http://www.haradoki.co.jp/>

Order Unit: 1 Piece (Price revision date: Apr, 2017) HARA RULE MFG.Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Tape Length (m)	Tape Width (mm)	Horizontal Retention (m)	SPQ (piece)	Weight (g)
484-1514	GDK1955S	¥1,934	—	5.5	19	1.8	4	244
484-1565	GDK2555S	¥2,321	—	5.5	25	2.3	4	290

Contact us: 0465-48-8211 <http://www.haradoki.co.jp/>

**TRUSCO** **"Interval-style Graduation Measuring Tape"** Calibration OK Approx. 2 Weeks RoHS

**eco** Chemical Content Inspection **.Com Drawing**

**Adjustable Hook** **Lock** **JIS 1Rank**

**Features**


- **Continuous scale allows understanding without looking throughout scale.**
- With 4 pins, hard to lose the claw.

**Materials**

- Tape: Steel

**Origin**


- Malaysia



**TRC-2555OB**

Double-sided

Easy to Read Gradation Scale

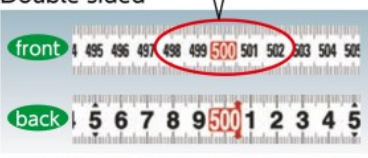

**MURATEC KDS** Stock 280 Items **"GG EVO"** Calibration OK Approx. 2 Weeks RoHS

**Adjustable Hook** **Lock** **JIS 1Rank** **455 mmPitch**

**Features**

- A highly durable nylon coat tape with excellent wear resistance is adopted.
- A newly designed short stroke stopper is adopted.
- With a safety metal holder with durability and outstanding usability.
- With a safety rope with excellent strength.

**Materials**

- Tape: Steel

**Origin**

- Malaysia



**GGEVO25-55AR**

Double-sided



Order Unit: 1 Piece TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Tape Length (m)	Tape Width (mm)	Horizontal Retention (m)	SPQ (piece)	Weight (g)
352-0196	TRC-1955OB	¥1,620	¥2,000	5.5	19	2.0	6	222
342-6114	TRC-2555OB	¥2,219	¥2,740	5.5	25	2.4	6	278

Contact us: 0120-509-849 <http://www.orange-book.com/>

Order Unit: 1 Piece MURATEC-KDS CORP.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Tape Length (m)	Tape Width (mm)	Horizontal Retention (m)	SPQ (piece)	Weight (g)
756-7561	GGEVO25-55AR	¥3,848	¥5,700	5.5	25	2.4	4	408

Contact us: 0120-25-5548 <http://www.muratec-kds.jp/>

**MURATEC KDS** Stock 280 Items **"GG EVOQ Con"** Calibration OK Approx. 2 Weeks RoHS

**Adjustable Hook** **Lock** **JIS 1Rank** **455 mmPitch**

**Features**

- A highly durable nylon coat tape with excellent wear resistance is adopted.
- A newly designed short stroke stopper is adopted.
- It uses a newly designed elastomer damper that is resistant to impact.

**Materials**

- Tape: Steel

**Origin**

- Malaysia



**GGEVO25-55H**

Double-sided



**MURATEC KDS** Stock 280 Items **"GG EVO X Q Con"** Calibration OK Approx. 2 Weeks RoHS

**Adjustable Hook** **Lock** **JIS 1Rank** **455 mmPitch**

**Features**

- A highly durable nylon coat tape with excellent wear resistance is adopted.
- A newly designed short stroke stopper is adopted.
- It uses a newly designed elastomer damper that is resistant to impact.
- It has adopted a rustless stainless steel spring.

**Materials**

- Tape: Steel
- **Spring: Stainless Steel**

**Origin**

- Malaysia



**GGEVOX25-55H**

Double-sided



Order Unit: 1 Piece (Price revision date: Jan, 2016) MURATEC-KDS CORP.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Tape Length (m)	Tape Width (mm)	Horizontal Retention (m)	SPQ (piece)	Weight (g)
475-6347	GGEVO25-55H	¥2,633	¥3,900	5.5	25	2.4	4	355

Contact us: 0120-25-5548 <http://www.muratec-kds.jp/>

Order Unit: 1 Piece (Price revision date: Jan, 2016) MURATEC-KDS CORP.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Tape Length (m)	Tape Width (mm)	Horizontal Retention (m)	SPQ (piece)	Weight (g)
475-6398	GGEVOX25-55H	¥3,105	¥4,600	5.5	25	2.4	4	358

Contact us: 0120-25-5548 <http://www.muratec-kds.jp/>

Surveying Tools

Measuring Tapes

Tape Measures

Road Counters

Line Lasers

Laser Distance Meters

Rotary Lasers

Theodolites

Automatic Levels

Staffs

Levels

Slant Levels

Stud Finders

Plumb Bobs

Ink Lines, Chalk Reels

Construction Writing Tools

Blackboards

Surveying Signs