

Split Pins

The number next to the logo mark indicates items in stock for each brand.




Stock 38,650 Items

Split Pin

Origin • Japan



B19 Type

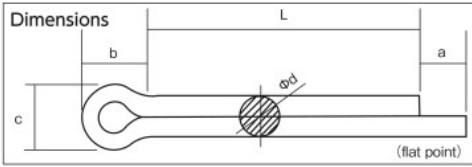

Basic Dimensional Table

(unit: mm)

Through Hole Diameter	φ d		c		Approx.	a	L	
	Basic Dimension	Allowable Difference	Basic Dimension	Allowable Difference			Basic Dimension	Allowable Difference
1.2	1.0		2.0	0/-3.0	3.0	2.5	8 to 25	± 0.5
1.6	1.4	0/-0.1	2.8		3.2	2.5	8 to 32	
2.0	1.8		3.6	0/-4.0	4.0	2.5	10 to 40	
2.5	2.3	0/-0.2	4.6	0/-0.6	5.0	2.5	12 to 50	± 0.8
3.0	2.7	± 0.1	5.5	± 0.5	6.0	3.2	15 to 55	
3.2	2.9	0/-0.2	5.8	0/-0.7	6.4	3.2	14 to 63	
3.5	3.0	± 0.1	6.0	± 0.5	7.0	4.4	-	-
4.0	3.7	0/-0.2	7.4	0/-0.9	8.0	4.0	18 to 80	± 1.2
4.5	4.0	± 0.1	8.0	± 0.5	9.0	4.4	-	-
5.0	4.6	0/-0.2	9.2	0/-1.2	10.0	4.0	22 to 100	
6.0	5.6	± 0.1	11.0	± 1.0	12.0	3.2	25 to 110	± 1.2
6.3	5.9	0	11.8	0/-1.5	12.6	4.0	32 to 125	
8.0	7.5	-0.2	15.0	0/-1.9	16.0	4.0	40 to 160	± 2.0

Steel Materials • Steel (SWRM6 to 17/SWCH6R to 17R) • Surface Treatment: Fabric

Order Unit: 1 Bag

TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Through Hole Diameter x L (mm)	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)	Order Code	Item No.	Price (per bag)	MSRP (per bag)	Through Hole Diameter x L (mm)	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
161-3383	B19-1220	¥435	¥470	1.2 x 20	160	10	23.6	161-3693	B19-4035	¥435	¥470	4.0 x 35	55	10	203.5
161-3391	B19-1225	¥435	¥470	1.2 x 25	100	10	17.8	161-3707	B19-4040	¥435	¥470	4.0 x 40	50	10	206.8
161-3405	B19-1620	¥435	¥470	1.6 x 20	200	10	59.2	161-3715	B19-4045	¥435	¥470	4.0 x 45	45	10	205.1
161-3413	B19-1625	¥435	¥470	1.6 x 25	180	10	64.1	161-3723	B19-4050	¥435	¥470	4.0 x 50	40	10	199.2
161-3421	B19-1630	¥435	¥470	1.6 x 30	150	10	62.4	161-3731	B19-4055	¥435	¥470	4.0 x 55	35	10	188.3
161-3430	B19-2020	¥435	¥470	2.0 x 20	195	10	97.3	161-3740	B19-4060	¥435	¥470	4.0 x 60	30	10	174.0
161-3448	B19-2025	¥435	¥470	2.0 x 25	165	10	98.8	163-1993	B19-4540	¥435	¥470	4.5 x 40	40	10	164.0
161-3456	B19-2030	¥435	¥470	2.0 x 30	150	10	104.9	163-2001	B19-4545	¥435	¥470	4.5 x 45	30	10	141.0
161-3464	B19-2035	¥435	¥470	2.0 x 35	115	10	91.9	163-2019	B19-4550	¥435	¥470	4.5 x 50	30	10	159.0
161-3472	B19-2040	¥435	¥470	2.0 x 40	95	10	85.4	163-2027	B19-4555	¥435	¥470	4.5 x 55	27	10	159.3
213-0131	B19-2050	¥435	¥470	2.0 x 50	70	10	76.9	163-2035	B19-4560	¥435	¥470	4.5 x 60	25	10	162.5
161-3499	B19-2520	¥435	¥470	2.5 x 20	165	10	140.1	161-3758	B19-5035	¥435	¥470	5.0 x 35	37	10	220.1
161-3502	B19-2525	¥435	¥470	2.5 x 25	135	10	136.7	161-3766	B19-5040	¥435	¥470	5.0 x 40	33	10	219.5
161-3511	B19-2530	¥435	¥470	2.5 x 30	120	10	134.1	161-3774	B19-5045	¥435	¥470	5.0 x 45	30	10	219.1
161-3529	B19-2535	¥435	¥470	2.5 x 35	95	10	127.8	161-3782	B19-5050	¥435	¥470	5.0 x 50	25	10	202.2
161-3537	B19-2540	¥435	¥470	2.5 x 40	90	10	135.2	161-3791	B19-5055	¥435	¥470	5.0 x 55	25	10	220.0
161-3553	B19-2550	¥435	¥470	2.5 x 50	65	10	118.9	161-3804	B19-5060	¥435	¥470	5.0 x 60	22	10	208.7
161-3561	B19-3020	¥435	¥470	3.0 x 20	120	10	144.0	161-3812	B19-5065	¥435	¥470	5.0 x 65	20	10	203.8
161-3570	B19-3025	¥435	¥470	3.0 x 25	110	10	165.0	161-3821	B19-5070	¥435	¥470	5.0 x 70	18	10	196.2
161-3588	B19-3030	¥435	¥470	3.0 x 30	90	10	153.0	161-3839	B19-6050	¥435	¥470	6.0 x 50	13	10	152.1
161-3596	B19-3035	¥435	¥470	3.0 x 35	90	10	171.0	161-3855	B19-6060	¥435	¥470	6.0 x 60	11	10	148.5
161-3600	B19-3040	¥435	¥470	3.0 x 40	70	10	147.0	161-3863	B19-6065	¥435	¥470	6.0 x 65	10	10	144.0
161-3618	B19-3045	¥435	¥470	3.0 x 45	70	10	161.0	161-3871	B19-6070	¥435	¥470	6.0 x 70	10	10	153.0
161-3626	B19-3050	¥435	¥470	3.0 x 50	60	10	150.0	161-3880	B19-6080	¥435	¥470	6.0 x 80	8	10	129.6
161-3634	B19-3530	¥435	¥470	3.5 x 30	65	10	123.5	161-3898	B19-6090	¥435	¥470	6.0 x 90	7	10	119.7
161-3642	B19-3535	¥435	¥470	3.5 x 35	60	10	132.0	161-3901	B19-8050	¥435	¥470	8.0 x 50	6	10	136.8
161-3651	B19-3540	¥435	¥470	3.5 x 40	60	10	150.0	161-3910	B19-8060	¥435	¥470	8.0 x 60	6	10	156.0
161-3669	B19-3545	¥435	¥470	3.5 x 45	60	10	168.0	161-3928	B19-8070	¥435	¥470	8.0 x 70	5	10	154.0
161-3677	B19-3550	¥435	¥470	3.5 x 50	60	10	186.0	161-3936	B19-8080	¥435	¥470	8.0 x 80	5	10	178.0
161-3685	B19-4030	¥435	¥470	4.0 x 30	65	10	215.1	213-0165	B19-8090	¥435	¥470	8.0 x 90	4	10	160.0



B64 Type

Stainless Steel Materials • Stainless Steel (equivalent to SUS304)

Order Unit: 1 Bag

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Through Hole Diameter x L (mm)	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)	Order Code	Item No.	Price (per bag)	MSRP (per bag)	Through Hole Diameter x L (mm)	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
161-3944	B64-1215	¥879	¥950	1.2 x 15	130	10	15.3	161-4151	B64-2550	¥879	¥950	2.5 x 50	29	10	53.0
161-3952	B64-1220	¥879	¥950	1.2 x 20	110	10	16.2	161-4169	B64-0330	¥879	¥950	3.0 x 30	35	10	59.5
161-3961	B64-1225	¥879	¥950	1.2 x 25	100	10	17.8	161-4177	B64-0335	¥879	¥950	3.0 x 35	30	10	57.0
161-3979	B64-1615	¥879	¥950	1.6 x 15	110	10	25.8	161-4185	B64-0340	¥879	¥950	3.0 x 40	29	10	60.9
161-3987	B64-1620	¥879	¥950	1.6 x 20	100	10	29.6	161-4193	B64-0345	¥879	¥950	3.0 x 45	27	10	62.1
161-3995	B64-1625	¥879	¥950	1.6 x 25	90	10	32.0	161-4207	B64-0350	¥879	¥950	3.0 x 50	25	10	62.5
161-4002	B64-1630	¥879	¥950	1.6 x 30	80	10	33.3	213-0343	B64-0360	¥879	¥950	3.0 x 60	21	10	60.9
161-4011	B64-0215	¥879	¥950	2.0 x 15	95	10	32.2	161-4215	B64-0440	¥879	¥950	4.0 x 40	20	10	82.7
161-4029	B64-0220	¥879	¥950	2.0 x 20	85	10	42.4	161-4223	B64-0445	¥879	¥950	4.0 x 45	19	10	86.6
161-4037	B64-0225	¥879	¥950	2.0 x 25	75	10	44.9	161-4231	B64-0450	¥879	¥950	4.0 x 50	18	10	89.6
161-4045	B64-0230	¥879	¥950	2.0 x 30	65	10	45.4	213-0351	B64-0460	¥879	¥950	4.0 x 60	16	10	92.8
161-4053	B64-0235	¥879	¥950	2.0 x 35	55	10	43.9	213-0360	B64-0470	¥879	¥950	4.0 x 70	14	10	92.4
161-4061	B64-0240	¥879	¥950	2.0 x 40	50	10	44.9	161-4240	B64-0540	¥879	¥950	5.0 x 40	14	10	93.1
161-4088	B64-0250	¥879	¥950	2.0 x 50	45	10	49.4	161-4258	B64-0545	¥879	¥950	5.0 x 45	14	10	102.2
161-4096	B64-2520	¥879	¥950	2.5 x 20	55	10	46.7	161-4266	B64-0550	¥879	¥950	5.0 x 50	13	10	105.3
161-4100	B64-2525	¥879	¥950	2.5 x 25	45	10	45.5	213-0378	B64-0560	¥879	¥950	5.0 x 60	12	10	114.0
161-4118	B64-2530	¥879	¥950	2.5 x 30	40	10	46.9	213-038							