

Gripping Balls (resin/metal)

The number next to the logo mark indicates items in stock for each brand.

TRUSCO **Stock 38,650 Items**

Grip Balls (plastic)



TPB-BK




TPB-R

- Features • A standard resin grip ball.
 Specs • Without core bar type
 Materials • ABS resin
 Origin • Japan

Warning

- When using an adhesive, please use an ABS resin compatible one.
- Since the thread part is tapered, it becomes hard in the middle, but please use it by screwing to the end.

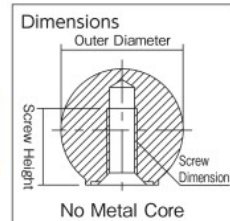

Black

Order Unit: 1 Box (Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per box)	MSRP (per box)	Outer Diameter (mm)	Screw Dimension	Screw Height (mm)	Q'ty Per Box (piece)	Weight (g/box)
329-2053	TPB20-5BK	¥2,689	¥3,320	20	M5 x 0.80	10	20	100
329-2061	TPB20-6BK	¥2,689	¥3,320	20	M6 x 1.00	10	20	100
329-2070	TPB25-6BK	¥2,957	¥3,650	25	M6 x 1.00	14	20	200
329-2088	TPB25-8BK	¥2,957	¥3,650	25	M8 x 1.25	14	20	200
329-2096	TPB32-8BK	¥4,107	¥5,070	32	M8 x 1.25	14	20	400
329-2100	TPB32-10BK	¥4,107	¥5,070	32	M10 x 1.50	20	20	400
329-2118	TPB40-10BK	¥6,415	¥7,920	40	M10 x 1.50	20	20	800
329-2126	TPB40-12BK	¥6,415	¥7,920	40	M12 x 1.75	20	20	800

Red

Order Unit: 1 Box (Price revision date: Jan, 2016)

Order Code	Item No.	Price (per box)	MSRP (per box)	Outer Diameter (mm)	Screw Dimension	Screw Height (mm)	Q'ty Per Box (piece)	Weight (g/box)
329-1979	TPB20-5R	¥2,689	¥3,320	20	M5 x 0.80	10	20	100
329-1987	TPB20-6R	¥2,689	¥3,320	20	M6 x 1.00	10	20	100
329-1995	TPB25-6R	¥2,957	¥3,650	25	M6 x 1.00	14	20	200
329-2002	TPB25-8R	¥2,957	¥3,650	25	M8 x 1.25	14	20	200
329-2011	TPB32-8R	¥4,107	¥5,070	32	M8 x 1.25	14	20	400
329-2029	TPB32-10R	¥4,107	¥5,070	32	M10 x 1.50	20	20	400
329-2037	TPB40-10R	¥6,415	¥7,920	40	M10 x 1.50	20	20	800
329-2045	TPB40-12R	¥6,415	¥7,920	40	M12 x 1.75	20	20	800

Contact us:0120-509-849 <http://www.orange-book.com/>

TRUSCO **Stock 38,650 Items**

Grip Balls (plastic)



P-TPB-BK




P-TPB-R

- Features • A standard resin grip ball.
 Specs • Without core bar type
 Materials • ABS resin
 Origin • Japan

Warning

- When using an adhesive, please use an ABS resin compatible one.
- Since the thread part is tapered, it becomes hard in the middle, but please use it by screwing to the end.

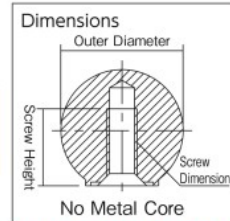

Black

Order Unit: 1 Piece (Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Outer Diameter (mm)	Screw Dimension	Screw Height (mm)	SPQ (piece)	Weight (g)
337-4017	P-TPB20-5BK	¥194	¥240	20	M5 x 0.80	10	20	5
337-4025	P-TPB20-6BK	¥194	¥240	20	M6 x 1.00	10	20	5
337-4033	P-TPB25-6BK	¥171	¥210	25	M6 x 1.00	14	20	10
337-4041	P-TPB25-8BK	¥171	¥210	25	M8 x 1.25	14	20	10
337-4050	P-TPB32-8BK	¥243	¥300	32	M8 x 1.25	14	20	20
337-4068	P-TPB32-10BK	¥243	¥300	32	M10 x 1.50	20	20	20
337-4076	P-TPB40-10BK	¥333	¥410	40	M10 x 1.50	20	20	40
337-4084	P-TPB40-12BK	¥333	¥410	40	M12 x 1.75	20	20	40

Red

Order Unit: 1 Piece (Price revision date: Jan, 2016)

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Outer Diameter (mm)	Screw Dimension	Screw Height (mm)	SPQ (piece)	Weight (g)
337-4092	P-TPB20-5R	¥194	¥240	20	M5 x 0.80	10	20	5
337-4106	P-TPB20-6R	¥194	¥240	20	M6 x 1.00	10	20	5
337-4114	P-TPB25-6R	¥171	¥210	25	M6 x 1.00	14	20	10
337-4122	P-TPB25-8R	¥171	¥210	25	M8 x 1.25	14	20	10
337-4131	P-TPB32-8R	¥243	¥300	32	M8 x 1.25	14	20	20
337-4149	P-TPB32-10R	¥243	¥300	32	M10 x 1.50	20	20	20
337-4157	P-TPB40-10R	¥333	¥410	40	M10 x 1.50	20	20	40
337-4165	P-TPB40-12R	¥333	¥410	40	M12 x 1.75	20	20	40

Contact us:0120-509-849 <http://www.orange-book.com/>


TRUSCO **Stock 38,650 Items**

Gripping Ball (aluminum)



TAB

- Features • Because it is made of an aluminum alloy, it is lightweight.
 Specs • Without core bar type
 Materials • Aluminum Alloy
 Origin • Germany

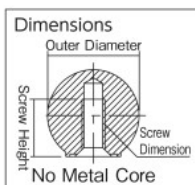

Order Unit: 1 Piece (Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Outer Diameter (mm)	Screw Dimension	Screw Height (mm)	SPQ (piece)	Weight (g)
329-2215	TAB-16	¥1,321	¥1,630	16	M4 x 0.70	7.2	10	5
329-2223	TAB-20	¥1,369	¥1,690	20	M5 x 0.80	9.1	10	10
329-2231	TAB-25	¥1,969	¥2,430	25	M6 x 1.00	11.0	10	20
329-2240	TAB-32	¥2,698	¥3,330	32	M8 x 1.25	14.5	10	45
329-2258	TAB-40	¥3,897	¥4,810	40	M10 x 1.50	18.0	10	85

Contact us:0120-509-849 <http://www.orange-book.com/>


TRUSCO **Stock 38,650 Items**

Gripping Ball (stainless steel)



TSB

- Features • Because it has excellent corrosion resistance, it is suitable for food product machinery and cleaning machinery.
 Specs • Without core bar type
 Materials • Stainless Steel (SUS304)
 Origin • Japan

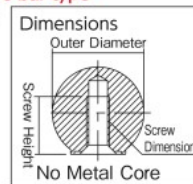

Order Unit: 1 Piece TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Outer Diameter (mm)	Screw Dimension	Screw Height (mm)	SPQ (piece)	Weight (g)
329-2134	TSB20-5S	¥2,309	¥2,850	20	M5 x 0.80	10	10	30
329-2142	TSB20-6S	¥2,309	¥2,850	20	M6 x 1.00	11	10	30
329-2151	TSB25-6S	¥2,592	¥3,200	25	M6 x 1.00	11	10	60
329-2169	TSB25-8S	¥2,592	¥3,200	25	M8 x 1.25	14	10	55
329-2177	TSB32-8S	¥3,078	¥3,800	32	M8 x 1.25	16	10	125
329-2185	TSB32-10S	¥3,078	¥3,800	32	M10 x 1.50	20	10	120
329-2193	TSB40-10S	¥4,212	¥5,200	40	M10 x 1.50	20	10	250
329-2207	TSB40-12S	¥4,212	¥5,200	40	M12 x 1.75	24	10	240

Contact us:0120-509-849 <http://www.orange-book.com/>