

For Construction Hinges, see p. 2-838 to 849

The number next to the logo mark indicates items in stock for each brand.




Stock 38,650 Items

Hinges (stainless steel)



TKH-100CA

- Specs
- Surface Treatment: Mirror Surface Buffing Process Finishing
 - Mounting Method: Wood Screw (sold separately)
- Materials
- Stainless Steel (SUS304)
- Origin
- China

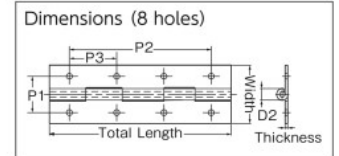

Order Unit: 1 Piece

(Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

(Unit: mm)

Total Length	P1	P2	P3	Wood Screw Size (D x L)
25	20	13	-	3 x 20
30	20	16	-	3 x 20
40	20	24	-	3 x 20
50	20	30	-	3 x 20
60	20	44	22	3 x 20
65	20	48	24	3 x 20
75	20	56	28	3 x 20
80	20	60	30	3 x 20
90	20	70	35	3 x 20
100	20	78	26	3 x 20

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Width (mm)	Thickness (mm)	D2 (mm)	Threaded Hole Number	Hole Diameter (mm)	Load Capacity (kg) when 2 pieces used	SPQ (piece)	Weight (g)
279-6082	TKH-25CA	¥361	¥390	25	32	1.5	6.3	4	3.2	3	200	13
279-6091	TKH-30CA	¥389	¥420	30	32	1.5	6.3	4	3.2	4	200	16
279-6104	TKH-40CA	¥379	¥410	40	32	1.5	6.3	4	3.2	6	150	21
279-6112	TKH-50CA	¥407	¥440	50	32	1.5	6.3	4	3.2	7	100	26
279-6121	TKH-60CA	¥472	¥510	60	32	1.5	6.3	6	3.2	9	100	31
279-6139	TKH-65CA	¥528	¥570	65	32	1.5	6.3	6	3.2	10	100	34
279-6147	TKH-75CA	¥602	¥650	75	32	1.5	6.3	6	3.2	11	50	39
279-6155	TKH-80CA	¥620	¥670	80	32	1.5	6.3	6	3.2	12	50	42
279-6163	TKH-90CA	¥666	¥720	90	32	1.5	6.3	6	3.2	13	50	47
279-6171	TKH-100CA	¥676	¥730	100	32	1.5	6.3	8	3.2	15	50	52

Contact us:0120-509-849 <http://www.orange-book.com/>




Stock 38,650 Items

Flat Hinge (stainless steel)



TLS-90B

- Specs
- Surface Treatment: Mirror Surface Buffing Process Finishing
 - Mounting Method: Wood Screw (sold separately)
- Materials
- Stainless Steel (SUS304)
- Origin
- China

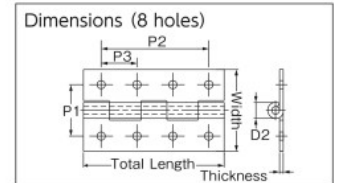

Order Unit: 1 Piece

(Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

(Unit: mm)

Total Length	P1	P2	P3	Wood Screw Size (D x L)
40	22	26	-	3 x 16
50	22	34	-	4 x 16
65	30	46	23	4 x 16
75	30	54	27	5 x 20
90	38	70	35	6 x 20
100	38	78	26	6 x 20

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Width (mm)	Thickness (mm)	D2 (mm)	Threaded Hole Number	Hole Diameter (mm)	Load Capacity (kg) when 2 pieces used	SPQ (piece)	Weight (g)
279-5884	TLS-40B	¥379	¥410	40	35	1.5	6.3	4	3.2	6	100	25
279-5892	TLS-50B	¥444	¥480	50	35	1.5	6.3	4	4.3	8	100	30
279-5906	TLS-65B	¥723	¥780	65	50	2.0	8.8	6	4.3	13	50	64
279-5914	TLS-75B	¥814	¥880	75	50	2.0	8.8	6	5.3	15	40	74
279-5922	TLS-90B	¥1,435	¥1,550	90	60	3.0	12.3	6	6.4	25	10	180
279-5931	TLS-100B	¥1,602	¥1,730	100	60	3.0	12.3	8	6.4	30	10	190

Contact us:0120-509-849 <http://www.orange-book.com/>




Stock 38,650 Items

Heavy Duty Flat Hinge (stainless steel)



TLS-100F

- Specs
- Surface Treatment: Mirror Surface Buffing Process Finishing
 - Mounting Method: Wood Screw (sold separately)
- Materials
- Main Body: Stainless Steel (SUS316)
- Origin
- China

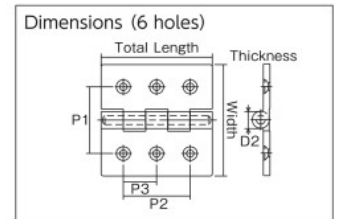

Order Unit: 1 Piece

(Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

(Unit: mm)

Total Length	P1	P2	P3	Wood Screw Size (D x L)
50	35	20	-	4 x 16
65	40	35	-	5 x 20
75	50	40	-	6 x 20
100	60	60	30	6 x 20

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Total Length (mm)	Width (mm)	Thickness (mm)	D2 (mm)	Threaded Hole Number	Hole Diameter (mm)	Load Capacity (kg) when 2 pieces used	SPQ (piece)	Weight (g)
279-6007	TLS-50F	¥3,629	¥3,920	50	50	5	14	4	4	35	20	110
279-6015	TLS-65F	¥4,582	¥4,950	65	65	5	14	4	5	45	20	190
279-6023	TLS-75F	¥5,314	¥5,740	75	75	6	16	4	6	65	10	305
279-6031	TLS-100F	¥6,249	¥6,750	100	100	6	18	6	6	85	10	500

Contact us:0120-509-849 <http://www.orange-book.com/>