

Removable Pin Hinge

For Construction Hinges, see p. 2-838 to 849

The number next to the logo mark indicates items in stock for each brand.




Stock 38,650 Items

Retractable Hinge (stainless steel)



- Specs
- Surface Treatment: Mirror Surface Buffing Process Finishing
 - Mounting Method: Wood Screw (sold separately)
- Materials
- Stainless Steel (SUS304)
- Origin
- China

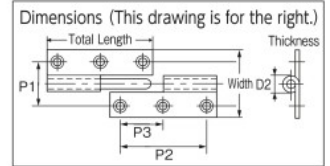

For right

Order Unit: 1 Set

(Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per set)	MSRP (per set)	Total Length (mm)	Width (mm)	Thickness (mm)	D2 (mm)	Threaded Hole Number	Hole Diameter (mm)	Load Capacity (kg) when 2 pieces used	SPQ (set)	Weight (g/set)
279-5957	TKN-50CR	¥666	¥720	50	32	1.5	3.2	6	3.2	7	100	32
279-5973	TKN-64CR	¥741	¥800	64	36	1.5	3.2	6	3.2	10	100	44
279-5990	TKN-75CR	¥917	¥990	75	38	2.0	3.2	6	3.2	15	50	64

For left

Order Unit: 1 Set

(Price revision date: Jan, 2016)

Order Code	Item No.	Price (per set)	MSRP (per set)	Total Length (mm)	Width (mm)	Thickness (mm)	D2 (mm)	Threaded Hole Number	Hole Diameter (mm)	Load Capacity (kg) when 2 pieces used	SPQ (set)	Weight (g/set)
279-5949	TKN-50CL	¥666	¥720	50	32	1.5	7.5	6	3.2	7	100	32
279-5965	TKN-64CL	¥741	¥800	64	36	1.5	7.5	6	3.2	10	100	44
279-5981	TKN-75CL	¥917	¥990	75	38	2.0	8.5	6	3.2	15	50	64

Contact us:0120-509-849 <http://www.orange-book.com/>



Stock 38,650 Items


Retractable Hinge (stainless steel)



- Specs
- Surface Treatment: Polished Finishing
 - Mounting Method: Wood Screw (sold separately)
- Materials
- Stainless Steel (SUS304)
- Origin
- China

(Unit: mm)

Total Length	P1	P2	Wood Screw Size (D x L)
40	16	20	3 x 20

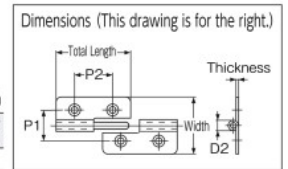

For right

Order Unit: 1 Set

(Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per set)	MSRP (per set)	Total Length (mm)	Width (mm)	Thickness (mm)	D2 (mm)	Threaded Hole Number	Hole Diameter (mm)	Load Capacity (kg) when 2 pieces used	SPQ (set)	Weight (g/set)
279-6295	TNH-40CR	¥583	¥630	40	30	1.5	7	4	3.2	7	150	21

For left

Order Unit: 1 Set

(Price revision date: Jan, 2016)

Order Code	Item No.	Price (per set)	MSRP (per set)	Total Length (mm)	Width (mm)	Thickness (mm)	D2 (mm)	Threaded Hole Number	Hole Diameter (mm)	Load Capacity (kg) when 2 pieces used	SPQ (set)	Weight (g/set)
279-6287	TNH-40CL	¥583	¥630	40	30	1.5	7	4	3.2	7	150	21

Contact us:0120-509-849 <http://www.orange-book.com/>




Stock 38,650 Items

Heavy Duty Removable Pin Hinge (stainless steel)



- Specs
- Surface Treatment: Mirror Surface Buffing Process Finishing
 - Mounting Method: Welded Type
- Materials
- Stainless Steel (SUS304)
- Origin
- China

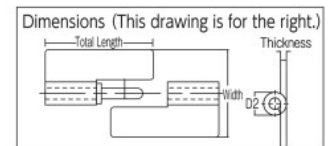

For right

Order Unit: 1 Set

(Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per set)	MSRP (per set)	Total Length (mm)	Width (mm)	Thickness (mm)	D2 (mm)	Load Capacity (kg) when 2 pieces used	SPQ (set)	Weight (g/set)
329-1685	TNH-50CR	¥990	¥1,070	50	40	2.5	10.5	15	15	62
329-1707	TNH-65CR	¥1,166	¥1,260	65	50	2.5	10.5	20	15	95
329-1723	TNH-75CR	¥1,824	¥1,970	75	70	3.0	12.0	30	10	180
329-1740	TNH-100CR	¥3,194	¥3,450	100	82	4.0	16.0	50	10	335

For left

Order Unit: 1 Set

(Price revision date: Jan, 2016)

Order Code	Item No.	Price (per set)	MSRP (per set)	Total Length (mm)	Width (mm)	Thickness (mm)	D2 (mm)	Load Capacity (kg) when 2 pieces used	SPQ (set)	Weight (g/set)
329-1677	TNH-50CL	¥990	¥1,070	50	40	2.5	10.5	15	15	62
329-1693	TNH-65CL	¥1,166	¥1,260	65	50	2.5	10.5	20	15	95
329-1715	TNH-75CL	¥1,824	¥1,970	75	70	3.0	12.0	30	10	180
329-1731	TNH-100CL	¥3,194	¥3,450	100	82	4.0	16.0	50	10	335

Contact us:0120-509-849 <http://www.orange-book.com/>