

Draw Latches

The number next to the logo mark indicates items in stock for each brand.

Machine Tools

O-Rings
Oil
Seals

Rubbers

Resins

Metal
Materials

Carbon
Fibers

Ceramic
Materials

Vibration
Absorber

Adjusters

Plungers

Springs
for
Die

Springs

Split
Pins

Snap
Rings

Oil
Gauges

Oil
Tank
Caps

Knobs

Lever

Handles
Grips

Handles

Hinges

Slide
Rails

Stays

Toggle
Latches

Fastening
Parts

Aluminum
Frames

TRUSCO **Stock 38,650 Items**


Toggle Latch (curved arm type, steel) RoHS



- Specs**
- Body Mounting Hole Dimension: 3.5mm
 - Receiving Hole Dimension: 3.4mm
- Materials**
- Cold Rolled Steel Plate (SPCC)
 - Surface Treatment: Trivalent Uni-chrome-plated Finishing
- Origin**
- Japan



P-147-2

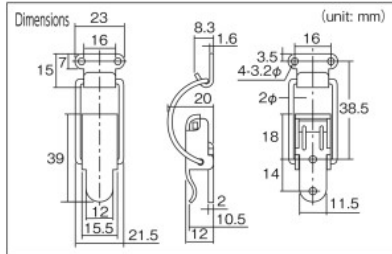

TRUSCO **Stock 38,650 Items**


Draw Latch (key hole-equipped type, steel) RoHS



- Specs**
- Body Mounting Hole Dimension: 3.3mm
 - Receiving Hole Dimension: 4.1mm
 - Key Hole Diameter: 4.6mm
- Materials**
- Cold Rolled Steel Plate (SPCC)
 - Surface Treatment: Nickel-plated Finishing
- Origin**
- Japan



P-21

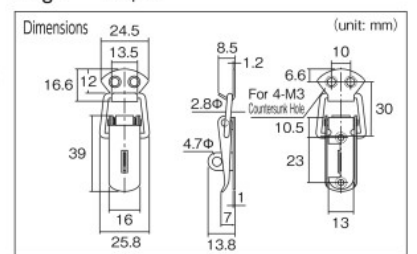

Order Unit: 1 Bag (Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
232-8305	P-147-2	¥2,361	¥2,550	4	10	110

Contact us: 0120-509-849 <http://www.orange-book.com/>

Order Unit: 1 Bag (Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
232-8623	P-21	¥879	¥950	4	10	80

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO **Stock 38,650 Items**


Draw Latch (key hole-equipped type, steel) RoHS



- Specs**
- Body Mounting Hole/Receiving Hole Dimension: 3.5mm
 - Key Hole Diameter: 5.0mm
- Materials**
- Cold Rolled Steel Plate (SPCC)
 - Surface Treatment: Nickel-plated Finishing
- Origin**
- Japan



P-20

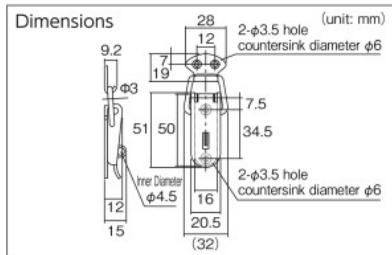

TRUSCO **Stock 38,650 Items**


Draw Latch (key hole-equipped type, steel) RoHS



- Specs**
- Body Mounting Hole Dimension: 5.5mm
 - Receiving Hole Dimension: 5.2mm
 - Key Hole Diameter: 9.0mm
- Materials**
- Cold Rolled Steel Plate (SPCC)
 - Surface Treatment: Trivalent Uni-chrome-plated Finishing
- Origin**
- Japan



P-93

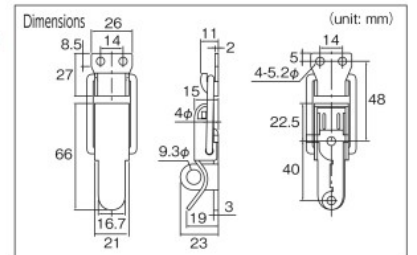

Order Unit: 1 Bag (Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
232-8658	P-20	¥1,194	¥1,290	4	10	170

Contact us: 0120-509-849 <http://www.orange-book.com/>

Order Unit: 1 Bag (Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
232-8046	P-93	¥1,065	¥1,150	2	10	180

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO **Stock 38,650 Items**

Draw Latch (key hole-equipped type, stainless steel) RoHS



- Specs**
- Key Hole Diameter: 4.6mm (P-21SUS), 5.0mm (P-20SUS)
- Materials**
- Stainless Steel (SUS304)
- Origin**
- Japan





P-21SUS



P-20SUS

Item No.	Body Mounting Hole Dimension (mm)	Receiving Hole Dimension (mm)
P-21SUS	3.3	4.1
P-20SUS	3.5	3.5

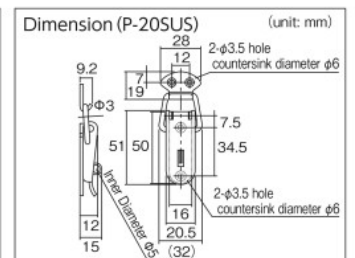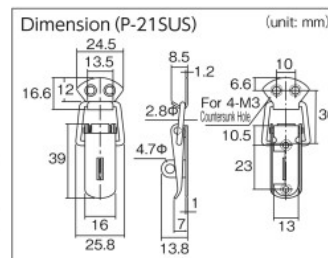

Order Unit: 1 Bag (Price revision date: Jan, 2016) TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
232-8631	P-21SUS	¥2,074	¥2,240	4	10	80
232-8666	P-20SUS	¥3,990	¥4,310	4	10	160

Contact us: 0120-509-849 <http://www.orange-book.com/>