

Hexagon Socket Head Cap Screws (cap screw)

The number next to the logo mark indicates items in stock for each brand.

Hexagon Bolts

Hexagon Socket Head Cap Screws

Hexagon Socket Set Screws

Wing Bolts

Decoration Screws, Nuts

Nuts

Caps for Screw

Washers

Small Screws

Mischievous Prevention Screws

Drill Screws

Tapping Screws

Wood Screws

Nails



Stock 38,650 Items


Low Head Hexagon Socket Head Cap Screw (stainless steel/half thread type)



- Features • The strength of the body where takes the load is higher compared with that of the full thread type.
 Specs • Tensile Strength Rank: Equivalent to A2-50
 Materials • Stainless Steel (SUS304 equivalent material)
 Origin • -



B089 Half Thread Type

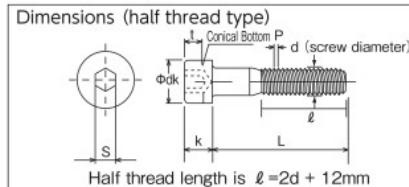

Basic Dimension

(unit: mm)


Nominal Designation of Thread (d)	Thread Pitch (P)	dk	k	s	t
M3	0.50	5.5	2.0	2.0	1.5
M4	0.70	7.0	2.8	2.5	2.3
M5	0.80	8.5	3.5	3.0	2.7
M6	1.00	10.0	4.0	4.0	3.0
M8	1.25	13.0	5.0	5.0	3.8

Order Unit: 1 Bag

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
285-8703	B089-0320	¥620	¥670	M3 x 20	11	10	20.2
285-8771	B089-0425	¥620	¥670	M4 x 25	8	10	33.7
285-8843	B089-0530	¥620	¥670	M5 x 30	7	10	58.0
285-8908	B089-0630	¥620	¥670	M6 x 30	4	10	83.0
285-8916	B089-0635	¥620	¥670	M6 x 35	4	10	68.5
285-8924	B089-0640	¥620	¥670	M6 x 40	3	10	76.0
285-8991	B089-0835	¥620	¥670	M8 x 35	2	10	100.0
285-9009	B089-0840	¥620	¥670	M8 x 40	2	10	92.2

Contact us: 0120-509-849 <http://www.orange-book.com/>

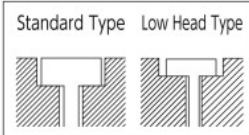

The head is lower compared with general hexagon socket head cap screw.



Stock 38,650 Items


Hexagon Socket Head Button Screw (steel/full thread type)



- Features • A trivalent chromate product with minimal environmental impact.
 Specs • SSS Standard Product (SSS003-1977)
 • Tensile Strength Rank: 10.9
 Materials • Chromium Molybdenum Steel (SCM435)
 • Surface Treatment: Trivalent Chromate Finishing (white)
 Origin • Japan



B774 Full Thread Type

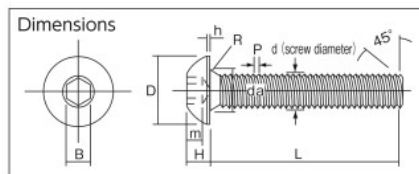

Basic Dimension

(unit: mm)

Nominal Designation of Thread (d)	Thread Pitch (P)	Basic Dimension		Reference	Basic Dimension		Min	Max
		D	H		B	m		
M4	0.70	7.5	2.6	0.4	2.5	1.8	0.20	4.7
M5	0.80	9.5	3.4	0.5	3.0	2.4	0.20	5.7
M6	1.00	10.5	4.0	0.8	4.0	2.8	0.25	6.8
M8	1.25	14.0	5.0	0.8	5.0	3.5	0.40	9.2

Order Unit: 1 Bag

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
300-3132	B774-0406	¥778	¥840	M4 x 6	25	10	25.0
300-3141	B774-0408	¥778	¥840	M4 x 8	25	10	28.5
300-3159	B774-0410	¥778	¥840	M4 x 10	25	10	31.5
300-3167	B774-0412	¥778	¥840	M4 x 12	25	10	35.5
300-3175	B774-0415	¥778	¥840	M4 x 15	23	10	37.7
300-3183	B774-0510	¥778	¥840	M5 x 10	25	10	57.5
300-3191	B774-0512	¥778	¥840	M5 x 12	25	10	63.0
300-3205	B774-0515	¥778	¥840	M5 x 15	23	10	67.1
300-3213	B774-0520	¥778	¥840	M5 x 20	21	10	73.0
300-3221	B774-0525	¥778	¥840	M5 x 25	18	10	73.4
300-3035	B774-0610	¥778	¥840	M6 x 10	20	10	66.0
300-3043	B774-0612	¥778	¥840	M6 x 12	20	10	67.0
300-3051	B774-0615	¥778	¥840	M6 x 15	19	10	78.2
300-3060	B774-0620	¥778	¥840	M6 x 20	19	10	95.0
300-3078	B774-0625	¥778	¥840	M6 x 25	17	10	100.3
300-3086	B774-0630	¥778	¥840	M6 x 30	15	10	100.5
300-3094	B774-0815	¥778	¥840	M8 x 15	11	10	89.1
300-3108	B774-0820	¥778	¥840	M8 x 20	11	10	106.1
300-3116	B774-0825	¥778	¥840	M8 x 25	10	10	116.2
300-3124	B774-0830	¥778	¥840	M8 x 30	9	10	118.8

Contact us: 0120-509-849 <http://www.orange-book.com/>

