


▶▶ The countersunk head tapping screw, see p. 2-477 to 478.

The number next to the logo mark indicates items in stock for each brand.



Stock 38,650 Items

Standoff (φ 12,16)

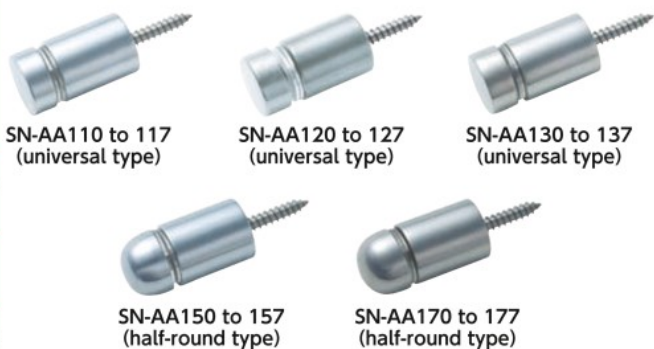

- Features** • Using a spacer between the wall and the sign enables the sign to be mounted floating from the wall.
- Use** • Menu boards and guide plates in restaurants and beauty salons.
- Specs** • Countersunk Screw Diameter for Use: 4mm (sold separately)
• 2 packings attached • Hole Diameter of Mounting Object: 6mm
• Thickness of Mounting Object: 12mm or thinner
- Origin** • China


Example




Universal (chrome plating)

- Materials** • Main Body: Brass
• Surface Treatment: Chrome-Plated Finishing

Universal Type

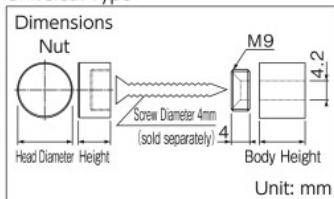

Half-Round Type

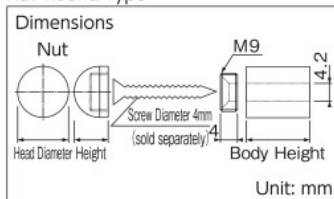

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nut Head (mm) Diameter x Height	Body Height (mm)	SPQ (piece)	Weight (g)
855-5694	SN-AA110	¥509	¥550	12 x 7	10	10	14
855-5697	SN-AA111	¥611	¥660	12 x 7	15	10	18
855-5700	SN-AA112	¥658	¥710	12 x 7	20	10	22
855-5709	SN-AA115	¥759	¥820	16 x 7	10	10	26
855-5712	SN-AA116	¥814	¥880	16 x 7	15	10	35
855-5715	SN-AA117	¥917	¥990	16 x 7	20	10	42

Universal (black chrome plating)

- Materials** • Main Body: Brass
• Surface treatment: black chrome-plated finishing

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nut Head (mm) Diameter x Height	Body Height (mm)	SPQ (piece)	Weight (g)
855-5695	SN-AA120	¥509	¥550	12 x 7	10	10	14
855-5698	SN-AA121	¥611	¥660	12 x 7	15	10	18
855-5701	SN-AA122	¥658	¥710	12 x 7	20	10	22
855-5710	SN-AA125	¥759	¥820	16 x 7	10	10	26
855-5713	SN-AA126	¥861	¥930	16 x 7	15	10	35
855-5716	SN-AA127	¥917	¥990	16 x 7	20	10	42

Universal (stainless steel)

- Materials** • Main Body: Stainless Steel
• Surface Treatment: Buffing Finishing

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nut Head (mm) Diameter x Height	Body Height (mm)	SPQ (piece)	Weight (g)
855-5696	SN-AA130	¥713	¥770	12 x 7	10	10	13
855-5699	SN-AA131	¥814	¥880	12 x 7	15	10	17
855-5702	SN-AA132	¥861	¥930	12 x 7	20	10	20
855-5711	SN-AA135	¥962	¥1,040	16 x 7	10	10	24
855-5714	SN-AA136	¥1,221	¥1,320	16 x 7	15	10	32
855-5717	SN-AA137	¥1,426	¥1,540	16 x 7	20	10	39

Fillister (chrome plating)

- Materials** • Main Body: Brass
• Surface Treatment: Chrome-Plated Finishing

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nut Head (mm) Diameter x Height	Body Height (mm)	SPQ (piece)	Weight (g)
855-5703	SN-AA150	¥528	¥570	12 x 8	10	10	14
855-5705	SN-AA151	¥630	¥680	12 x 8	15	10	17
855-5707	SN-AA152	¥685	¥740	12 x 8	20	10	22
855-5718	SN-AA155	¥787	¥850	16 x 10	10	10	28
855-5720	SN-AA156	¥861	¥930	16 x 10	15	10	34
855-5722	SN-AA157	¥962	¥1,040	16 x 10	20	10	27

Fillister (stainless steel)

- Materials** • Main Body: Stainless Steel
• Surface Treatment: Buffing Finishing

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nut Head (mm) Diameter x Height	Body Height (mm)	SPQ (piece)	Weight (g)
855-5704	SN-AA170	¥787	¥850	12 x 8	10	10	13
855-5706	SN-AA171	¥889	¥960	12 x 8	15	10	15
855-5708	SN-AA172	¥944	¥1,020	12 x 8	20	10	20
855-5719	SN-AA175	¥990	¥1,070	16 x 10	10	10	27
855-5721	SN-AA176	¥1,296	¥1,400	16 x 10	15	10	32
855-5723	SN-AA177	¥1,500	¥1,620	16 x 10	20	10	26

Contact us: 0120-509-849 <http://www.orange-book.com/>



Stock 38,650 Items

Short Standoff (φ 16,20)



SN-AA type

- Features** • A metal fitting that can display a sign floating from the wall.

- Shorter body than the existing type.
 - Ideal for replacing signs by simply removing the bolt head.
- Specs** • Countersunk Screw Diameter for Use: 4mm (sold separately)
• 2 packings attached
• Hole Diameter of Mounting Object: 8mm


- Materials** • Head/Body: Brass
• Surface Treatment: Chrome-Plated Finishing
• Washer: Brassware

- Origin** • Japan

Mounting Method



1. Drive the washer to the wall with a 4mm thick flat head tapping.
2. Attach the body to the washer.
3. Attach the packing, screw in the standoff head and the installation is complete.

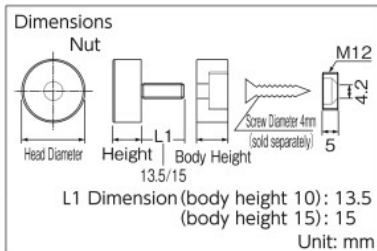

Order Unit: 1 Piece

TRUSCO NAKAYAMA CORPORATION

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Nut Head (mm) Diameter x Height	Body Height (mm)	Thickness of Mounting Object (mm)	SPQ (piece)	Weight (g)
855-5753	SN-AA484	¥676	¥730	16 x 7	10	5 to 8	10	28
855-5754	SN-AA485	¥723	¥780	16 x 7	15	3 to 8	10	33
855-5755	SN-AA487	¥778	¥840	20 x 9	10	5 to 8	10	50
855-5756	SN-AA488	¥824	¥890	20 x 9	15	3 to 8	10	60

Contact us: 0120-509-849 <http://www.orange-book.com/>