

Truss Head Tapping Screws/Countersunk Head Tapping Screws

Stock 424Items

2-477

Prices displayed include 8% tax.

For Drill Screwdriver, see p. 5-124 to 156

TRUSCO Stock 38,650 Items

Truss Head Tapping Screw for Thin Plates



Y041 Type

- Features
- A screw that can fasten tightly to thin plates (thickness of 0.3 to 0.6mm)
 - Burring is unnecessary.
- Origin
- Japan

Steel Materials • Iron (SWCH) • Surface Treatment: Trivalent Chromate

Stainless Steel Materials • Stainless Steel (SUS410)

Order Unit: 1 Bag TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)
856-0946	Y041-0308	¥648	¥700	M3 x 8	100	5
856-0947	Y041-0310	¥648	¥700	M3 x 10	100	5
856-0948	Y041-0408	¥648	¥700	M4 x 8	90	5
856-0949	Y041-0410	¥648	¥700	M4 x 10	85	5

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)
856-0950	Y341-0308	¥648	¥700	M3 x 8	80	5
856-0951	Y341-0310	¥648	¥700	M3 x 10	75	5
856-0952	Y341-0408	¥648	¥700	M4 x 8	60	5
856-0953	Y341-0410	¥648	¥700	M4 x 10	55	5

Contact us: 0120-509-849 <http://www.orange-book.com/>

TRUSCO Stock 38,650 Items

Countersunk Head Tapping Screw (stainless steel)



- Features
- A screw for thin steel plate with a countersunk head shape and can be fastened with pilot hole only without using a tap or nut.
 - Corrosion resistant stainless steel is used.
- Materials
- Stainless Steel (SUS304 equivalent material)
- Origin
-


Basic Dimension (unit: mm)

Nominal Diameter d	Head Outer Diameter (Φ dk)	Head Thickness (k)	Screw Pilot Hole Dimension
M3	6	1.75	2.6
M3.5	7	2.00	2.9
M4	8	2.30	3.2
M5	10	2.80	4.0
M6	12	3.40	4.9

*The screw pilot hole dimension is in case of the base material thickness of 1.2mm.



B10 Type

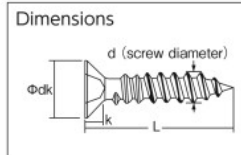

Compatible Screwdriver	
M3 to M5	Plus No. 2
M6	Plus No. 3

Order Unit: 1 Bag TRUSCO NAKAYAMA CORPORATION

Order Unit: 1 Bag

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
159-6284	B10-0306	¥676	¥730	M3.0 x 6	165	10	54.6
159-6292	B10-0308	¥676	¥730	M3.0 x 8	155	10	62.9
159-6306	B10-0310	¥676	¥730	M3.0 x 10	150	10	73.6
159-6314	B10-0312	¥676	¥730	M3.0 x 12	140	10	80.0
159-6322	B10-0316	¥676	¥730	M3.0 x 16	120	10	87.7
159-6331	B10-0320	¥676	¥730	M3.0 x 20	100	10	89.2
159-6349	B10-0325	¥676	¥730	M3.0 x 25	85	10	92.7
159-6357	B10-0330	¥676	¥730	M3.0 x 30	75	10	96.7
212-5188	B10-3512	¥676	¥730	M3.5 x 12	105	10	89.9
212-5196	B10-3516	¥676	¥730	M3.5 x 16	90	10	96.6
212-5200	B10-3520	¥676	¥730	M3.5 x 20	75	10	96.8
212-5218	B10-3525	¥676	¥730	M3.5 x 25	65	10	101.4
212-5226	B10-3530	¥676	¥730	M3.5 x 30	55	10	110.7
159-6365	B10-0408	¥676	¥730	M4.0 x 8	110	10	79.0
159-6373	B10-0410	¥676	¥730	M4.0 x 10	100	10	86.1
159-6381	B10-0412	¥676	¥730	M4.0 x 12	95	10	95.1
159-6390	B10-0416	¥676	¥730	M4.0 x 16	80	10	102.7
159-6403	B10-0420	¥676	¥730	M4.0 x 20	70	10	109.6
159-6411	B10-0425	¥676	¥730	M4.0 x 25	60	10	115.0
159-6420	B10-0430	¥676	¥730	M4.0 x 30	50	10	113.5

Order Code	Item No.	Price (per bag)	MSRP (per bag)	Dimension (mm) d x L	Q'ty Per Bag (piece)	SPQ (bag)	Weight (g/bag)
159-6438	B10-0435	¥676	¥730	M4 x 35	45	10	118.0
159-6446	B10-0440	¥676	¥730	M4 x 40	40	10	119.0
159-6454	B10-0445	¥676	¥730	M4 x 45	30	10	99.6
159-6462	B10-0450	¥676	¥730	M4 x 50	25	10	92.0
159-6471	B10-0512	¥676	¥730	M5 x 12	55	10	96.4
159-6489	B10-0516	¥676	¥730	M5 x 16	45	10	99.2
159-6497	B10-0520	¥676	¥730	M5 x 20	40	10	106.3
159-6501	B10-0525	¥676	¥730	M5 x 25	35	10	112.8
159-6519	B10-0530	¥676	¥730	M5 x 30	30	10	113.7
159-6527	B10-0535	¥676	¥730	M5 x 35	25	10	108.9
159-6535	B10-0540	¥676	¥730	M5 x 40	22	10	108.3
159-6543	B10-0545	¥676	¥730	M5 x 45	20	10	109.8
159-6551	B10-0550	¥676	¥730	M5 x 50	18	10	108.9
159-6560	B10-0616	¥676	¥730	M6 x 16	30	10	103.9
159-6578	B10-0620	¥676	¥730	M6 x 20	25	10	102.8
159-6586	B10-0625	¥676	¥730	M6 x 25	22	10	108.2
159-6594	B10-0630	¥676	¥730	M6 x 30	20	10	114.5
159-6608	B10-0635	¥676	¥730	M6 x 35	18	10	117.6
159-6616	B10-0640	¥676	¥730	M6 x 40	15	10	110.1
159-6632	B10-0650	¥676	¥730	M6 x 50	13	10	116.4

Contact us: 0120-509-849 <http://www.orange-book.com/>



A pro-tool compact catalog that lists a wide variety of products all in one, including nearly every category on Orange-Book!

Published once every 2 years

Number of Products Listed: approx. **56,000** items

Number of Off-the-shelf Products: approx. **53,200**,
off-the-shelf ratio **95%**

Number of Listed Manufacturers: approx. **1,419** companies

Number of Catalog Pages: approx. **2,700** pages

Order Code	Item No.	Price (tax not included)
858-5867	OBJM2018E	¥5,500

