

Plate Type Urethane Casters (for medium/heavy load)

Stock 436 Items

2-681

Prices displayed include 8% tax.

TRUSCO
Stock 38,650 Items

Plate Type Caster (nylon wheel urethane tire)

Com Drawing



TYGUJ-150

 


TYGUJB-100A



TYGUK-150

Dimensions



- Features** •Lightweight because of employing nylon wheels.
Specs •Plate Type •With Commercial Bearing
Materials •Metal Fitting: Steel •Metal Fitting Surface Treatment: Trivalent Unichrome Plated
 •Wheel: Nylon Wheel, Urethane
Origin •Japan

Flexible Specs •Flexible Type

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
278-2227	TYGUJ-100	¥1,898	¥2,050	100 102.0	100	32	144	95 x 95	67 to 74 x 67 to 74	11	16	1.00
278-2235	TYGUJ-130	¥2,675	¥2,890	180 183.6	130	40	177	105 x 105	75 to 82 x 75 to 82	11	8	1.70
278-2243	TYGUJ-150	¥2,870	¥3,100	200 204.0	150	40	198	120 x 120	87 to 94 x 87 to 94	11	8	2.08

Flexible with double stopper Specs •Flexible Type (with double stopper)
 •Simultaneously lock the turning part and the wheel

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
450-9889	TYGUJB-100A	¥2,305	¥2,490	100 102.0	100	32	144	95 x 95	67 to 74 x 67 to 74	11	16	1.13
450-9897	TYGUJB-130A	¥3,147	¥3,400	180 183.6	130	40	177	105 x 105	75 to 82 x 75 to 82	11	8	1.80
450-9901	TYGUJB-150A	¥3,342	¥3,610	200 204.0	150	40	198	120 x 120	87 to 94 x 87 to 94	11	8	2.36

Fixed Specs •Fixed Type

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
278-2456	TYGUK-100	¥1,610	¥1,740	100 102.0	100	32	144	115 x 80	80 x 45	11	16	0.73
278-2464	TYGUK-130	¥2,231	¥2,410	180 183.6	130	40	177	137 x 93	100 x 56	11	8	1.31
278-2472	TYGUK-150	¥2,416	¥2,610	200 204.0	150	40	198	137 x 93	100 x 56	11	8	1.47

Contact us: 0120-509-849 <http://www.orange-book.com/>

SAMSUNG
Stock 167 Items

Plate Type Caster with Built-in Spring (urethane wheel)




TP6061-02-PSD-SA-R



TP6061R-02-PSD-SA-R

 Dimensions



- Features** •A caster equipped with tension spring, excellent in driveability and shock absorbing performance even though it has heavy load capacity.
Specs •Plate Type •Maximum shock absorbing load: 117.7daN (120kgf)
Materials •Metal Fitting: Steel •Metal fitting surface treatment: Trivalent galvanizing
 •Wheel: Polyurethane
Origin •Korea

Flexible Specs •Flexible Type

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
835-8140	TP6061-02-PSD-SA-R	¥3,078	¥4,560	176 180	150	40	191	102 x 102	80 x 80 (75 x 75)	10	10	2

Fixed Specs •Fixed Type

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
835-8141	TP6061R-02-PSD-SA-R	¥2,889	¥4,280	176 180	150	40	191	102 x 102	80 x 80 (75 x 75)	10	10	1.75

SAMSUNG CASTER CO. LTD.


SAMSUNG
Stock 167 Items

Plate Type Caster "Automatic Return Caster" (aluminum wheel urethane tire)



TP6658-PAL-PBB

 Dimensions



- Features** •If the load is not applied, the wheels automatically return in the linear direction.
 •Excellent in caster startability, dustproof and waterproof function.
 •Maintenance-free type that uses sealed staple fiber bearing and does not require grease injection for bearing management.


- Specs** •Plate Type
 •Flexible Type
Materials •Metal Fitting: Steel
 •Wheel: Aluminum Wheels, Heat Resistant Urethane
Origin •Korea

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (kg)
818-8330	TP6658-PAL-PBB	¥20,250	¥25,000	300 306	138	50	184.5	130 x 100	77 x 105	11	8	3.1
818-8331	TP6688-PAL-PBB	¥22,680	¥28,000	400 408	203	50	250.0	130 x 100	77 x 105	11	4	3.6

SAMSUNG CASTER CO. LTD.

Video

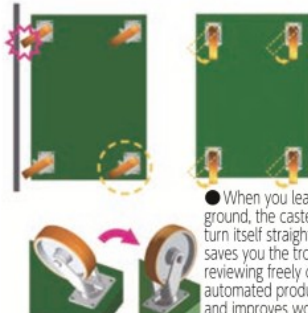

When you leave the ground, the caster will turn itself straight. This saves you the trouble of reviewing freely casters in an automated production line and improves work efficiency.

Casters

Plate Type Rubber Casters

Plate Type Urethane Casters

Plate Type Nylon Casters

Plate Type Resin Casters

Screwed Rubber Casters

Screwed Urethane Casters

Screwed Nylon Casters

Screwed Resin Casters

Nuts, Spanners

Stem Casters

Stainless Steel Casters

Angle Casters

Corner Casters

Dual Wheel Casters

Sound Reducing Casters

ESD-Safe Casters

Shock Absorbing Casters

Castors for Specific Environment

Pneumatic/No-Puncture Caster

Low Level Casters

Heavy-Duty Casters

Casting Casters

Stoppers