

Plate Type Nylon Casters (for light/medium load)

Stock 201 Items

2-697

Prices displayed include 8% tax.


TRUSCO
 **Stock 38,650 Items**

Plate Type Caster "TYS Series" (nylon wheel)



- Features**
- A standard type caster for light/medium load with driveability and load capacity.
 - A standard dimension caster used a lot for transportation dollies, roll box pallets and other general work uses.
- Specs**
- Plate Type
- Materials**
- Metal Fitting: Steel
 - Metal Fitting Surface Treatment: Trivalent Unichrome Plated
 - Wheel: Nylon
- Origin**
- Japan

Bearing structure of pivot portion

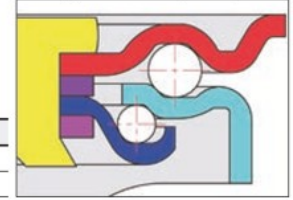


Wheel Diameter	Bearing
50-65-75-100-125	None
150	Yes

Flexible Specs •Flexible Type

TRUSCO NAKAYAMA CORPORATION



TYSNY-150

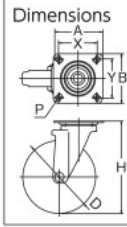


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (g)
474-7984	TYSNY-50	¥ 399	¥ 430	60 61.2	50	28	70	70 x 58	55 x 42	8.8	20	550
474-7992	TYSNY-65	¥ 444	¥ 480	70 71.4	65	25	85	70 x 58	55 x 42	8.8	20	600
474-8000	TYSNY-75	¥ 490	¥ 530	80 81.6	75	25	93	70 x 58	55 x 42	8.8	20	650
474-8018	TYSNY-100	¥ 982	¥ 1,060	120 122.4	100	32	132	90 x 90	68 x 68 (71 x 71)	11.0	20	700
474-8026	TYSNY-125	¥ 1,648	¥ 1,780	150 153.0	125	40	168	102 x 102	75 x 75 (80 x 80)	11.0	8	750
474-8034	TYSNY-150	¥ 1,851	¥ 2,000	160 163.2	150	40	190	102 x 102	75 x 75 (80 x 80)	11.0	8	800

Flexible with stopper Specs •With flexible stopper



TYSNYB-150

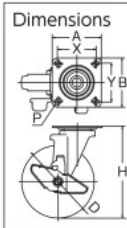


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (g)
474-8042	TYSNYB-50	¥ 509	¥ 550	60 61.2	50	25	70	70 x 58	55 x 42	8.8	20	550
474-8051	TYSNYB-65	¥ 546	¥ 590	70 71.4	65	25	85	70 x 58	55 x 42	8.8	20	600
474-8069	TYSNYB-75	¥ 611	¥ 660	80 81.6	75	26	93	70 x 58	55 x 42	8.8	20	650
474-8077	TYSNYB-100	¥ 1,416	¥ 1,530	120 122.4	100	32	132	90 x 90	68 x 68 (71 x 71)	11.0	20	700
474-8085	TYSNYB-125	¥ 2,222	¥ 2,400	150 153.0	125	40	168	102 x 102	75 x 75 (80 x 80)	11.0	8	750
474-8093	TYSNYB-150	¥ 2,426	¥ 2,620	160 163.2	150	40	190	102 x 102	75 x 75 (80 x 80)	11.0	8	800

Fixed Specs •Fixed Type



TYSNYK-150

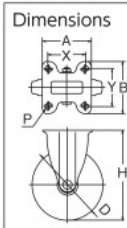


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (g)
474-8107	TYSNYK-50	¥ 296	¥ 320	60 61.2	50	25	70	70 x 47	55 x 28	8.8	20	550
474-8115	TYSNYK-65	¥ 324	¥ 350	70 71.4	65	25	85	70 x 47	55 x 28	8.8	20	600
474-8123	TYSNYK-75	¥ 370	¥ 400	80 81.6	75	26	93	70 x 47	55 x 28	8.8	20	650
474-8131	TYSNYK-100	¥ 778	¥ 840	120 122.4	100	32	132	110 x 78	80 x 45 (90 x 50)	11.0	20	700
474-8140	TYSNYK-125	¥ 1,389	¥ 1,500	150 153.0	125	40	168	140 x 94	100 x 56 (112 x 53)	11.0	8	750
474-8158	TYSNYK-150	¥ 1,481	¥ 1,600	160 163.2	150	40	190	140 x 94	100 x 56 (112 x 53)	11.0	8	800

Replacement Wheel



TYSNW-100

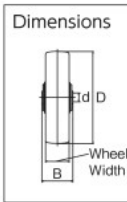

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Hub Width B (mm)	Hole Diameter d (mm)	SPQ (piece)	Weight (g)
484-7491	TYSNW-100	¥ 630	¥ 680	120 122.4	100	32	42	12	32	240
484-7504	TYSNW-125	¥ 1,065	¥ 1,150	150 153.0	125	40	55	12	16	300
484-7512	TYSNW-150	¥ 1,203	¥ 1,300	160 163.2	150	40	55	12	16	450


Contact us: 0120-509-849 <http://www.orange-book.com/>

HAMMER CASTER
 **Stock 793 Items**

Plate Type Caster "440G Series" (nylon wheel)



440G-N75-BAR01

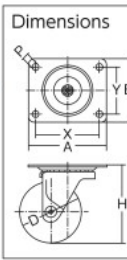

- Features**
- As the mounting height is low and the wheel width is wide, good in stability, rich in drivability and turnability, and excellent in durability.
- Specs**
- Plate Type
- Materials**
- Metal Fitting: Steel
 - Wheel: Nylon
- Origin**
- Japan

Flexible Specs •Flexible Type


HAMMER CASTER Co.Ltd.

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (g)
367-1577	440G-N65-BAR01	¥ 630	-	90 91.8	65	28	82	95 x 70	76 x 44	8.5	24	377
367-1585	440G-N75-BAR01	¥ 836	-	100 102.0	75	35	93	105 x 80	87 x 60	8.5	24	512
367-1569	440G-N100-BAR01	¥ 1,926	-	120 122.4	100	40	125	127 x 102	102 x 76	10.5	16	946

Fixed Specs •Fixed Type



440R-N100-BAR01

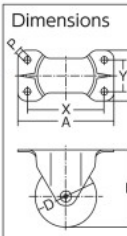

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN) (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Mounting Plate A x B (mm)	Mounting Pitch X x Y (mm)	Mounting Hole Diameter P (mm)	SPQ (piece)	Weight (g)
367-1640	440R-N65-BAR01	¥ 504	-	90 91.8	65	28	82	113 x 59	89 x 28	8.5	24	291
367-1658	440R-N75-BAR01	¥ 685	-	100 102.0	75	35	93	127 x 65	100 x 30	8.5	24	399
367-1631	440R-N100-BAR01	¥ 1,570	-	120 122.4	100	40	125	156 x 82	125 x 51	10.5	16	684

URL <http://www.hammer-caster.co.jp/>

Casters

Plate Type Rubber Casters

Plate Type Urethane Casters

Plate Type Nylon Casters

Plate Type Resin Casters

Screwed Rubber Casters

Screwed Urethane Casters

Screwed Nylon Casters

Screwed Resin Casters

Nuts, Spanners

Stem Casters

Stainless Steel Casters

Angle Casters

Corner Casters

Dual Wheel Casters

Sound Reducing Casters

ESD-Safe Casters

Shock Absorbing Casters

Casters for Specific Environment

Pneumatic/No-Puncture Caster

Low Level Casters

Heavy-Duty Casters

Casting Casters

Stoppers