

Threaded Type Rubber Casters

Stock 153Items

2-707

Prices displayed include 8% tax.




Stock 700 Items

Threaded Type Caster "LT Series" (rubber wheel)



- Features • A standard small type caster optimum for wagons and racks to carry lightweight freight.
 Materials • Metal Fitting: Steel
 • Metal Fitting Surface Treatment: Trivalent Unichrome Plated
 • Wheel: Rubber
 Origin • Japan

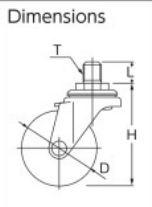


Flexible (unified screw) Specs • Flexible Type
 • Unified screw thread type

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN)	Allowable Weight (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Shaft Length L (mm)	Screw T	Ridge	SPQ (piece)	Weight (g)
360-9057	LT-40R-UNF1/2-14	¥224	-	25	25.5	40	17	59	14	UNF1/2	20 Ridges	40	135
360-9111	LT-50R-UNF1/2-14	¥273	-	30	30.6	50	20	68	14	UNF1/2	20 Ridges	40	145
360-9171	LT-65RH-UNF1/2-14	¥390	-	30	30.6	65	21	85	14	UNF1/2	20 Ridges	20	190
360-9235	LT-75RH-UNF1/2-14	¥453	-	40	40.8	75	21	95	14	UNF1/2	20 Ridges	20	245


YUEI CASTER Co.Ltd

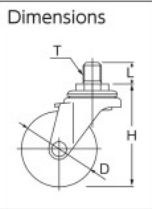

Flexible (metric screw) Specs • Flexible Type
 • Metric Screw Type

Order Unit: 1 Piece


Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN)	Allowable Weight (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Shaft Length L (mm)	Screw T	Thread Pitch (mm)	SPQ (piece)	Weight (g)
360-9006	LT-40R-M12-14	¥224	-	25	25.5	40	17	59	14	M12	1.25	40	135
855-8589	LT-50R-M8-14	¥274	-	30	30.6	50	20	68	14	M8	1.25	40	145
360-9065	LT-50R-M12-14	¥273	-	30	30.6	50	20	68	14	M12	1.25	40	145
360-9120	LT-65RH-M12-14	¥390	-	30	30.6	65	21	85	14	M12	1.25	20	190
360-9189	LT-75RH-M12-14	¥453	-	40	40.8	75	21	95	14	M12	1.25	20	245

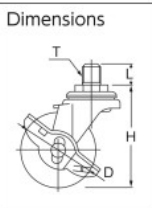

Flexible with stopper (unified screw) Specs • Flexible Type (with stopper)
 • Unified screw thread type

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN)	Allowable Weight (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Shaft Length L (mm)	Screw T	Ridge	SPQ (piece)	Weight (g)
360-9049	LT-40RS-UNF1/2-14	¥287	-	25	25.5	40	17	59	14	UNF1/2	20 Ridges	40	155
360-9103	LT-50RS-UNF1/2-14	¥349	-	30	30.6	50	20	68	14	UNF1/2	20 Ridges	40	170
360-9162	LT-65RHS-UNF1/2-14	¥471	-	30	30.6	65	21	85	14	UNF1/2	20 Ridges	20	230
360-9227	LT-75RHS-UNF1/2-14	¥532	-	40	40.8	75	21	95	14	UNF1/2	20 Ridges	20	280

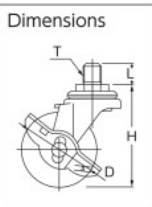

Flexible with stopper (metric screw) Specs • Flexible Type (with stopper)
 • Metric Screw Type

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN)	Allowable Weight (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Shaft Length L (mm)	Screw T	Thread Pitch (mm)	SPQ (piece)	Weight (g)
360-9022	LT-40RS-M12-14	¥287	-	25	25.5	40	17	59	14	M12	1.25	40	155
855-8590	LT-50RS-M8-14	¥352	-	30	30.6	50	20	68	14	M8	1.25	40	170
360-9081	LT-50RS-M12-14	¥349	-	30	30.6	50	20	68	14	M12	1.25	40	170
360-9146	LT-65RHS-M12-14	¥471	-	30	30.6	65	21	85	14	M12	1.25	20	230
360-9201	LT-75RHS-M12-14	¥532	-	40	40.8	75	21	95	14	M12	1.25	20	280

Contact us:06-6747-5618 <http://www.yueicaster.co.jp/>




Stock 38,650 Items

Threaded Type Caster (rubber wheel/long screw type)



- Features • Optimum for tool wagons and pipe wagons to carry lightweight freight.
 • Possible to install even in small space.
 Specs • Threaded type
 Materials • Metal Fitting: Steel
 • Metal Fitting Surface Treatment: Trivalent Unichrome Plated
 • Wheel: Rubber
 Origin • Japan

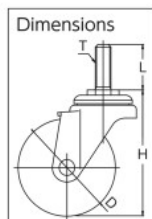


Flexible Specs • Flexible Type

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN)	Allowable Weight (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Shaft Length L (mm)	Screw T	Thread Pitch (mm)	SPQ (piece)	Weight (g)
278-3169	TYLT-75RH	¥370	¥400	40	40.8	75	21	95	35	M12	1.75	20	270

TRUSCO NAKAYAMA CORPORATION

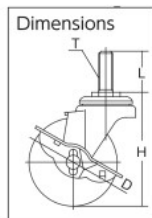

Flexible with stopper Specs • Flexible Type (with stopper)

Order Unit: 1 Piece

Order Code	Item No.	Price (per piece)	MSRP (per piece)	Allowable Weight (daN)	Allowable Weight (kgf)	Wheel Diameter D (mm)	Wheel Width (mm)	Mounting Height H (mm)	Shaft Length L (mm)	Screw T	Thread Pitch (mm)	SPQ (piece)	Weight (g)
278-3177	TYLT-75RHS	¥426	¥460	40	40.8	75	21	95	35	M12	1.75	20	300

Contact us:0120-509-849 <http://www.orange-book.com/>

Casters

Plate Type Rubber Casters

Plate Type Urethane Casters

Plate Type Nylon Casters

Plate Type Resin Casters

Screwed Rubber Casters

Screwed Urethane Casters

Screwed Nylon Casters

Screwed Resin Casters

Nuts, Spanners

Stem Casters

Stainless Steel Casters

Angle Casters

Corner Casters

Dual Wheel Casters

Sound Reducing Casters

ESD-Safe Casters

Shock Absorbing Casters

Casters for Specific Environment

Pneumatic/No-Puncture Caster

Low Level Casters

Heavy-Duty Casters

Casting Casters

Stoppers